









# Wall Plates

## Single Receptacle & Power Outlet Openings

Standard Size Plastic & Metal

Description	Nylon		Thermoset	Metal	
	Color	TradeMaster® Plates	Smooth	Material	Smooth
<b>Single Receptacle Openings</b>					
<b>One Gang</b> 	Ivory White Brown Gray Black Red Light Almond	TP7-I TP7-W TP7 TP7-GRY TP7-BK TP7-RED TP7-LA	SP7-I SP7-W SP7 SP7-GRY  SP7-LA	Aluminum Brass Polished Brass 430S/S 302S/S	SA7 SB7 SB7-PB SL7 SS7
<b>Two Gang</b> 	Ivory White Brown		SP72-I SP72-W SP72	302S/S	SS72
<b>Three Gang</b> 				302S/S 302S/S Painted Ivory 302S/S Painted White 302S/S Painted Gray	SS73 SS73-I SS73-W SS73-GRY
<b>Power Outlet Receptacle Openings – One Gang</b>					
 1.5938" hole for 1.5625" dia. device – 2 mtg. holes	Ivory White Brown Gray Light Almond	TP720-I TP720-W TP720 TP720-GRY TP720-LA	SP720-I SP720-W SP720 SP720-GRY SP720-LA	302S/S	SS720
 1.625" hole for 1.5938" dia. device – 2 mtg. holes				302S/S	SS721
 1.75" hole for 1.7186" dia. device-2 mtg. holes				302S/S	SS725
 2.125" hole for 2.094" dia. device – 2 mtg. holes				302S/S	SS723
 2.156" hole for 2.125" dia. device – 2 mtg. holes	Ivory White Brown Gray Black Light Almond	TP724-I TP724-W TP724 TP724-GRY TP724-BK TP724-LA	384-I  384	Chrome 302S/S	S384-C SS724

These products listed to UL514, Cover Plates for Flush-Mounted Wiring Devices, CSA Certified.

# Wall Plates Specifications

## Application

Pass & Seymour/Legrand's broad line of Standard Size Plastic and Metal Wall Plates features the most complete range of types, sizes, colors, and finishes available. Choose from more than 1,900 standard plates in non-combustible thermoset plastic material, self-extinguishing nylon material, screwless polycarbonate material, or attractively finished metal, for residential, commercial, institutional, and industrial applications. All plastic wall plates color match to Pass & Seymour/Legrand devices.



Thermoset SP Series

## Thermoset Plastic Wall Plates Features

- Molded of non-combustible mar-proof material.
- Available in "SP" series in Standard, Junior-Jumbo, and Jumbo sizes.
- Seven standard colors available – Ivory, White, Brown, Gray, Black, Red, and Light Almond.
- Individually wrapped with color-matching screws.
- Resistant to discoloration, grease, oil, solvent and moisture.
- Nominal thickness, .070"

## TradeMaster® Thermoplastic Wall Plates Features

- Molded of rugged, practically indestructible self-extinguishing nylon. ("TP" series only.)
- Available in "TP" series, extra 3/16" width and height than Standard size plates; and "TPJ" series, extra 3/16" width and height than Junior-Jumbo size plates.
- Available in Ivory, White, Brown, Gray, Black, Blue, Orange, Red, and Light Almond.
- Preferred for hospital, industrial, institutional, and other high-abuse applications.
- Nominal thickness, .070"



Nylon TP Series

## Screwless Polycarbonate Wall Plates Features

- Molded of .065" thick polycarbonate with matte finish.
- Subplate made of .042" zinc-plated steel.
- Available in "SW" series, extra 1/8" width and height than Standard size plates.
- Available in Ivory, White, Gray, Black, and Light Almond.
- Oversized opening to accommodate all NEMA 26 decorator-style openings.

## Metal Wall Plates Features

- Constructed of corrosion-resistant stainless steel, brass, aluminum, chrome, brushed bronze or galvanized steel.
- Standard, Jumbo, and Tandem size plates available, as well as special Panel size plates up to 5-gangs high and 10-gangs wide.
- Packaged in protective film, with finish-matching screws.
- Variety of special plated finishes. Paintable to match plastic plates.
- Can be silk-screened or engraved, and custom punched with over 300 opening styles.

## Materials

- Type 302 Stainless Steel, non-magnetic, .032" nominal thickness, brushed finish. This alloy contains 18% chromium and 8% nickel for superior resistance to corrosion. Recommended for use in food processing plants, dairies, chemical plants, and other industrial, institutional, and commercial applications where corrosive atmospheres exist.
- Type 430 Stainless Steel, magnetic, .032" nominal thickness, brushed finish. Less corrosion-resistant than Type 302, but ideal for general service in high abuse applications in industrial plants, commercial, and institutional buildings.
- Chrome, Brushed and Polished Brass, .040" thick. 70% copper, 30% zinc alloy gives warm, appealing finish to modern decor as well as retrofit applications. Lacquered to prevent corrosion.
- Aluminum, .040" thick. Lustrous satin finish. Lacquered to prevent corrosion.
- Galvanized Steel. Used only for Handy Box Plates.
- Brushed Bronze, .040" thick. 90% copper, 10% zinc. Lacquered to prevent corrosion.



Screwless Polycarbonate SW Series



302 Stainless Steel



Polished Brass



Brushed Brass




Aluminum

# Wall Plates Specifications

Pass & Seymour




Standard Size Wall Plates					
<ul style="list-style-type: none"> <li>Standard size wall plates for all applications.</li> <li>Best fit for surface mount boxes.</li> </ul>			<ul style="list-style-type: none"> <li>Available in plastic and metal only.</li> </ul>		
Dimensions					
<b>1 gang</b>	2.75" x 4.5"	<b>4 gang</b>	8.125" x 4.5"	<b>7 gang</b>	13.62" x 4.5"
<b>2 gang</b>	4.56" x 4.5"	<b>5 gang</b>	10" x 4.5"	<b>8 gang</b>	15.44" x 4.5"
<b>3 gang</b>	6.375" x 4.5"	<b>6 gang</b>	11.812" x 4.5"		

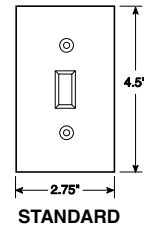


STANDARD

TradeMaster® Wall Plates					
<ul style="list-style-type: none"> <li>Extra 3/16" width and height than Standard size wall plates.</li> <li>Provide better sheet rock coverage with standard size appearance.</li> <li>Available in unbreakable nylon 6 construction only.</li> <li>Screws pre-installed in the duplex, toggle, and decorator single gang plates.</li> </ul>					
Dimensions					
<b>1 gang</b>	2.9375" x 4.6875"	<b>3 gang</b>	6.563" x 4.6875"	<b>5 gang</b>	10.188" x 4.6875"
<b>2 gang</b>	4.75" x 4.6875"	<b>4 gang</b>	8.375" x 4.6875"	<b>6 gang</b>	12" x 4.6875"

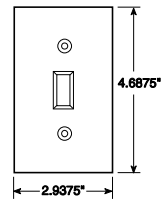


TRADEMASTER STANDARD

Screwless Polycarbonate Wall Plates					
<ul style="list-style-type: none"> <li>Extra 1/8" width and height than Standard size wall plates.</li> <li>Provide better sheet rock coverage with standard size appearance.</li> <li>Molded of .065" thick polycarbonate.</li> <li>Subplate made of .042" zinc-plated steel.</li> <li>Oversized opening to accommodate all NEMA 26 decorator-style openings.</li> </ul>					
Wall Plate Dimensions					
<b>1 gang</b>	3.10" x 4.87"	<b>3 gang</b>	6.724" x 4.87"	<b>5 gang</b>	10.348" x 4.87"
<b>2 gang</b>	4.912" x 4.87"	<b>4 gang</b>	8.536" x 4.87"	<b>6 gang</b>	12.16" x 4.87"
Subplate Dimensions					
<b>1 gang</b>	2.85" x 4.62"	<b>3 gang</b>	6.474" x 4.62"	<b>5 gang</b>	10.098" x 4.62"
<b>2 gang</b>	4.662" x 4.62"	<b>4 gang</b>	8.286" x 4.62"	<b>6 gang</b>	11.910" x 4.62"

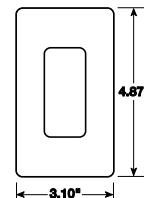


SCREWLESS

Junior-Jumbo Wall Plates					
<ul style="list-style-type: none"> <li>Extra 3/8" width and height than Standard size wall plates.</li> <li>Additional coverage for sheet rock gaps.</li> </ul>			<ul style="list-style-type: none"> <li>Available in plastic and metal only.</li> </ul>		
Dimensions					
<b>1 gang</b>	3.125" x 4.87"	<b>3 gang</b>	6.75" x 4.87"		
<b>2 gang</b>	4.93" x 4.87"	<b>4 gang</b>	8.56" x 4.87"		

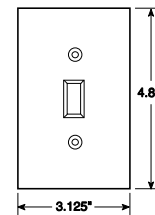


JUNIOR-JUMBO

TradeMaster Jumbo Wall Plates					
<ul style="list-style-type: none"> <li>Extra 3/16" width and height than Junior-Jumbo size wall plates.</li> <li>Provide additional coverage for sheet rock gaps, matching the appearance of the TradeMaster Plates.</li> <li>Available in unbreakable nylon 6 construction only.</li> <li>Screws pre-installed in the duplex, toggle, and decorator single gang plates.</li> </ul>					
Dimensions					
<b>1 gang</b>	3.3125" x 5.0625"	<b>3 gang</b>	6.9375" x 5.0625"		
<b>2 gang</b>	5.125" x 5.0625"	<b>4 gang</b>	8.75" x 5.0625"		

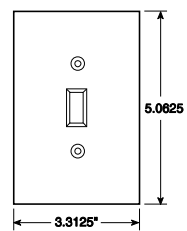

TRADEMASTER JUMBO

Jumbo Wall Plates					
<ul style="list-style-type: none"> <li>Extra 3/4" width and height than Standard size wall plates.</li> <li>Largest size wall plates to cover larger wall damage.</li> </ul>			<ul style="list-style-type: none"> <li>Available in plastic and metal only.</li> </ul>		
Dimensions					
<b>1 gang</b>	3.5" x 5.25"	<b>3 gang</b>	7.12" x 5.25"		
<b>2 gang</b>	5.31" x 5.25"	<b>4 gang</b>	8.93" x 5.25"		

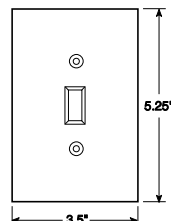

JUMBO