


Straight Blade Receptacles Tamper-Resistant Hard Use & Commercial Grade Receptacles

15 & 20A, 125V



Straight Blade Receptacles


- | Features | |
|---|--|
| <ul style="list-style-type: none"> ■ Dual mechanical shutter system to help prevent insertion of foreign objects. ■ Auto-ground clip assures positive ground. ■ Easily accessed break-off line-contact connecting tab for fast and easy split-circuit wiring. ■ Backed-out tri-drive brass terminal screws for faster installation. Internal screw-pressure-plate back and side wire capability. Two back wire holes for additional wiring flexibility. | <ul style="list-style-type: none"> ■ Corrosion-resistant plated steel strap is locked in to face and back body to resist pulling away from the face/body assembly. ■ .032 inch thick brass triple-wipe power contacts. ■ Two drive screws anchor steel strap to back body and face where abrupt removal torque is greatest. |

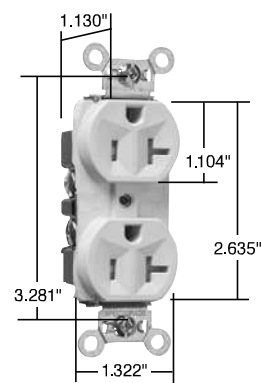

TR5362LA

Catalog Number	Rating A. V.	Color	NEMA Config. No.	3rd Party Compliance		
				UL UL498	FSUL WC596	CS C22.2 No. 42
Tamper-Resistant Duplex Receptacles Back & Side Wire						
TR5262I	15 125	Ivory	5-15R	•	•	•
TR5262W	15 125	White	5-15R	•	•	•
TR5262	15 125	Brown	5-15R	•	•	•
TR5262GRY	15 125	Gray	5-15R	•	•	•
TR5262BK	15 125	Black	5-15R	•	•	•
TR5262RED	15 125	Red	5-15R	•	•	•
TR5262LA	15 125	Light Almond	5-15R	•	•	•
TR5362I	20 125	Ivory	5-20R	•	•	•
TR5362W	20 125	White	5-20R	•	•	•
TR5362	20 125	Brown	5-20R	•	•	•
TR5362GRY	20 125	Gray	5-20R	•	•	•
TR5362BK	20 125	Black	5-20R	•	•	•
TR5362RED	20 125	Red	5-20R	•	•	•
TR5362LA	20 125	Light Almond	5-20R	•	•	•


- | Features | |
|---|---|
| <ul style="list-style-type: none"> ■ Dual mechanical shutter system to help prevent insertions of foreign objects. ■ Two drive screws anchor strap to back body and face where abrupt removal torque is greatest. ■ .032 inch thick brass triple-wipe power contacts for lasting retention. ■ Corrosion-resistant plated steel strap is locked in to the face and back body to resist pulling away from the face/body assembly. | <ul style="list-style-type: none"> ■ Auto-ground clip assures positive ground. ■ Easily accessed break-off line-contact connecting tab for fast and easy split-circuit wiring. ■ Backed-out tri-drive steel terminal screws. Side wire capability. |

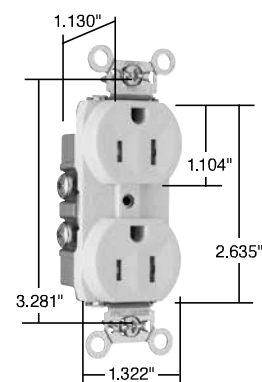

TR15LA

Catalog Number	Rating A. V.	Color	NEMA Config. No.	3rd Party Compliance		
				UL UL498	cULus cULus	CS C22.2 No. 42
Tamper-Resistant Duplex Receptacles Side Wire						
TR15I	15 125	Ivory	5-15R	•	•	•
TR15W	15 125	White	5-15R	•	•	•
TR15	15 125	Brown	5-15R	•	•	•
TR15GRY	15 125	Gray	5-15R	•	•	•
TR15LA	15 125	Light Almond	5-15R	•	•	•
TR20I	20 125	Ivory	5-20R	•	•	•
TR20W	20 125	White	5-20R	•	•	•
TR20	20 125	Brown	5-20R	•	•	•
TR20GRY	20 125	Gray	5-20R	•	•	•
TR20BK	20 125	Black	5-20R	•	•	•
TR20LA	20 125	Light Almond	5-20R	•	•	•

2 Pole, 3 Wire

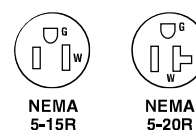

For Bulk Packaging Solutions consult factory.

All devices listed on this page conform to NEMA WD-1 and WD-6.

TR Hard Use & Commercial Grade Recept.