









Combination Wallplates, 2-Gang

Description	Color	Nylon Standard	Nylon Mid-Size	Material	Metal Catalog Number
 <p>2-Gang, 1-Toggle, 1-Duplex</p>	Almond	NP18AL	NPJ18AL	Aluminum	①
	Black	NP18BK	NPJ18BK	Brass	①
	Brown	NP18	NPJ18	Brass Plated	SBP18
	Gray	NP18GY	NPJ18GY	Chrome	SCH18
	Ivory	NP18I	NPJ18I	S/S 302/304	SS18
	Light Almond	NP18LA	NPJ18LA	S/S 430	SS18L
	Office White	NP18OW	NPJ18OW	Steel, Almond	SP18AL*
	Red	NP18R	NPJ18R	Steel, Gray	SP18G*
	White	NP18W	NPJ18W		
	 <p>2-Gang, 1-Duplex, 1-Decorator</p>	Almond	NP826AL	NPJ826AL	Aluminum
Black		NP826BK	NPJ826BK	Brass	SB826
Brown		NP826	NPJ826	Brass Plated	①
Gray		NP826GY	NPJ826GY	Chrome	①
Ivory		NP826I	NPJ826I	S/S 302/304	SS826
Light Almond		NP826LA	NPJ826LA	S/S 430	-
Office White		NP826OW	-		
White		NP826W	NPJ826W		
 <p>2-Gang, 1-Toggle, 1-Decorator</p>	Almond	NP126AL	NPJ126AL	Aluminum	①
	Black	NP126BK	NPJ126BK	Brass	SB126
	Brown	NP126	NPJ126	Brass Plated	SBP126
	Gray	NP126GY	NPJ126GY	Chrome	①
	Ivory	NP126I	NPJ126I	S/S 302/304	SS126
	Light Almond	NP126LA	NPJ126LA	S/S 430	SS126L
	White	NP126W	NPJ126W	Steel, Almond	PJS126AL*
				Steel, Gray	PJS126G*
 <p>2-Gang, 1-Duplex, 1-Telephone .406 in. (10.3) Hole Strap Mount</p>	Black	NP128BK	-	Aluminum	-
	Brown	NP128	-	Brass	-
	Gray	NP128GY	-	Brass Plated	-
	Ivory	NP128I	-	Chrome	-
	White	NP128W	-	S/S 302/304	-
				S/S 430	-
 <p>2-Gang, 1-Toggle, 1-Telephone .406 in. (10.3) Hole Strap Mount</p>	Black	NP112BK	-	Aluminum	-
	Brown	NP112	-	Brass	-
	Gray	NP112GY	-	Brass Plated	-
	Ivory	NP112I	-	Chrome	-
	Office White	NP112OW	-	S/S 302/304	-
	White	NP112W	-	S/S 430	-
 <p>2-Gang, 1-Decorator, 1-Telephone .406 in. (10.3) Hole Strap Mount</p>	Black	NP1226BK	-	Aluminum	-
	Brown	NP1226	-	Brass	-
	Gray	NP1226GY	-	Brass Plated	-
	Ivory	NP1226I	-	Chrome	-
	White	NP1226W	-	S/S 302/304	-
				S/S 430	-
 <p>2-Gang, 1-Single Receptacle 1.40 in. (35.6) Hole, 1-Duplex</p>	Almond	NP78AL	-	Aluminum	①
	Brown	NP78	-	Brass	①
	Gray	NP78GY	-	Brass Plated	①
	Ivory	NP78I	-	Chrome	①
	White	NP78W	-	S/S 302/304	SS78
				S/S 430	-
 <p>2-Gang, 1-Single Recept. 1.60 in. (40.6) Hole, 1-Duplex</p>	Almond	-	-	Aluminum	①
	Brown	-	-	Brass	①
	Ivory	-	-	Brass Plated	①
	White	-	-	Chrome	①
				S/S 302/304	SS8720
				S/S 430	-

Note: All standard and mid-size nylon wallplates feature pre-inserted captive screws for faster assembly, up to 6-gang.
 ①Available as a custom wallplate, see pages N-32 to N-36. Consult custom wallplates section for additional openings and combinations.
 *Powder coat paint finish.

Combination, Nylon, Standard Wallplates

Color	2-Gang, 1-Toggle 1-Decorator	2-Gang, 1-Duplex, 1-Decorator	2-Gang, 1-Blank Box Mount 1-Decorator	3-Gang, 2-Toggle 1-Decorator	3-Gang, 1-Toggle 2-Decorator	4-Gang, 3-Toggle 1-Decorator	4-Gang, 2-Toggle 2-Decorator
Black	NP126BK	NP826BK	NP1326BK	NP226BK	NP1262BK	NP326BK	NP2262BK
Brown	NP126	NP826	NP1326	NP226	NP1262	NP326	NP2262
Gray	NP126GY	NP826GY	NP1326GY	NP226GY	NP1262GY	NP326GY	NP2262GY
Ivory	NP126I	NP826I	NP1326I	NP226I	NP1262I	NP326I	NP2262I
Light Almond	NP126LA	NP826LA	NP1326LA	NP226LA	NP1262LA	NP326LA	NP2262LA
White	NP126W	NP826W	NP1326W	NP226W	NP1262W	NP326W	NP2262W



Combination, Nylon, Mid-Size Wallplates

Color	2-Gang, 1-Toggle 1-Decorator	2-Gang, 1-Duplex, 1-Decorator	2-Gang, 1-Blank Box Mount 1-Decorator	3-Gang, 2-Toggle 1-Decorator	3-Gang, 1-Toggle 2-Decorator	4-Gang, 3-Toggle 1-Decorator	4-Gang, 2-Toggle 2-Decorator
Black	NPJ126BK	NPJ826BK	—	NPJ226BK	—	—	—
Brown	NPJ126	NPJ826	NPJ1326	NPJ226	—	—	—
Gray	NPJ126GY	NPJ826GY	—	NPJ226GY	—	—	—
Ivory	NPJ126I	NPJ826I	NPJ1326I	NPJ226I	—	—	—
Light Almond	NPJ126LA	NPJ826LA	NPJ1326LA	NPJ226LA	—	—	—
White	NPJ126W	NPJ826W	NPJ1326W	NPJ226W	—	—	—

Combination, Standard, Metal Wallplates

Material	2-Gang, 1-Toggle 1-Decorator	2-Gang, 1-Duplex, 1-Decorator	2-Gang, 1-Blank Strap Mount 1-Decorator	3-Gang, 2-Toggle 1-Decorator	3-Gang, 1-Toggle 2-Decorator	4-Gang, 3-Toggle 1-Decorator	4-Gang, 2-Toggle 2-Decorator
Brass	SB126	SB826	—	—	—	—	—
Brass Plated	SBP126	—	—	—	—	—	—
Chrome	—	—	—	—	—	—	—
SS 302/304	SS126	SS826	SS1426	SS226	—	SS326	—
SS 430	SS126L	—	—	—	—	—	—

Dimensions

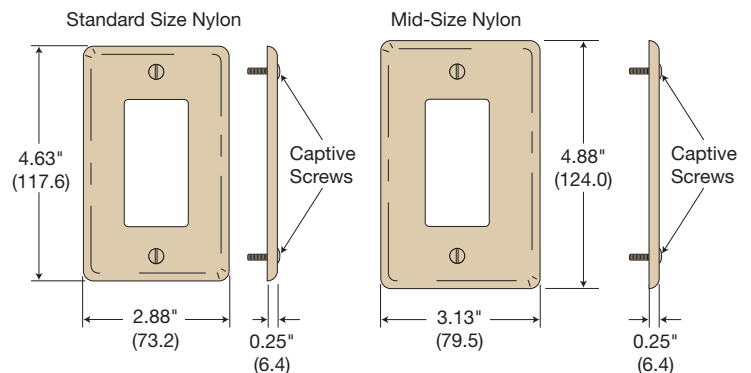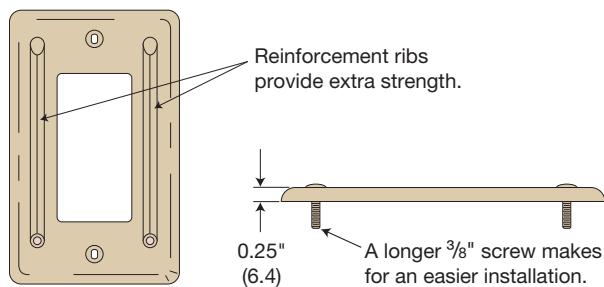

Dimensions in Inches (mm)