


4100P12W

Pin and Sleeve Devices - IEC 60309

Item Description

100 Amp, 125/250 Volt, 3P, 4W, North American-Rated Pin & Sleeve Plug, Industrial Grade, IP67, Watertight - ORANGE

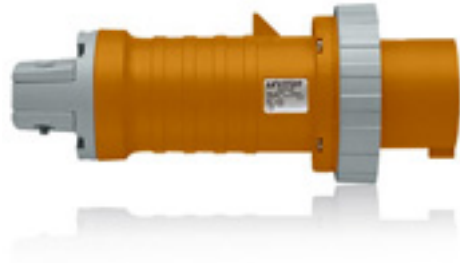

Color:



Orange

UPC Code: 07847783887

Country of Origin: Sweden - *Eligible for
ARRA funded projects > \$7,443,000

Configuration:



Technical Information

Electrical Specifications

Amperage: 100 Amp

Voltage: 125/250 Volt

Pole: 3

Wire: 4

Dielectric Voltage: 2000V for 1 min.

Insulation Resistance: 500V for 1 min;
>= 5M

Endurance: Up to 250 connects and disconnects, under load, at full rated current and voltage

Current Interrupting: Certified for current interrupting at full rated current

Temperature Rise: Max 30C after 50 cycles OL at 150 percent rated current

Environmental Specifications

Flammability: Rated V-0 per UL94

Corrosion Resistance: Ferrous parts immersed in 20°C, 10 percent ammonium chloride solution for 10 min

Moisture Resistance: Per UL 1682, immersed for 24 hours in 5cm of 25°C water

IP Rating: IP67, Watertight

Material Specifications

Body Material: Valox 357

Locking Ring: Valox 357

Internal Cord Clamp Assembly: Thermoplastic

External Cord Clamp Assembly: Valox 357

Gland Cap: Valox 357

Grommet/Gasket: Chloroprene

Contact Carrier: Reinforced Nylon

Phase and Ground Pins: Brass

Internal Screws: Zinc-plated steel

Terminal Screws: Stainless Steel

External Screws: Acid-Proof S/S

Mechanical Specifications

Cable Secureness: Force: 150lb, Torque: 2.0 ft-lb, Max Disp: <= 3/32"

Impact Resistance: Drop from 30" 8 times after conditioning to -25°C for 6 hrs

Crush Test: 250lbs for 1 min after -25°C for 6 hrs

Minimum Withdrawal Force: 20lbs

Cord Range: .950 - 1.875

Product Features

Pin Material: Solid Brass

Color: Orange

Standards and Certifications

UL Listed: 1682 and 1686


CSA Certified: C22.2 No 182.1

IEC Rating: 60309-1 and 60309-2

CE Marking: Per low voltage directives 73/23/EEC, 93/68/EEC

Warranty: 2-Year Limited

Dimensional Diagram

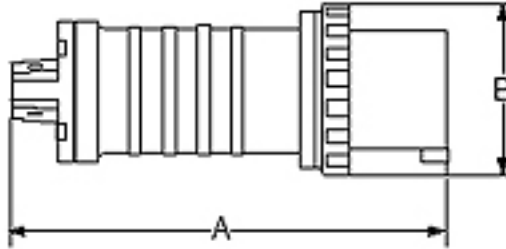

UNIT	A	B
inch	12.3	5.00
mm	312	127

SPECIFICATION SUBMITTAL

JOB NAME: <input style="width: 95%; height: 20px;" type="text"/>	CATALOG NUMBERS: <input style="width: 95%; height: 20px;" type="text"/>	
JOB NUMBER: <input style="width: 95%; height: 20px;" type="text"/>	<input style="width: 95%; height: 20px;" type="text"/>	<input style="width: 95%; height: 20px;" type="text"/>

Leviton Manufacturing Co., Inc.

201 North Service Road, Melville, NY 11747
 Telephone: 1-800-323-8920 · FAX: 1-800-832-9538 · Tech Line (8:30AM-7:30PM E.S.T. Monday-Friday): 1-800-824-3005

Leviton Manufacturing of Canada, Ltd.

165 Hymus Boulevard, Pointe Claire, Quebec H9R 1E9 · Telephone: 1-800-469-7890 ·
 FAX: 1-800-824-3005 · www.leviton.com/canada

Leviton S. de R.L. de C.V.

Lago Tana 43, Mexico DF, Mexico CP 11290 · Tel.: (+52)55-5082-1040 · FAX: (+52)5386-1797 · www.leviton.com.mx

Visit our Website at: www.leviton.com

© 2012-2013 Leviton Manufacturing Co., Inc. All rights reserved. Subject to change without notice.

Leviton has a global presence.

If you would like to know where your local Leviton office is located please go to: www.leviton.com/international/contacts/

**Buy American Compliant Logo -- The American Recovery And Reinvestment Act of 2009 ("ARRA") provides federal grants and loans for projects throughout the country. Section 1605 of the Act, named the "Buy American" provision, requires that certain materials and manufactured products used in projects funded by the Act be manufactured in the United States. The appearance of the Recovery Act Logo in relation to a Leviton product is only intended to reflect that such product may be used in an ARRA funded project. It does not mean that such product or Leviton is sponsored or endorsed by, or that Leviton receives funds from, the federal government or the Recovery Accountability and Transparency Board. Nothing in Leviton's use of the logo is intended to suggest anything regarding the requirements for funding under ARRA.*

