

Commercial Grade

Traditional

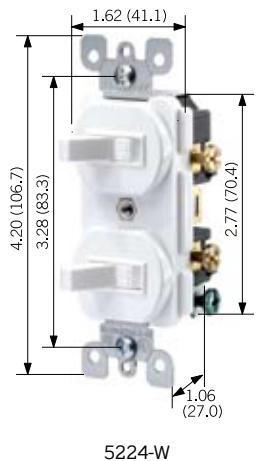
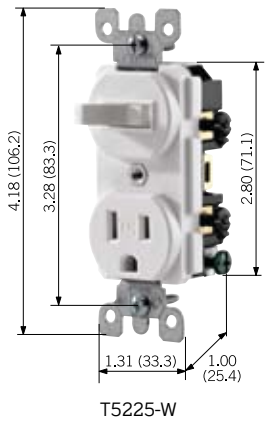
Leviton's Combination Devices offer pleasing, practical designs that fit standard wallboxes. Switch/switch, switch/receptacle and switch/pilot light combinations are available. These devices come in a range of colors and are backed by a limited two-year warranty.

Specifications and Features

- AC quiet switches have silver-cadmium oxide contacts and receptacles have double-wire contacts for maximum conductivity
- All devices have a grounding screw, except where noted
- Terminal screws accept up to No. 12 AWG copper or copper-clad wire
- Fits standard wallboxes
- Break-off tabs on devices with switches permit conversion to separate feeds
- Limited Two-Year Warranty



Tamper Resistant Receptacles

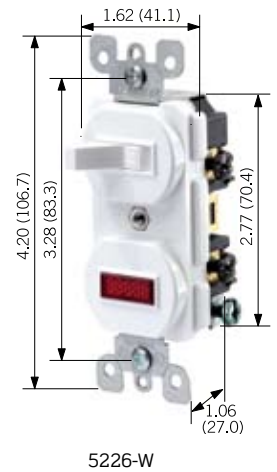
- Shutter mechanism inside the receptacle blocks access to the contacts unless a two-prong plug is inserted, helping ensure hairpins, keys, etc., will be locked out
- TR symbol on residential receptacles assures they meet the 2008 NEC requirement
- Heavy-duty construction offers long, trouble-free service life



COMBINATION DEVICES

Description	Color	Cat No.	Cat. No.
NEMA		5-15R	5-20R
Rating		Switch: 15A-120VAC Receptacle: 15A-125V	
Single Pole Switch/ Tamper Resistant Receptacle*	White Ivory Almond Light Almond Brown	T5225-W T5225-I T5225-A T5225-T T5225	
Rating		Switch: 15A-120VAC Receptacle: 15A-125V	Switch: 20A-120VAC Receptacle: 20A-125V
Single Pole Switch/Receptacle*	White Ivory Almond Light Almond Black Brown	5225-W 5225-I 5225-A 5225-T — 5225	5335-W 5335-I — — 5335-E 5335
Rating		15A-120/277VAC	
Two Single Pole Switches, non-ground	White Ivory Brown	5224-W 5224-I 5224	
Rating		15A-120/277VAC	20A-120/277VAC
Two Single Pole Switches, with ground screw	White Ivory Almond Light Almond Brown	5224-2W 5224-2I 5224-2A 5224-2T 5224	5334-W 5334-I — — 5334

Description	Color	Cat No.	Cat. No.
NEMA		 5-15R	 5-20R
Rating		Switch: 15A-120VAC Pilot Light: 1/25W-125VAC	Switch: 20A-120VAC Pilot Light: 1/25W-125VAC
Single Pole Switch/Pilot Light*	White	5226-W	—
	Ivory	5226-I	5336-I
	Almond	5226-A	—
	Light Almond	5226-T	—
	Brown	5226	5336
Rating		15A-120/277VAC	
3-Way Switch/Single Pole Switch *	White	5241-W	
	Ivory	5241-I	
	Almond	5241-A	
	Light Almond	5241-T	
	Brown	5241	
Rating		15A-120/277VAC	
Two 3-Way Switches*	White	5243-W	
	Ivory	5243-I	
	Almond	5243-A	
	Light Almond	5243-T	
	Brown	5243	
Rating		Switch: 15A-120/277VAC Receptacle: 15A-125V	
3-Way Switch/Receptacle*	White	5245-W	
	Ivory	5245-I	
	Brown	5245	



*With ground screw

TESTING AND CODE COMPLIANCE

- UL Listed (File #E-7458)
- CSA Certified (File #LR-3413)
- NOM Certified (#057)

HORSEPOWER

15A — 1/2 @ 120V, 2 @ 240V
20A — 1 @ 120V, 2 @ 240V

MATERIAL CHARACTERISTICS

Environmental: Flammability UL-94, V2 Rating
Operating Temperature: -40°C to 120°C