



8450

Description

50 Amp, 250 Volt, NEMA 15-50R, 3P, 4W, Flush Mtg Receptacle, Straight Blade, Industrial Grade, Grounding, 3-Phase, Side Wired, Steel Strap, - Black

Product Features

Color: Black



Grounding: Grounding

Feature: 3-Phase

Amperage: 50 Amp

Voltage: 250 Volt

NEMA: 15-50R

Pole: 3

Wire: 4

Termination: Side

Face Material: Nylon

Body Material: Nylon

Strap Material: Steel

Color: Black

Standards and Certifications: UL/CSA

Warranty: 10 Year Limited


AC Horsepower Ratings	
At Rated Voltage	7-1/2 HP
Environmental Specifications	
Flammability	Rated V-2 per UL94
Operating Temperature	-40C to 60C
Mechanical Specifications	
Terminal ID	Brass-Hot, Green-Ground, White-Neutral
Terminal Accom.	Up to 4 AWG

Electrical Specifications	
Dielectric Voltage	Withstands 2000V per UL498
Current Limiting	Full Rated Current
Temperature Rise	Max 30C after 50 cycles OL at 150 percent rated current

Material Specifications	
Face Material	Nylon
Body Material	Nylon
Line Contacts	Brass Double-Wipe
Product ID	Ratings are permanently marked on device
Yoke	Zinc-Plated Steel

Standards and Certifications	
NEMA	WD-6
ANSI	C-73
UL498	File E13399
CSA C22.2 No. 42	File 152105
NOM	057

Wiring Diagram

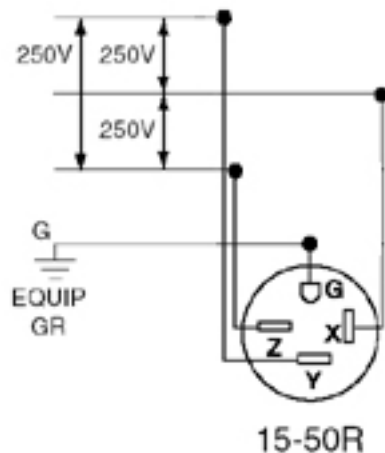

SPECIFICATION SUBMITTAL

JOB NAME: <input type="text"/>	CATALOG NUMBERS: <input type="text"/>	<input type="text"/>
JOB NUMBER: <input type="text"/>	<input type="text"/>	<input type="text"/>

Leviton Manufacturing Co., Inc.

59-25 Little Neck Parkway, Little Neck, NY 11362-2591

Telephone: 1-800-323-8920 · FAX: 1-800-832-9538 · Tech Line (8:30AM-7:30PM E.S.T. Monday-Friday): 1-800-824-3005

Leviton Manufacturing of Canada, Ltd.

165 Hymus Boulevard, Pointe Claire, Quebec H9R 1E9 · Telephone: 1-800-469-7890 · FAX: 1-800-824-3005

Leviton S. de R.L. de C.V.

Lago Tana 43, Mexico DF, Mexico CP 11290 · Tel.: (+52)55-5082-1040 · FAX: (+52)5386-1797 · www.leviton.com.mx



Visit our Website at: www.leviton.com

©2007 Leviton Manufacturing Co., Inc. All rights reserved. Subject to change without notice.