

CS6361C

Locking Wiring Devices



UPC Code: 07847732602

Country of Origin: Mexico - *Eligible for
ARRA funded projects > \$7,443,000

Configuration:



Brand Features

Leviton's Industrial Grade Locking Devices are built to provide unparalleled quality and superior performance in the most severe industrial settings. Leviton combines the best materials available with superior production standards to produce a broad selection of Locking Devices of unmatched flexibility and dependability.

Item Description

50Amp, 125V AC, Non-NEMA, 2P, 3W, Black & White Locking Plug, Industrial Grade, Grounding, California-Style(CS) – BLACK-WHITE

Technical Information

Electrical Specifications

Grounding: Grounding

Amperage: 50 Amp

Voltage: 125 Volt

Pole: 2

Wire: 3

Dielectric Voltage Withstand: 2000V minimum per UL 498

Maximum Working Voltage: 125V as rated

Current Interrupting: Certified for current interrupting at full rated current

Temperature Rise: Max 30°C temp rise at full-rated current after 150 cycles of OL at 150% rated DC current

Environmental Specifications

Flammability: UL94V-2

Operating Temperature: -40deg.C to 75deg.C (-40deg.F to 167deg.F)

Material Specifications

Face Module: Nylon

Wiring Chamber: Nylon

Assembly Screws: Brass

Housing Material: Nylon

Dust Shield: Santoprene TPE

Terminal Block: 0.062inch thick Copper

Terminal Set Screw: SS 302/304

Ground Shunt: Bronze

Ground Post: Brass

Plug Blade: 0.1000inch thick Brass

Plug Blade Shroud: SS 302/304

Standard Cable Clamp: Nylon

Cable Clamp Screw: Philips Head, SS 304

Color: Black-White

Mechanical Specifications

Terminal ID: X, W, Y, Z and Green for ground

Terminal Accom.: #10 min to #4max AWG Solid or Stranded Wire

Product ID: Ratings and Catalogue No. molded into face and stamped into shroud

Cord Range: .680 - 1.125

Product Features

NEMA: Non-NEMA

Color: Black-White

Standards and Certifications


UL 498: File E13399

CSA C22.2 No. 42: File 152105

NOM: 057

RoHS: Compliant

Warranty: Lifetime Limited

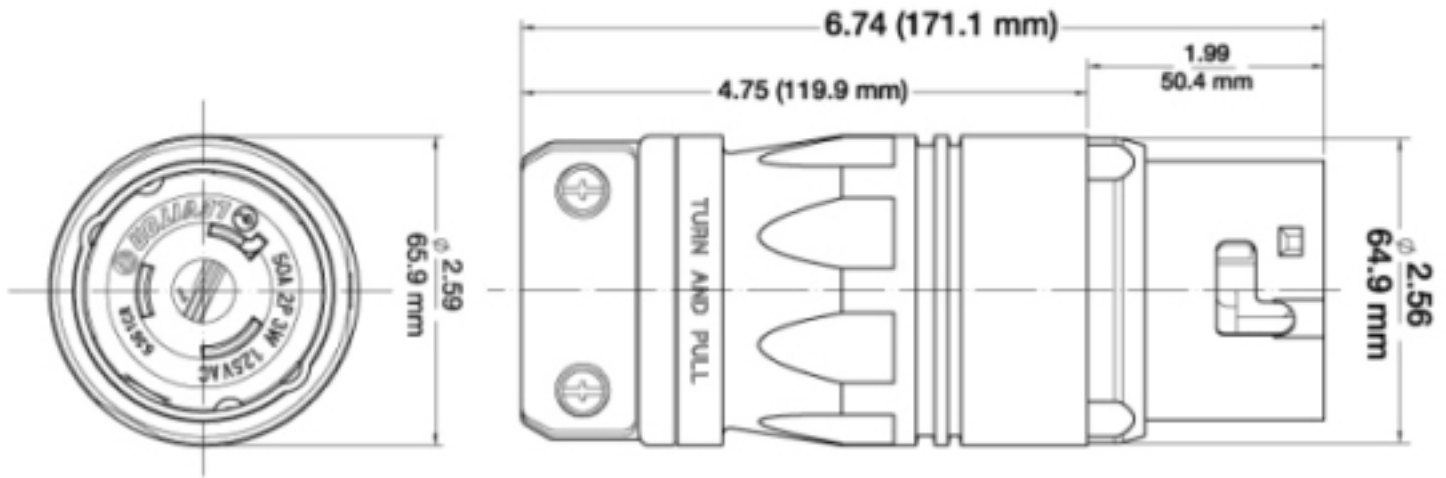

SPECIFICATION SUBMITTAL

JOB NAME:	CATALOG NUMBERS:	
<input type="text"/>	<input type="text"/>	<input type="text"/>
JOB NUMBER:	<input type="text"/>	<input type="text"/>

Leviton Manufacturing Co., Inc.
 201 North Service Road, Melville, NY 11747
 Telephone: 1-800-323-8920 · FAX: 1-800-832-9538 · Tech Line (8:30AM-7:30PM E.S.T. Monday-Friday): 1-800-824-3005

Leviton Manufacturing of Canada, Ltd.
 165 Hymus Boulevard, Pointe Claire, Quebec H9R 1E9 · Telephone: 1-800-469-7890 ·
 FAX: 1-800-824-3005 · www.leviton.com/canada

Leviton S. de R.L. de C.V.
 Lago Tana 43, Mexico DF, Mexico CP 11290 · Tel.: (+52)55-5082-1040 · FAX: (+52)5386-1797 · www.leviton.com.mx

Visit our Website at: www.leviton.com
 © 2012-2013 Leviton Manufacturing Co., Inc. All rights reserved. Subject to change without notice.



Leviton has a global presence.
 If you would like to know where your local Leviton office is located please go to: www.leviton.com/international/contacts/

**Buy American Compliant Logo -- The American Recovery And Reinvestment Act of 2009 ("ARRA") provides federal grants and loans for projects throughout the country. Section 1605 of the Act, named the "Buy American" provision, requires that certain materials and manufactured products used in projects funded by the Act be manufactured in the United States. The appearance of the Recovery Act Logo in relation to a Leviton product is only intended to reflect that such product may be used in an ARRA funded project. It does not mean that such product or Leviton is sponsored or endorsed by, or that Leviton receives funds from, the federal government or the Recovery Accountability and Transparency Board. Nothing in Leviton's use of the logo is intended to suggest anything regarding the requirements for funding under ARRA.*