

M1221-GY



Color: Gray

 
 
UPC Code: 07847749437
Country Of Origin: Mexico

*Eligible for ARRA funded projects > \$7,443,000



[*Disclaimer...](#)

Choose a Color



Product Lists

Add to Product List

View Product List

Quantity:

M1221-GY

Item Description

20 Amp, 120/277 Volt, Single-Pole AC Toggle Switch, Extra Heavy Duty Specification Grade, Self Grounding, Lev-Lok Modular – GRAY

Mating Lev-Lok Wiring Module Required for Use

Where To Buy

Market Channel

enter your zip code

[Technical Information](#) | [Support](#) | [Related Products](#) | [Videos](#)

Technical Information

[TOP](#)

AC Horsepower Ratings

HP Rating: 1HP-120V 2HP-240V

Electrical Specifications

Amperage: 20 Amp
Voltage: 120/277 VAC
Grounding: Self-Grounding
Dielectric Voltage: Withstands 1500V for 1 minute
Overload UL20 Test: 100 cycles of OL at 4.8 times rated current
Temperature Rise: Maximum 30 degrees C rise
Endurance: 50,000 cycles minimum

Environmental Specifications

Flammability: Rated V-2 per UL94
Operating Temperature: -40°C to 65°C

Material Specifications

Strap Material: Galvanized Steel
Base Material: PBT
Toggle: Polycarbonate
Cover Material: Nylon
Contact Material: Silver Alloy
Ground Clips: Brass
Dome: Nylon
Color: Gray

Mechanical Specifications

Product ID: Markings are permanently marked on device

Product Features

Color: Gray

Standards and Certifications

NEMA: WD-1 & WD-6
ANSI: C-73
NOM: 057
RoHS: Compliant
Warranty: 10 Year Limited
cULus: File # E7458

Support

[TOP](#)

Product Brochure


[Dimensional Data](#)

[Instruction Sheet](#)

[Wiring Diagram](#)

Related Products

[TOP](#)

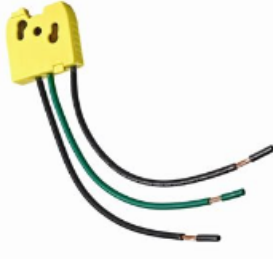

MSPSW-ST

20 Amp, 347V AC Max, Wiring Module for Lev-Lok Single Pole Toggle Switches, 3 Wire, Black 6" Stranded ...

[More](#)



84001

1-Gang Toggle Device Switch Wallplate, Standard Size, 430 Stainless Steel, Device Mount, - Stainless S...

[More](#)



MSPSW-WST

20 Amp, 347V AC Max, Wiring Module for Lev-Lok Single Pole Toggle Switches, 3 Wire, Black 6" Stranded ...

[More](#)



20 Amp, 347V AC Max, Wiring Module for Lev-Lok Single Pole Toggle Switches, 3 Wire, Black 6" Stranded ...

[More](#)

Videos

[TOP](#)

Lev-Lok Modular Switch and Receptacle

Lev-Lok Modular Switch and Receptacle



Lev-Lok Modular Switch

Leviton is the smart choice, delivering the most comprehensive range of solutions to meet the needs of today's residential, commercial and industrial customers in more than 90 countries across the globe. From simple switches and receptacles, to networking systems and smart home automation, Leviton exceeds market needs by delivering innovative products to create sustainable, intelligent environments through its electrical wiring devices, network and data center connectivity solutions, LED lighting and lighting energy management systems, and security and automation applications. For Leviton, it is clear the FUTURE IS ON.



PRODUCTS

- Connected Home
- Electric Vehicle Charging
- Electrical Wiring Devices
- GFCIs and AFCIs
- Lighting Controls
- Network Solutions
- Security & Automation
- Submetering
- Surge Protective Devices
- Temporary Power

SOLUTIONS

- Applications
- Brands
- Business
- Contech Lighting
- Intense Lighting
- Energy Management
- Government
- Home Solutions
- Industrial
- JCC Lighting Products
- Security & Automation

SUPPORT

- Contact Us
- Cross Reference
- Discussions
- Documents & Resources
- ez-Biz
- ez-Learn
- Knowledgebase
- Leviton Warranties
- Mobile Apps
- Product Support
- Quality Concerns