

Commercial Grade Modular Devices 15 & 20 Amp Duplex

Straight Blade Receptacles, 2-Pole, 3-Wire Grounding

Cat. Nos.

M5262-S, M5362-S, MT562-S, MT563-S, MSTWL

Application

In accordance with the NEC, these devices are suitable for use in all 15 or 20 ampere branch circuits of 125 Volts in commercial and institutional installations where UL Federal Specification WC-596 standard of mechanical and electrical life is specified.





M5362-SW

MSTLW-A

MATERIALS

Component	Material
Cover	Nylon
Base	Nylon
Mounting Strap	Galvanized Steel w/riveted ground contact
Ground Clip	Brass
Line Contacts	0.040" Thick Brass
Locking Pins	Solid Brass
Bushing	Solid Brass
Mounting Screws	Triple Combination Head, Steel
Shutter Mechanism ("MT" versions)	Delrin® Acetal
Certifications and Code Compliance	NEMA WD-1&6, Fed. Spec. WC-596, UL 498, CSA C22.2 No. 42, ANCE NOM 057
Wiring Module	Material
Wire Leads	6", #12 AWG THHN 1 Hot Lead (Black), 1 Neutral Lead (White), 1 Ground Lead (Green)
Contacts	Brass
Housing	Polycarbonate

ORDERING INFORMATION

Description	Color	15A 125V, NEMA 5-15R 		20A 125V, NEMA 5-20R 	
		Standard	Tamper-Resistant	Standard	Tamper-Resistant
Duplex Receptacles	Brown	M5262-S	MT562-S	M5362-S	MT563-S
	Ivory	M5262-SI	MT562-SI	M5362-SI	MT563-SI
	White	M5262-SW	MT562-SW	M5362-SW	MT563-SW
	Black	—	—	—	—
	Blue	—	—	—	—
	Gray	M5262-GYS	MT562-SGY	M5362-GYS	MT563-SGY
	Red	—	—	—	—
	Light Almond	M5262-ST	MT562-ST	M5362-ST	MT563-ST
Description		Cat. No.			
Wiring Module – Right Angle, Stranded Wire Leads		MSTWL-A			
Wiring Module – Right Angle, Solid Wire Leads		MSTWL-SDA			





M5262 15Amp-125 Volts


Dimensions apply to

Cat. Nos.

M5262-S, M5362-S,
MT562-S, MT563-S & MSTWL

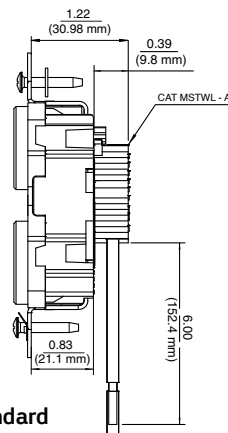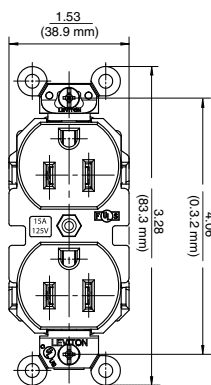

Standard

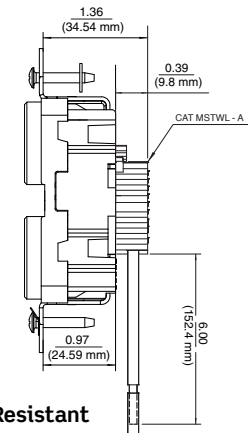

Tamper-Resistant

lev-lok® M5262-S, M5362-S, MT562-S, MT563-S, MSTWL