

LED-8050M 300W LED for HID Retrofit for 1000W Highbay





Models


LED-8050M50, 90-305VAC, cULus, 5000K CCT, E39
 LED-8050M50-HV, 249-528VAC, cULus, 5000K CCT, E39

Features

- > 300W LED Replaces 1000W HID Lamp
- > Inventronics Driver Included
- > IP64 Lamp and IP67 Remote/External Driver
- > 0-10V, PWM, or Resistive dimming when used with lighting controls
- > UL approved for wet environments
- > 50,000 hour rated LED life (supported by LM80 and ISTMT reports (see website))
- > 5 Year Limited Warranty - see website for details
- > UL1598C retains fixture UL Listing

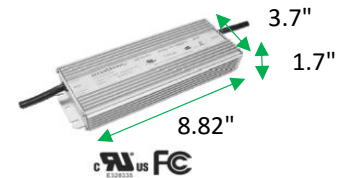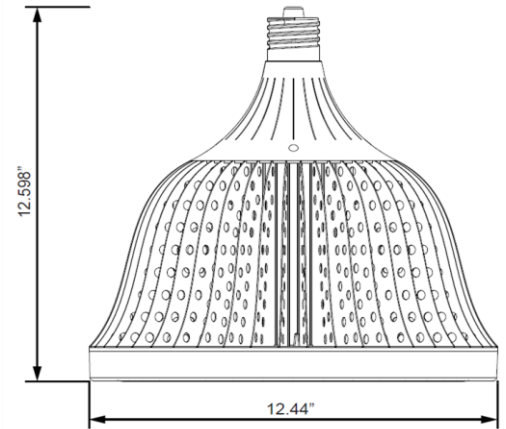

Illuminance Plots

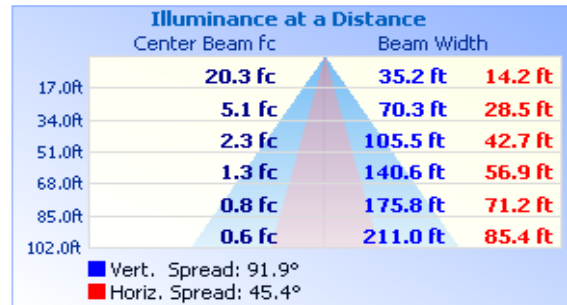

Technical Specifications		
Models US/CAN	LED-8050M50	LED-8050M50-HV
CCT	5000K	5000K
Power Consumption	300 watts	
Replaces	1000 MH/HPS	
Mounting	E39	
Voltage	90-305VAC	249-528VAC
LED Type	TBD	
Beam Angle	120°	
Dimmable	Yes	
Operating Temp	-40°F - +122°F	
Rated R70 Life	Up to 50,000 Hrs.	
Warranty	5 Year Limited*	
LM79 Specifications		
	Yes	Yes
Power (W)	298.2	297.9
CCT	4888	4886
Light Output	34153	33533
Efficacy	114.53	112.56
THD @ 277V	3.93%	7.41%
PF @ 277V	99	98
CRI:	71.7	71.6
R9	0	0
Duv	0.0027	0.0026
Packaging	1/ Master Carton	
Unit	13.9 X 13.9 X 14.1 " lbs.	
Master	14.5 X 28.4 X 14.7" lbs.	

Installation Notes:

- Ballast must be bypassed
- Approved for Open Fixtures Only
- Installing surge/lightning protectors is highly recommended

LED Power Consumption (Watts)	HID Power Consumption (Watts)	HID Ballast Power Consumption (Watts)	Total Savings (Watts)	Annual Energy Savings (14 hrs/day)	Lifetime Energy Savings (over 50,000 hrs)
300	1000	150	850	\$478	\$4,675

Mounting Orientation			Minimum Fixture Size Requirements (inches)	
Base Up	Base Down	Horiz		
			Length	14.5
			Width	14.5
			Height	14.5
Approved	Approved	Not Approved	Cu. Inches	3048.6



188 S. Northwest Highway • Cary, IL 60013
 (847) 380-3540 • FAX: (847) 380-3542
 www.led-llc.com

