 





DESIGN TOOLS




TECHNICAL DATA



CLIC 8-59

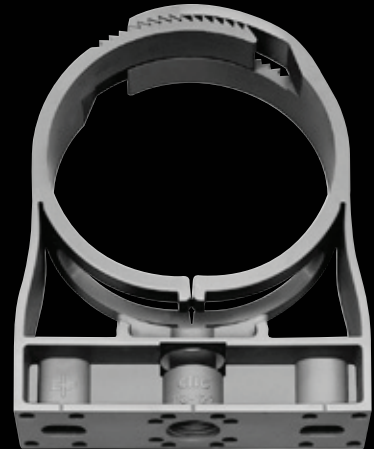

TECHNICAL INFORMATION

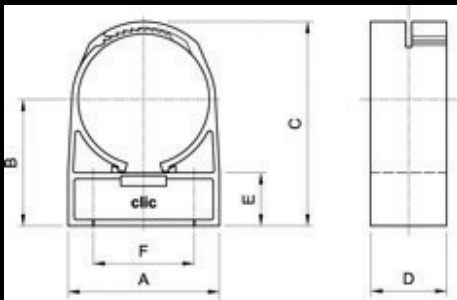

CLIC 63-127

- High-quality Polyamide
- Easy and excellent fixing for pipes with o.d. 63 mm - 127 mm
- Ideal for infrastructural and industrial buildings
- Secure against vibration through patented closing mechanism
- Temperature range up to +110 °C
- Mounting temperature up to -20 °C

TYPE	A INCH	B INCH	C INCH	D INCH	E INCH	F INCH	BREAKING LOADS F_y N	BREAKING LOADS F_x N
63	3.071	2.835	4.528	1.575	1.222	2.047	1800	1000
71	3.425	3.031	4.882	1.575	1.222	2.283	2200	1300
80	3.858	3.268	5.354	1.575	1.222	2.598	2600	1600
90	4.331	3.504	5.827	1.575	1.222	2.992	3000	1900
101	4.882	3.780	6.417	1.575	1.222	3.386	3500	2200
113	5.472	4.134	7.087	1.575	1.222	4.016	4000	2500

Breaking loads with 2 screws DIN 571 at + 20 °C