

FEATURES & SPECIFICATIONS

INTENDED USE

For use with housings LP6.

CONSTRUCTION

Aluminum one piece reflector.

Polyester powder coat paint.

Metal baffles available in black or white.

Metal cones available in clear and black specular finishes.

30 degree vertical tilt standard.

350 degree horizontal rotation.

White integral flange as standard.

INSTALLATION

Socket to trim interface.

Rough-in with clips retain trim.

LISTING

U.L. Listed to U.S. and Canadian safety standards.


Damp location listed.

Catalog Number	
Notes	Type

6" Finishing Trim

6AB/C2

PREMIUM ADJUSTABLE
Narrow Flange

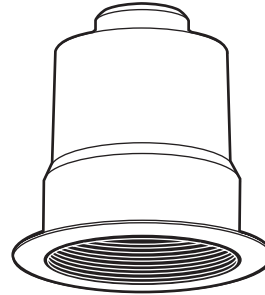


Specifications

Height: 7-3/4 (19.7)

Lamp opening: 6 (15.2)

Diameter: 7-5/8 (19.4)

Trim height when used with
Non-IC incandescent rough-ins.

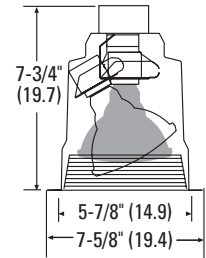

All dimensions are inches (centimeters).

ORDERING INFORMATION

Lead times will vary depending on options selected. Consult with your sales representative.

Example: **6AB2**

Series

6AB2 Black baffle
6AB2W White baffle
6AC2AZ Clear specular cone
6AC2BLZ Black specular cone

Options

TRBL Black integral flange ring

Housing Compatibility

Housing and trim ordered separately.

Application	Source	Maximum wattage	Housing
Non-IC	Incandescent	150 PAR38	LP6

6AB2/C2 6" Adjustable Full Reflector Trim

For photometric data consult factory.

