

Catalog Number	
Notes	Type

FEATURES & SPECIFICATIONS

INTENDED USE

For use with housings L3 and L3R.

CONSTRUCTION

Antique bronze, oil-rubbed bronze, brushed nickel, white and black finishes are one piece aluminum open reflectors with integral flange.

INSTALLATION

Socket to trim interface.


Retaining clips pull and snap onto top of reflector to hold trim inside housing.

LISTING

U.L. Listed to U.S. and Canadian safety standards.

Damp location listed.

Pull on clip Patent # (U.S.) 5707143, (Canada) 2193902.

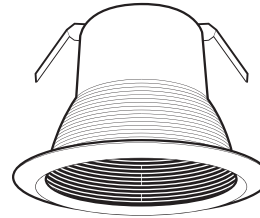

3" Finishing Trim

3B1


BAFFLE SHALLOW
Narrow Flange

Specifications

Height: 4-3/4 (12.1)

Lamp opening: 3-1/2 (8.9)

Diameter: 4-7/8 (12.4)

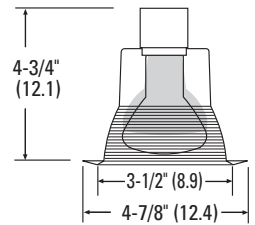

All dimensions are inches (centimeters).

ORDERING INFORMATION

For shortest lead times, configure product using **standard options (shown in bold)**.

Example: **3B1**

3B1	
Series	Finish
3B1	(blank) Black baffle W White baffle BN Brushed nickel baffle BZA Antique bronze baffle ORB Oil-rubbed bronze baffle

Housing Compatibility

Housing and trim ordered separately.

Application	Maximum Source	wattage	Housing
IC	Incandescent	35 PAR20 50 PAR20 ¹ 50 R20 ¹	L3, L3R
Non-IC	Incandescent	50 PAR20	L3, L3R

NOTES:

1 White baffle (3B1W) only.

3B1 3" Baffle Shallow Full Reflector Trim



An **Acuity** Brands Company

Sheet #: 3B1

©2000-2009 Acuity Brands Lighting, Inc. All rights reserved. Rev. 11/2/09

Lithonia Lighting
Recessed Downlighting
One Lithonia Way, Conyers, GA 30012
Phone: 800-315-4935 Fax: 770-918-1209
www.lithonia.com