

## FEATURES & SPECIFICATIONS

### INTENDED USE

Provides general illumination for outdoor spaces in residential and commercial applications.

### CONSTRUCTION

Dark bronze, die-cast aluminum housing with a prismatic polycarbonate lens door.

Mounting hardware included.

Operating temperature: -25°C (-13°F) to 35°C (95°F).

Lamp Type: 70W pulse-start metal halide lamp (included).

Lamp Output: 2564 lumens.

### OPTICS

Polycarbonate refractor.

Medium-base lamp included in carton.

### ELECTRICAL

Fixture is rated for 120V 60 Hz power supply.

Not suitable for use with dimmers, motion sensors or other remote devices.

### INSTALLATION

Intended for wall mount above 6ft (1,8m) only. Fixture must be at least 18" below any overhang or other structural detail.

Housing is configured for mounting directly over a standard 4" outlet box or for surface wiring via any of three convenient 3/4"-threaded conduit entry hubs.

### LISTING

UL- and CUL-Listed to US and Canadian safety standards. Suitable for wet locations.

### WARRANTY

1-year limited warranty (excludes lamp).

Note: All specifications subject to change without notice.

Catalog Number
Notes
Type

### Outdoor General Purpose

# OWPC

70W METAL HALIDE  
WALL PACK CUBE




### Specifications

Height: 9-1/2 (24.2)

Width: 8-3/4 (22.2)

Depth: 7-13/16 (19.9)

Weight: 7.6 lbs (3.46kg)

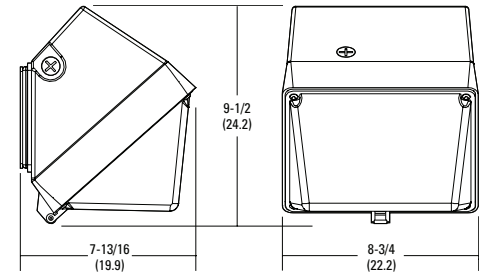

All dimensions shown in inches (centimeters) unless otherwise noted.

### ORDERING INFORMATION

Example: OWPC 70M 120 LP DDB

OWPC	70M	120	LP	DDB
Series	Wattage	Voltage	Lamp	Finish
<b>OWPC</b> Outdoor wall pack cube, lamp included	<b>70M</b> 70-Watt Metal Halide	<b>120</b> 120-Volt magnetic ballast	<b>LP</b> Lamp included	<b>DDB</b> Dark Bronze

