

All-Purpose Undercabinet Lights

UC8



Intended Use

For undercabinet or display lighting where a compact luminaire design is required.

Features

Low profile design with on/off switch. Available in four lengths. All mounting hardware included. Rugged powder coated steel housing. Separate, hingeable service tray for easy installation and maintenance. Milk white acrylic diffuser provides soft widespread illumination with zip-lock for easy lamp replacement and superior retention.

T8 electronic ballast (120V, 60Hz) as standard.

Approved for residential use, ensures no flickering and quiet operation without interfering with home electronics.

Utilizes T8 lamps for energy efficiency, superior color rendering and long life. Not included.

Listings

Standard fixtures are UL Listed to US and Canadian safety standards.

Ordering Information

Series	Lamp number & type ¹
UC8	15 15W T8 (18")
	24 17W T8 (24")
	36 25W T8 (36")
	48 32W T8 (48")

Voltage
120 Standard 120V electronic T8 ballast

Switch
SWR Standard on/off switch

Options
Consultfactory.

Example: **UC8 15 120 SWR**

Availability and Dimensions


Nominal length	Model number	Number of lamps ¹	Length in. (cm)	Width in. (cm)	Depth in. (cm)
18"	UC8 15 120 SWR	(1) 15W T8	18 5/16 (46.5)	4 (10.2)	1 3/8 (3.5)
24"	UC8 17 120 SWR	(1) 17W T8	24 5/16 (61.8)	4 (10.2)	1 3/8 (3.5)
36"	UC8 25 120 SWR	(1) 25W T8	36 5/16 (92.2)	4 (10.2)	1 3/8 (3.5)
48"	UC8 32 120 SWR	(1) 32W T8	48 5/16 (122.7)	4 (10.2)	1 3/8 (3.5)

NOTES:

¹ Lamps not included.

Twin Task Lights

TTL

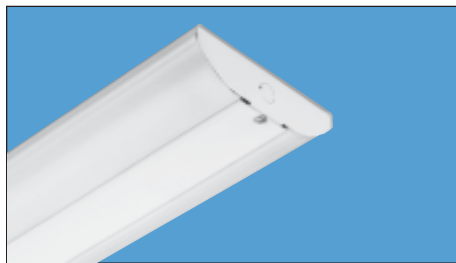

Intended Use

Task lighting for under cabinets where a compact luminaire design is required.

Features

Low profile design with on/off switch. Available in two lengths. All mounting hardware included. Rugged powder coated steel housing. Milk white acrylic diffusers provide soft widespread illumination with zip-lock for easy lamp replacement and superior retention.

T5 electronic ballast (120V, 60Hz) as standard. Approved for residential use, ensures no flickering and quiet operation without interfering with home electronics.

Utilizes T5 lamps for energy efficiency, superior color rendering and long life. Not included.

Listings

UL Listed to US and Canadian safety standards.

Ordering Information

Series	Lamp number & type ¹
TTL	2 8W 8W T5 (12 1/2")
	2 13W 17W T5 (21 1/2")

Voltage
120 Standard 120V electronic T8 ballast

Options
Consultfactory.

Example: **TTL 2 8W 120**

Availability and Dimensions

Nominal length	Model number	Number of lamps ¹	Width in. (cm)	Depth in. (cm)	Length in. (cm)
12"	TTL 2 8W 120	(1) 8W T5	4 5/8 (11.7)	1 1/2 (3.2)	12 1/2 (31.8)
21"	TTL 2 13W 120	(1) 13W T5	4 5/8 (11.7)	1 1/2 (3.2)	21 1/2 (54.6)

NOTES:

¹ Lamps not included.