

Catalog Number
Notes
Type

FEATURES & SPECIFICATIONS

INTENDED USE

Utility wall-, ceiling- or pendant-mounted fixtures for entrances, hallways, closets, tunnels or other utility applications. Incandescent, fluorescent, metal halide or high pressure sodium sources are available.

CONSTRUCTION

Rugged die-cast aluminum housing with heavy-duty glass globe. 3/4" threaded knockouts allow for side or top conduit entry. Gray finish.

Designed for easy installation and maintenance.

Prismatic globe for even distribution.

Junction box included.

LISTINGS

Listed and labeled to UL standards for wet locations.

Listed and labeled to CSA standards.

WARRANTY

Fixtures are covered by Lithonia Lighting 24-month warranty against mechanical defects in manufacture.

Note: Specifications subject to change without notice.

Contractor Select

Utility Vapor Tights



VC



VP



VW

ORDERING INFORMATION

Catalog Number	UPC	Description	Lamp Wattage	Source	Lamp Voltage	Lamp Included	Pallet (lbs)	Standard Carton Qty	Qty
VC150I M12	745973817704	Ceiling mount	150	Incandescent	120	N	2	288	12
VP150I M12	745973817698	Pendant mount	150	Incandescent	120	N	2	288	12
VW150I M12	745973817681	Wall mount	150	Incandescent	120	N	2	192	12
VC300I M6	745973817674	Ceiling mount	300	Incandescent	120	N	2	144	6
VP300I M6	745973817667	Pendant mount	300	Incandescent	120	N	2	144	6
VW300I M6	745973817643	Wall mount	300	Incandescent	120	N	2	72	6
VC42L M6	745973817773	Ceiling mount	42	CFL	120	Y	6	48	6
VP42L M6	745973817759	Pendant mount	42	CFL	120	Y	6	72	6
VW42L M6	745973817711	Wall mount	42	CFL	120	Y	6	36	6
VC100ML M6	745973817841	Ceiling mount	100	MH	120	Y	9	48	6
VP100ML M6	745973817834	Pendant mount	100	MH	120	Y	8	72	6
VW100ML M6	745973817827	Wall mount	100	MH	120	Y	10	36	6
VC150SL M6	745973817810	Ceiling mount	150	HPS	120	Y	9	48	6
VP150SL M6	745973817803	Pendant mount	150	HPS	120	Y	8	72	6
VW150SL M6	745973817780	Wall mount	150	HPS	120	Y	10	36	6

Utility Vapor Tights

Ceiling



VC150I

Height: 9 (22.9)
Width: 4-1/2 (11.4)

VC300I

Height: 11-3/8 (28.9)
Width: 5-3/4 (14.6)

VC42L, VC150SL & VC100ML

Height: 14-7/8 (37.8)
Width: 7 (17.8)

Pendant



VP150I

Height: 9-7/8 (25.1)
Width: 4-1/2 (11.4)


VP300I

Height: 12-1/8 (30.8)
Width: 5-3/4 (14.6)

VP42L, VP150SL & VP100ML

Height: 13-1/4 (33.7)
Width: 7 (17.8)

Wall

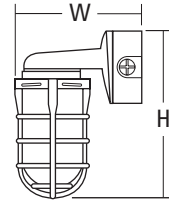

VW150I

Height: 10 (25.4)
Width: 7-1/4 (18.4)

VW300I

Height: 11-7/8 (30.1)
Width: 8-3/4 (22.2)

VW42L, VW150SL & VW100ML

Height: 15-1/2 (39.4)
Width: 8-3/4 (22.2)