

Catalog Number
Notes
Type

FEATURES & SPECIFICATIONS

INTENDED USE

Provides maintenance-free general and security illumination for outdoor use in residential and light commercial applications. Ideal illumination for walkways, yards, patios, play areas and driveways creating an inviting exterior space as well as providing safety and security.

CONSTRUCTION

Three tool-free adjustable heads allow for easy aiming up/down or side to side. Rugged cast aluminum, corrosion-resistant housing in bronze or white. Clear acrylic lenses are fully gasketed to keep out moisture, dirt and bugs.

Each head contains (3) 5700K* high performance LEDs which maintain a total of 1,636 lumen output at 50,000 hour life. LED driver is 120V and operates at 60Hz.

Dusk-to-dawn photocell automatically turns light on at dusk and off at dawn for convenience and energy savings.

* Nominal correlated color temperature per ANSI C78-377-2008.

INSTALLATION

Wall or eave mount.

All mounting hardware included.

LISTINGS

UL/C-UL Certified to US and Canadian safety standards. Wet location listed.

WARRANTY

Five-year limited warranty. Full warranty terms located at

www.acuitybrands.com/CustomerResources/Terms_and_conditions.aspx.

Outdoor General Purpose


Dusk-to-Dawn LED Floodlight 3 Adjustable Heads

High Performance LED



Dimensions

All dimensions are inches (centimeters)

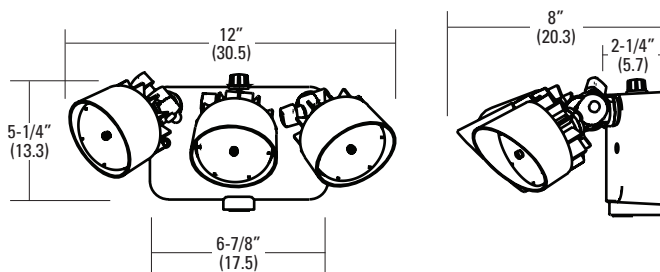

ORDERING INFORMATION

For shortest lead times, configure products using **bolded options**.

Example: OFLR 9LC 120 P BZ

OFLR		9LC		120		P			
Series		No. of LEDs		Ballast/Voltage		Features		Finish	
OFLR	LED Floodlight	9LC	9 LEDs, 3 heads	120	120V residential electronic ballast	P	Dusk-to-dawn photocell	BZ	Bronze
								WH	White

3-Head LED Floodlight with Photocell

PHOTOMETRICS

Full photometric data report available within 2 weeks from request. Consult factory.

