

WSL1F

Wet Location



Intended Use
Rated Non-IC for new construction in indoor applications or outdoor wet locations, such as courtyards and pathways.

Construction
Mechanical: Aluminum die-cast, white powder coat paint, corrosion-resistant

housing. Louvered, slotted, and open faceplates available. Die-cast powder coat painted faceplates are available in white or black finish. Faceplates are shipped separately.

Electrical
13DTTE, instant-start electronic ballast standard

(120V or 277V). One electrical conduit fitting and one plug provided. Electrical conduit fitting for wet location in wood construction, masonry and poured concrete applications.

Listings
UL Listed to U.S. and Canadian safety standards.

ORDERING INFORMATION

For shortest lead times, configure products using **bolded options**.


Example: WSL1F 13DTTE FPLBL 120

Series	Lamp type	Finish	Voltage
WSL1F	13DTTE	FPL White louvered faceplate FPLBL Black louvered faceplate FPS White slotted faceplate FPSBL Black slotted faceplate FPO White, opal lens FPOBL Black, opal lens	120 277

ADDITIONAL INFORMATION

For additional product information, visit www.lithonia.com.

Drawings are for dimensional detail only and may not represent actual mechanical configuration. Dimensions are shown in inches (centimeters) unless otherwise noted.

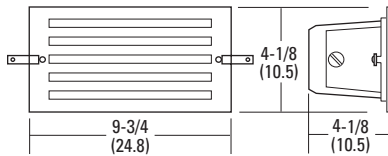

PRODUCT INFORMATION

STEPLIGHTS

Damp Location



Intended Use
Rated IC or Non-IC. For new construction only. To direct light on steps or pathways. Wall or step riser mounting.

Construction
Approved for through-branch circuit wiring. Galvanized steel housing and wiring compartment with a ground

wire. Bar hangers span 16" with recessed integral nailer tabs. Powder-coated steel louver available in white or black finish. Butterfly springs hold louver securely in place. Die-cut foam gasket seals steel louver against surface, preventing light leaks.

Electrical
Encased and potted NPF (normal power factor) 120V electromagnetic ballast. Durable two-pin positive latch thermoplastic socket. 13W DTT. Thermally protected.

Listings
UL Listed to U.S. and Canadian safety standards.



ORDERING INFORMATION

For shortest lead times, configure products using **bolded options**.

Example: SL1F 13DTT BL


Series	Lamp type	Finish
Incandescent SL1	Incandescent ¹ (blank) Incandescent	(blank) White BL Black
Fluorescent SL1F	Fluorescent 13DTT	

ADDITIONAL INFORMATION

For additional product information, visit www.lithonia.com.

IC/NON-IC RATED - THESE STEPLIGHTS ARE DAMP LOCATION LISTED. MAXIMUM WATTAGE AND LAMPS ARE LISTED.	
INCANDESCENT	FLUORESCENT
25 A19 (IC)	13DTT (IC)
40 A19 (Non-IC)	

Drawings are for dimensional detail only and may not represent actual mechanical configuration. Dimensions are shown in inches (centimeters) unless otherwise noted.

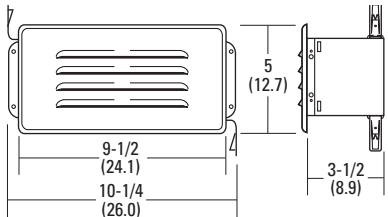

Notes

¹ Leave lamp type information blank.