

GRX-PCBL-346S Cable


Plenum rated cable for use with the following Lutron systems:

- GRAFIK Eye® 3000
- GRAFIK Eye® QS
- Energi Savr Node™

- Plenum rated for use in ceilings and enclosures that are also used by the building air distribution system to transport environmental air.

Specifications

- Listed as type CL3P (Class 3 Plenum Cable) or CMP cULus.
- Available in 500 ft (150 m) spool.
- Five conductors:
 - Common – 18 AWG (0.75 mm²)
 - Power – 18 AWG (0.75 mm²)
 - MUX Data – 22 AWG (0.25 mm²)
 - MUX Data – 22 AWG (0.25 mm²) } Twisted wire pair
 - Drain Wire – 24 AWG (0.2 mm²)
- Total Outer Jacket Diameter: 0.17 in (4.37 mm).
- 300 V Rated.
- Plenum sheath, 75 °C rated.
- UL Listed.
- Rated FT6.
- cULus or CSA Listed.
- Capacitance of 22 AWG (0.25 mm²) Twisted Wire Pair:
 - Conductor to shield: 48 pf/ft max
 - Conductor to Conductor: 25 pf/ft max

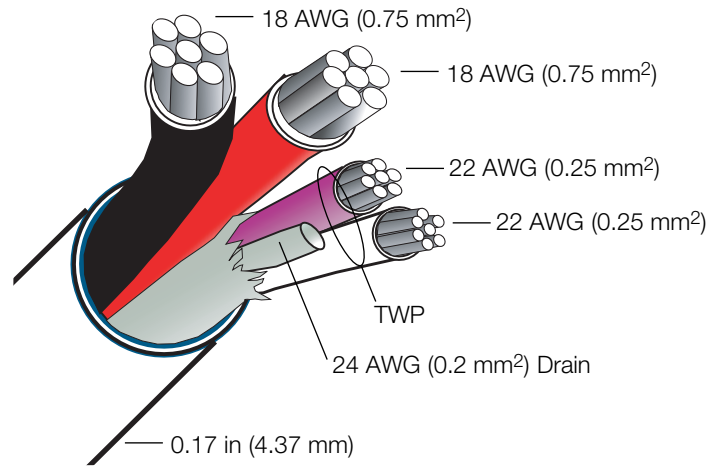

* Please refer to the Product Specification Submittal Sheets or Product Installation Guides for control link wiring distance maximums and other limitations.

Job Name:	Model Numbers:
Job Number:	