

# HID Temporary Lighting

## Designed and Packaged for Quick Installation

### Applications

- More and more contractors are using temporary HID fixtures to light their work sites. Instead of modifying Low-Bay fixtures for this application, McGill's HID Temporary Lighting allows them to buy something faster and easier.

### Features

- 400 W Pulse Start Metal Halide lamp provides over 6 foot candles of illumination at a 20 ft./6.1 meter mounting height.
- McGill offers lighting layouts to conform with OSHA requirements for light output.
- Type "O" lamp and mogul socket complies with NEC 2008 Section 410.130(F)(5) and ANSI C78.387.
- Quick-attach durable 10"/254 mm welded wire guard mounts directly to the body to protect lamp and lampholder from accidental impact.
- Fixture is factory wired at 120 Volt, but can be rewired internally for other voltage settings.
- 3'/0.9 m cord with 5-15P molded plug on end.
- Compact size for easy handling.
- Low-profile fixture design keeps it up and out of the way of activity below.
- High light output and long lamp life.
- Open-air ballast for cooler operation.
- Hook with locking feature.
- (2) 3/4"/19.1 mm knock-outs for conduit access.
- Single durable package design makes it easier for distributors to stock and more organized for contractors on the job site.
- Quick and easy to assemble.
- Optional bottom trap available.

### Standard Materials

- Enclosure: Heavy-duty steel with powder coated finish
- Lamp: 400 Watt Pulse Start Metal Halide: O-Type, BT37 Clear, EX39 (Exclusionary Mogul Base)
- Multi-Tap ballast: 120, 208, 240, 277 Volt: Factory wired at 120 Volt
- Power cord: 3 FT/0.9 M, 18/3 SJTW, 120 Volt, 15 Amp cord complete with NEMA 5-15 molded plug
- Lamp guard: 11 ga. white painted steel
- Mounting hook: 11 ga. steel

### Certifications and Compliances

- UL and cUL Listed: E196293
- UL Standard: UL 1598
- Suitable for damp locations


### Options

- Optional bottom trap available




Shown with optional bottom trap

### Illustrated Feature

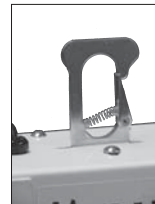

Spring-lock hook allows contractors to mount the unit in seconds, without the need for tools.

### Dimensions in Inches/Millimeters

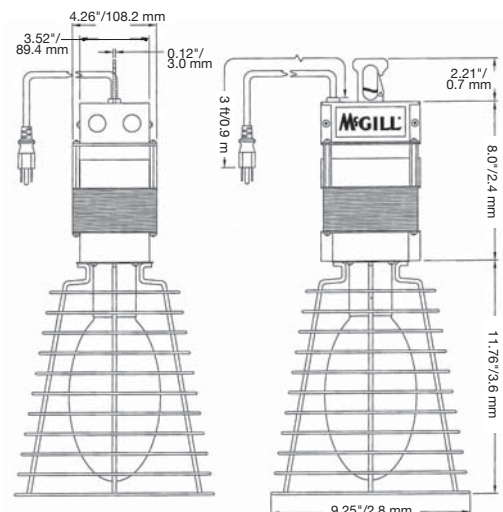

	Catalog Number
400 W Fixture with Guard	TL40PMTO
Bottom Guard Trap	TLTRAPW
Replacement Lamp Guard	TLGUARDW
Replacement Lamp: 400 W PSMH, O-Type, BT37 Clear, EX39	GMP400BUPS