



**400 AMP MAX
320 AMP CONTINUOUS**

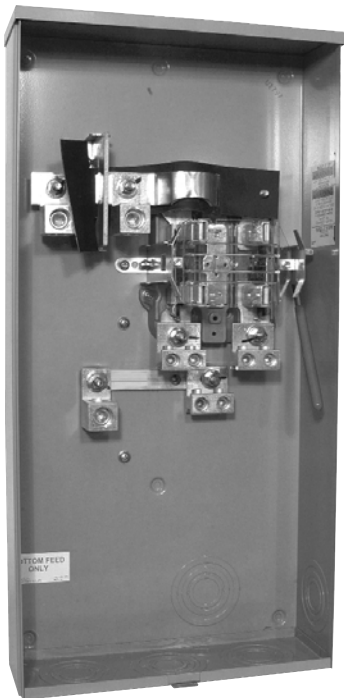

U1797-O-K3L-K2L

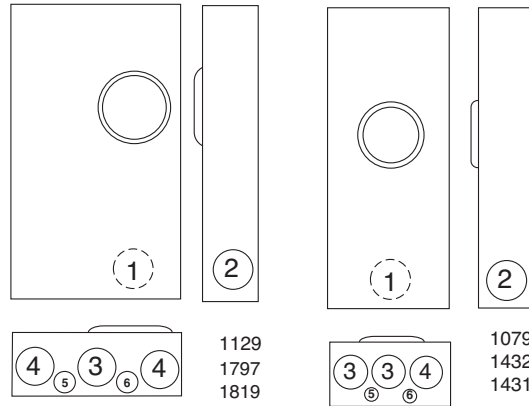

U1129-O-K3L-K2L

320 AMP—4 TERMINAL—RINGLESS—600 VAC

AMP	SVC.	CATALOG NUMBER	FIFTH TERM.	HUB	CONNECTORS CU/AL		BY-PASS	DIMENSIONS			CONCENTRIC K.O.'S					
					LINE	LOAD		D"	W"	H"	1	2	3	4	5	6
320	OH	U1079-R	K3866	H.O.	3/8"-16 STUDS		LEVER	4 7/8	13	38 3/4	3	2 1/2	3	3	1/4	1/4, 1/2
320	UG	U1129-O-K3L-K2L	K3865	BLANK	#4-600 or (2) 1/0-250	TWIN #6-350	LEVER	4 7/8	15	30	3	2 1/2	3	3	1/4	1/4, 1/2
320	OH/UG	U1431-R*	K3866	H.O.	3/8"-16 STUDS		NONE	4 7/8	13	38 3/4	3	2 1/2	3	3	1/4	1/4, 1/2
320	UG	U1432-O*	K3865	BLANK	3/8"-16 STUDS		NONE	4 7/8	13	29 3/4	3	2 1/2	3	3	1/4	1/4, 1/2
320	UG	U1819-X*	K3865	C.P.	3/8"-16 STUDS		NONE	4 7/8	15	30	3	3	3	3	1/4	1/4, 1/2
320	UG	U1797-O-K3L-K2L	K3865	BLANK	#4-600 or (2) 1/0-250	TWIN #6-350	LEVER	4 7/8	15	30	3	3	3	3	1/4	1/4, 1/2

HUBS: For proper hub selection, see hub suffix chart in accessories page.

BY-PASS: *Lever supplies clamping action on meter spades only on the **U1431, U1432** and **U1819**. Lever supplies clamping action and also operates bypass device on the **U1079, U1129** & **U1797**.

CONNECTOR KITS: Stud type units are supplied with 3/8"-16 hex head nuts with Belleville washers. Order two connector kits to cover both line and load. Order **K1539** (single #350), **K1540** (single #600) or **K1350** (twin #350). See accessories page.

NOTE: The **U1129** unit has a single connector on the line side only.

FIFTH TERMINAL: For field mounted fifth terminal, order as extra **K3866** for the **U1079** & **U1431**. Order as extra **K3865** for units **U1129, U1432, U1819**, and **U1797**.

LUG SIZE RANGE: See accessories page for lug size range for the **U1129** & **U1797** units.

Utility requirements for this equipment may vary. Always consult the serving utility for their requirements before ordering or installing equipment in this catalog.

