


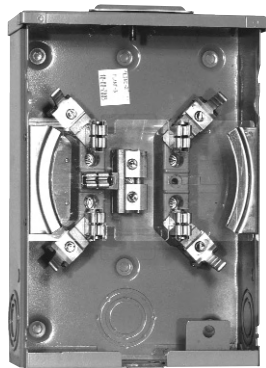

U7021-RL-TG-KK-DLC




U8569-XL-KK-BLG



U7487-RL-TG-KK



U7040-XL-TG-KK

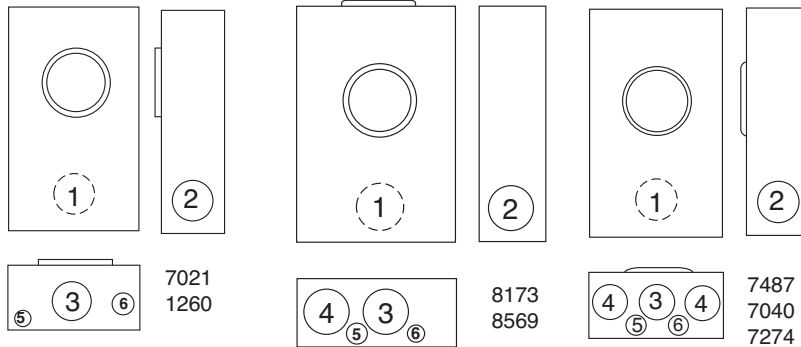
**125 & 200 AMP-SINGLE POSITION-4 & 5 TERMINAL-RINGLESS-1Ø3W**

UTIL. APRVL	NO. OF TERMS	AMP	SERVICE	CATALOG NUMBER	HUB	CONNECTORS CU/AL	BY-PASS	DIMENSIONS			CONCENTRIC K.O.'S					
								D"	W"	H"	1	2	3	4	5	6
ALLEG-DUQ	4	125	OH/UG	<b>U7274-YL-KK</b>	1 1/4"	#6 - 2/0	HORN	3 5/16	8	11 1/2	1 1/2	1 1/2	2	1 1/4	-	1/4
ALLEG	4	125	OH/UG	<b>U7487-RL-TG-KK</b>	H.O.	#6 - 2/0	HORN	3 5/16	8	11 1/2	1 1/2	1 1/2	2	1 1/4	-	1/4
ALLEG-GPU-PPL	4	125	OH/UG	<b>U7487-RL-TG-KK-BLG*</b>	H.O.	#6 - 2/0	HORN	3 5/16	8	11 1/2	1 1/2	1 1/2	2	1 1/4	-	1/4
ALLEG	4	125	OH/UG	<b>U7487-YL-TG-KK-BLG*</b>	1 1/4"	#6 - 2/0	HORN	3 5/16	8	11 1/2	1 1/2	1 1/2	2	1 1/4	-	1/4
ALLEG-PECO	4	125	OH/UG	<b>U7487-RL-KK-BL**</b>	H.O.	#6 - 2/0	HORN	3 5/16	8	11 1/2	1 1/2	1 1/2	2	1 1/4	-	1/4
PSEG	5	125	OH/UG	<b>U8569-YL-KK-BLG*Ⓛ</b>	1 1/4"	#6 - 2/0	HORN	3 5/16	8	11 1/2	1 1/2	1 1/2	1 1/2	1 1/2	-	1/4
PSEG	5	200	OH/UG	<b>U8173-XL-KK-BLG*Ⓛ</b>	C.P.	#6-350 kcmil	HORN	4 1/8	11	15 1/2	2 1/2	2 1/2	2 1/2	2 1/2	1/4, 1/2	1/4
ALLEG-PECO	4	200	OH	<b>U7021-RL-KK-BL**</b>	H.O.	#6-350 kcmil	HORN	4 1/8	8	15 1/2	2 1/2	2 1/2	2 1/2	-	1/4	1/4, 1/2
DUQ	4	200	OH	<b>U7021-RL-KK-DLC</b>	H.O.	#6-350 kcmil	HORN	4 1/8	8	15 1/2	2 1/2	2 1/2	2 1/2	-	1/4	1/4, 1/2
ALLEG-GPU-PPL	4	200	OH	<b>U7021-RL-TG-KK-BLG*</b>	H.O.	#6-350 kcmil	HORN	4 1/8	8	15 1/2	2 1/2	2 1/2	2 1/2	-	1/4	1/4, 1/2
ALLEG	4	200	OH/UG	<b>U7040-XL-TG-KK</b>	C.P.	#6-350 kcmil	HORN	4 1/8	11	15 1/2	2 1/2	2 1/2	2 1/2	2 1/2	1/4, 1/2	1/4
CON	4	200	OH	<b>U7040-RL-KK-DPL</b>	H.O.	#6-350 kcmil	HORN	4 1/8	11	15 1/2	2 1/2	2 1/2	2 1/2	2 1/2	1/4, 1/2	1/4
PSEG	5	200	OH	<b>U1260-RL-TG-KK-BLG*</b>	H.O.	#6-350 kcmil	HORN	4 1/8	8	15 1/2	2 1/2	2 1/2	2 1/2	-	1/4	1/4, 1/2

**FIFTH TERMINAL:** For field mounted fifth terminal: Order catalog number **K5T** to fit into square opening at the 9 o'clock position of the *new style block* (#6-350 kcmil.) Order catalog number **5T8K2** to fit into round opening at the 9 o'clock position of the *old style block* (#6-2/0 kcmil.)

**HUBS:** For proper hub selection see the hub suffix chart on the accessory page.

**CONNECTORS:** Extruded aluminum connectors are tin plated.

**BYPASS:** Units provided with horn type bypass (suffix **-KK**).

\* Barrel lock with guard provision (suffix **-BLG**).

\*\* Barrel lock (suffix **-BL**).

Ⓛ Lexan® safety shield provided.

*Utility requirements for this equipment may vary. Always consult the serving utility for their requirements before ordering or installing equipment in this catalog.*

CATALOG NO.	UPC	DESCRIPTION	PAGE
<b>SINGLE POSITION METERING</b>			
<b>125-200 amp-4, 5 &amp; 7 Terminal-Ringless-600 VAC</b>			
U7487-RL-TG-KK	14119	125A 4T RL OU	5
U7487-RL-TG-KK-BLG	24177	125A 4T RL OU	5
U7487-YL-TG-KK-BLG	24178	125A 4T RL OU	5
U7487-RL-KK-BL	14114	125A 4T RL OU	5
U7274-YL-KK	14054	125A 4T RL OU DLCO S	5
U8569-YL-KK-BLG	28668	125A 5T RL OU 1WAYHUB	5
U7021-RL-KK-BL	13991	200A 4T RL OH	5
U7021-RL-KK-DLC	13992	200A 4T RL OH	5
U7021-RL-TG-KK-BLG	24176	200A 4T RL OH	5
U7040-XL-TG-KK	14039	200A 4T RL OU	5
U7040-RL-KK-DPL	37108	200A 4T RL OU	5
U1260-RL-TG-KK-BLG	22331	200A 5T RL OH	5
U8173-XL-KK-BLG	21703	200A 5T RL OU	5
U1980-O-KK-BL	19247	200A 4T RL SWY UG	6
U1980-O-KK-DPL	37109	200A 4T RL SWY UG	6
U3126-O-KK-BLG	24174	200A 4T RL SWY UG	6
U3126-O-KK-DLC	28007	200A 4T RL SWY UG	6
U4413-O-KK-BLG	24175	200A 4T RL SWY UG	6
U1276-RL-BLG	13394	125A 7T RL MD LVR OH	7
U1277-RXL-BLG	13395	125A 7T RL MD LVR OH	7
U9551-X-DPL	37115	200A 5T RL HD LVR OU	7
U9700-RRL-BLG	24194	200A 7T RL HD LVR OH	7
U9701-RRL	14336	200A 7T RL HD LVR OH	7
U9701-RRL-BLG	17649	200A 7T RL HD LVR OU	7
U7423-RXL	14100	200A 7T RL MD LVR OU	7
U4029-X-DPL	37114	200A 7T RL MD LVR OU	7
U1279-X-BLG	13397	200A 7T RL MD LVR OU	7
U3786-O-BLG	24650	200A 7T RL SWY MD LVR UG	7

<b>SINGLE POSITION METERING</b>			
<b>320-480 amp-4, 5 &amp; 7 Terminal-Ringless-600 VAC</b>			
U1729-X-DPL	37110	320A 4T RL HD LVR UG	8
U1779-R-K3-BLG	24594	320A 4T RL STUD HD LVR OU	8
U9399-X	13916	320A 4T RL SWY HD LVR UG	8
U1797-O-K3L-K2L	30172	320A 4T RL SWY HD LVR UG	8
U3000-O-2/K3L-BL	31840	320A 4T RL SWY HD LVR UG	8
U4912-X-K3-BLG	25525	320A 4T RL SWY STUD HD	8
U4168-X-K7-BLG	24475	320A 7T RL SWY HD LVR OU	8
U2120-O	17427	320A 7T RL SWY STUD HD	8
U4664-X-8522-DPL	27397	480A CONT/600A MAX 4T OU	9
U4667-X-8043-DPL	37116	480A CONT/600A MAX 7T OU	9

<b>MULTIPLE METERING</b>			
<b>100-200 amp/Position-4 &amp; 5 Terminal-Ringless-600 VAC</b>			
U8032-XL-KK-BLG	24179	100A 4T RL 2P CTR WY	10
U8032-XL-KK-BL	20952	100A 4T RL 2P CTR WY	10
U8033-XL-KK-BLG	24180	100A 4T RL 3P CTR WY	10
U8033-XL-KK-BL	20953	100A 4T RL 3P CTR WY	10
U8034-XL-KK-BLG	24181	100A 4T RL 4P CTR WY	10
U8034-XL-KK-BL	20954	100A 4T RL 4P CTR WY	10
U8035-XL-KK-BLG	24182	100A 4T RL 5P CTR WY	10
U8035-XL-KK-BL	20955	100A 4T RL 5P CTR WY	10
U8036-XL-KK-BLG	24183	100A 4T RL 6P CTR WY	10
U8036-XL-KK-BL	20956	100A 4T RL 6P CTR WY	10
U9312-XL-KK-DLC	15401	150A 4T RL 2P CTR WY	10
U9313-XL-KK-DLC	15402	150A 4T RL 3P CTR WY	10
U9314-XL-KK-DLC	15756	150A 4T RL 4P CTR WY	10
U8212-XL-KK-BLG	24184	100A 4T RL 2P END WY	11
U8213-XL-KK-BLG	24185	100A 4T RL 3P END WY	11
U8214-XL-KK-BLG	24186	100A 4T RL 4P END WY	11
U8215-XL-KK-BLG	24187	100A 4T RL 5P END WY	11
U8216-XL-KK-BLG	24188	100A 4T RL 6P END WY	11
U2692-XL-KK-BL	20979	100A 4T RL 2P VERT	12
U2693-XL-KK-BL	20978	100A 4T RL 3P VERT	12
U1252-X-KK-K3-BLG	24169	200A 4T RL 2P CTR WY	13
U1252-X-KK-K3-BL	27895	200A 4T RL 2P CTR WY	13
U1252-X-KK-K3-DPL	37111	200A 4T RL 2P CTR WY	13
U1253-X-KK-K3-BLG	24170	200A 4T RL 3P CTR WY	13
U1253-X-KK-K3-BL	21142	200A 4T RL 3P CTR WY	13
U1254-X-KK-K3-BLG	24171	200A 4T RL 4P CTR WY	13
U1254-X-KK-K3-BL	20982	200A 4T RL 4P CTR WY	13
U1254-X-KK-K3-DPL	37112	200A 4T RL 4P CTR WY	13
U1255-X-KK-K3-BLG	24172	200A 4T RL 5P CTR WY	13
U1255-X-KK-K3-BL	20983	200A 4T RL 5P CTR WY	13
U1256-X-KK-K3-BLG	24173	200A 4T RL 6P CTR WY	13
U1256-X-KK-K3-BL	20984	200A 4T RL 6P CTR WY	13
U1256-X-KK-K4-DPL	37113	200A 4T RL 6P CTR WY	13

<b>METER MAINS &amp; LOAD CENTERS</b>			
<b>100 &amp; 200 amp 4 Terminal-Ringless-600 VAC</b>			
U7375-RL-KK	14076	100A 4T RL OH MAIN	14
U7607-RL-200-KK	14170	200A 4T RL OU MAIN STMPD	14
U3798-O-150-KK	24271	200A 4T RL UG MAIN	14
U3798-O-200-KK	24272	200A 4T RL UG MAIN	14

<b>METER MAINS &amp; LOAD CENTERS, cont.</b>			
UAP5024-XL		200A 4T RL OU LOAD CTR	15
U5268-XTL-200	47554	200A 4T RL OU MAIN 20CRT	15
U5268-XTL-200-KK	47557	200A 4T RL OU MAIN 20CRT	15
U5168-XTL-200	47531	200A 4T RL OU MAIN 8CRT	15
U5168-XTL-200-KK	47535	200A 4T RL OU MAIN 8CRT	15
USE-22-200-MB	14663	200A OH UNMTR P/O W/200A	15

<b>METERED PEDESTALS &amp; ACCESSORIES</b>			
U5136-O	31837	200A RL MTR DB PED	17
U5136-O-100S	28976	200A RL MTR DB PED 100A	17
U5136-O-200S	27590	200A RL MTR DB PED 200A	17
U5137-O	31838	200A DBL RL DB PED	17
U5137-O-100S	28762	200A DBL RL DB PED 100A	17
U5137-O-200S	27591	200A DBL RL DB PED 200A	17
K3450	11389	TEL TV BRKT KIT FOR MOB	17
K5193	31941	PARA WIRE KIT	17
K5194	31942	SERIES WIRE KIT	17
K5400-1450	25890	REC&CB KIT 50A NEMA 14-50	17
K5400-520GR	25888	REC&CB KIT 20A GFI REC	17
K5400-BRIDGE-1POS	32020	RCPT BRIDGE KIT	17
K5400-BRIDGE-2POS	31926	RCPT BRIDGE KIT	17
K5400-TT30	25889	REC&CB KIT 30A NEMA TT30	17
K5415	25914	STABILIZER FOOT KIT	17

<b>CT CABINETS &amp; TRANSOCKETS</b>			
363612-CT3R-SP	19831	CT ENC TYP3R HINGED	18
484812-CT3R-SP	20269	CT ENC TYP3R HINGED	18
CE136	11206	20A 6T RL TS06-0205 PRWRD	19
S4244-X	28632	400A 13T RL 600V TS	18
U5095-O	31042	10X36X36 TRANS ENC	18

<b>DISCONNECTS</b>			
U3800	13902	60A NONFUS DISCNCT	19
U3801	13903	60A NONFUS DISCNCT	19
U3830	13904	30A FUSE DISCNCT	19
U3860	13905	60A FUSE DISCNCT	19
U3822-20GR	28282	60A NONFUS DISCNCT	20
U4881-O	36949	100A 4CRKT 3R MLO	20
U4881-O-50GB	26815	100A 4CRKT 3R W/2P 50A GFI	20
U4881-O-60GB	27930	100A 4CRKT 3R W/2P 60A GFI	20

<b>MISCELLANEOUS</b>			
<b>Milbank Accessories</b>			
5TBK2	10760	5TH TERM ADDY 100/200A SCKTS	22
6003	10761	GRAY PLASTIC CLS PLT	22
6116	10763	CLEAR PLASTIC CLS PLT	22
A7514-17	11039	1 IN HUB UNIT	22
A7518	11044	2 1/2 IN HUB UNIT	22
A7551	11046	STD CLS PLT	22
A8110	11047	3 IN HUB UNIT	22
A8111	11048	3 1/2 IN HUB UNIT	22
A8112	11049	4 IN HUB UNIT	22
A9064	12889	LG CLS PLT	22
CP-21	11208	METAL CLS PLT	22
K1350	11329	TWN LUG ASSY 350KCM 1P	22
K1350L	30387	TWN LUG ASSY 350KCM 1P LKG	22
K1539	11333	SGL LUG ASSY 350KCM 1P	22
K1540	11334	SGL LUG ASSY 600KCM 1P	22
K1540L	30394	SGL LUG ASSY 600KCM 1P LKG	22
K1541	11335	TWN LUG ASSY 600KCM 1P	22
K3082	11366	SGL LUG ASSY 350KCM 3P	22
K3083	11367	SGL LUG ASSY 600KCM 3P	22
K3441	11387	SGL LUG ASSY 600KCM 3P	22
K3442	11388	TWN LUG ASSY 350KCM 3P	22
K4977-INT	27436	100A CONN & SLIDE	22
K5022-INT	28141	100A ADD-ON CONN	22
K5T	21256	5T TERM ASSY	22
S8324	12819	HUB ADAPTR PLT	22
Z703916-AC	24044	CONN 1P 3/0-800KCM S/E	21
Z703917-AC	24724	CONN 2P 6-350KCM S/E	21
Z703918-AC	24045	CONN 2P 4-350KCM F/E	21
Z703919-AC	23511	CONN 2P 350KCM S/E	21
Z703921-AC	23984	CONN 1P 3/0-800KCM F/E	21
Z704693-AC	25111	CONN 2P 500KCM-2 S/E	21
Z704694-AC	24865	CONN 2P 4-500KCM F/E	21
Z705420-AC	24046	CONN 4P 6-350 KCM F/E	21
Z705456-AC	24047	CONN 2P 6-350KCM B/E	21
Z708145-AC	24048	CONN 3P 6-250KCM F/E	21

Utility Matrix	23
Other Milbank Products	24
Conduit and Ampacity Information	25
Energization of Electrical Equipment	26
Materials and Finishes	27