

Catalog Number Logic

U = UL Listed
S = Non-UL Listed
UAP = UL / Alum / Painted

TG = Triplex Ground
QG = Quadplex Ground

KK = Horn By-Pass Provision

Specific Utility Designation

Milbank Drawing Number

Barrel Lock

U7040-RL-TG-KK-5T9-BL-AUT

HUB OPENINGS / CLOSING PLATES				
O	Plain Top	WL	1"	For -RL Opening
RL	Small Hub Opening	YL	1¼"	For -RL Opening
R	Large Hub Opening	ZL	1½"	For -RL Opening
XL	Small Closing Plate	DL	2"	For -RL Opening
X	Large Closing Plate	EL	2½"	For -RL Opening
RXL	Large Hub Opening adapted to small Closing Plate.	F	3"	For -R Opening
		G	3½"	For -R Opening
RRL	Large Hub Opening adapted to small Hub Opening	H	4"	For -R Opening

Fifth Terminal Designation

- 5T6 installed at 6:00
- 5T9 installed at 9:00

Barrel Lock / Guard Provision

U2448-X-QG-5T9-K3-BLG-ARE


Milbank Drawing Number

TG = Triplex Ground
QG = Quadplex Ground

Specific Utility Designation

Lugs [1Ø or 3Ø – 350 or 600 kcmil]

- Single [K1, K3, K5, K7]
- Twin [K2, K4, K6, K8]

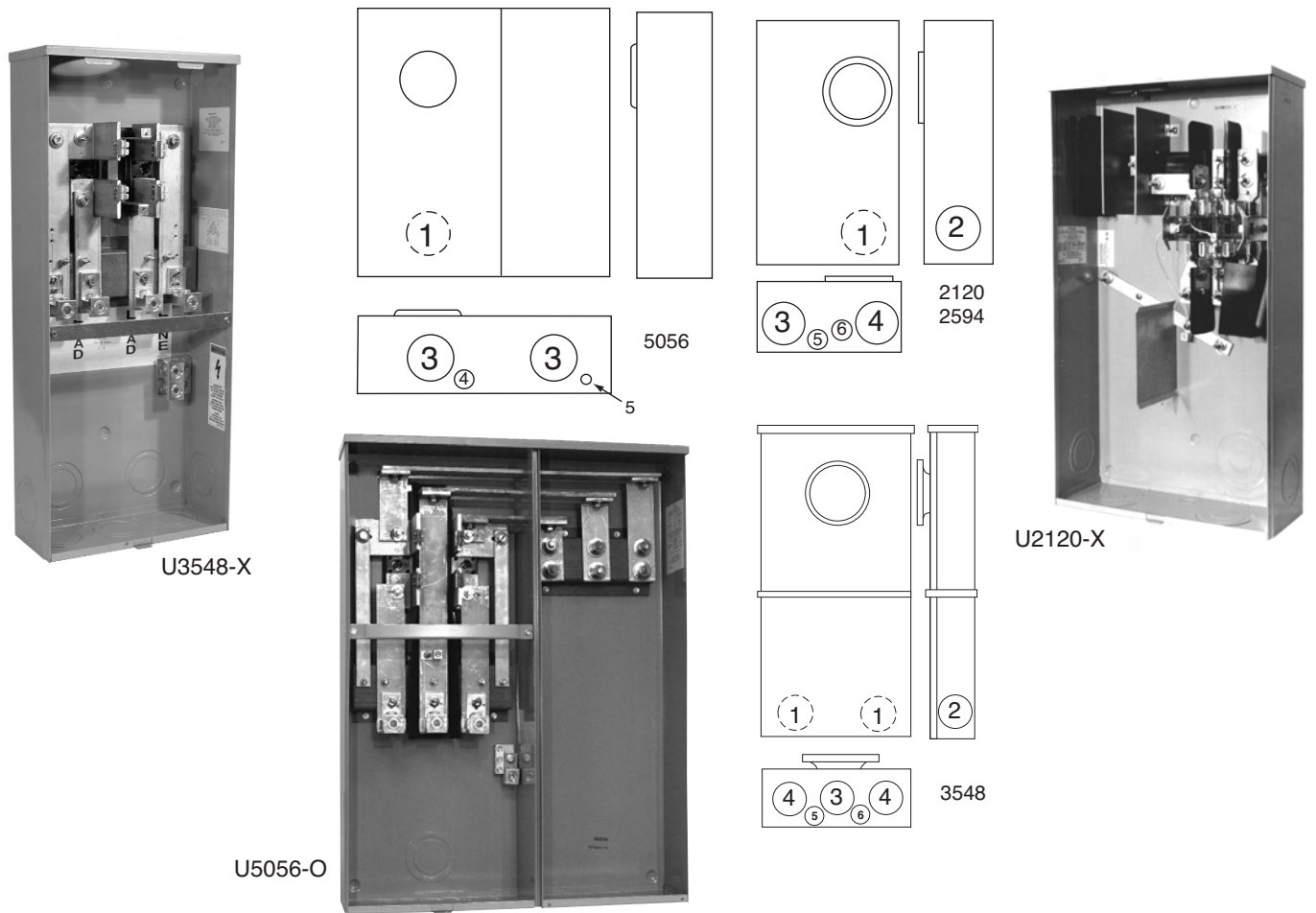

SECTION B
METER SOCKETS

320 AMP—4 TERMINAL—LINK BYPASS—RING TYPE—1Ø3W

SERVICE	CATALOG NUMBER	HUB	CONNECTORS CU/AL		BY-PASS	DIMENSIONS			CONCENTRIC K.O.'S					
			LINE	LOAD		D"	W"	H"	1	2	3	4	5	6
OH/ UG	U3548-X*	C.P.	SINGLE = 4-600 PARALLEL = 1/0-250		LINK	6	14	33	3	3	3	3	1/4	1/4, 1/2
UG	U5056-O**	BLANK	1/2"-13 STUDS	#4-600 or twin 1/0-250	LINK	6	24	32	3	—	4	1/4, 1/2	1/4	—

SEALING RING: Ring type units are supplied with an MR-4, screw type, sealing ring as standard.

TRIPLE TAP LUG: For triple tap lug kit order **K5049**.

LINK BYPASS: Links provided by utility.

***FLUSH MOUNT KIT:** For field mounted flush mount kit order **K4086**.

****This is a PP&L approved unit.**

320 AMP—7 TERMINAL—SIDE WIREWAY—RINGLESS

AMP	SERVICE	CATALOG NUMBER	HUB	CONNECTORS CU/AL	BY-PASS	DIMENSIONS			CONCENTRIC K.O.'S					
						D"	W"	H"	1	2	3	4	5	6
320	UG	U2120-X	C.P.	3/8"-16 STUDS	LEVER	6 1/2	17 3/4	31 3/4	4	3	4	4	1/4	1
320	OH/UG	U2594-X	C.P.	3/8"-16 STUDS	LEVER	6 1/2	19	34 1/8	—	3	4	4	1/4	1/2, 3/4, 1

BYPASS: Lever supplies clamping action on meter spades and operates bypass device.

CONNECTOR KITS: Stud type units are supplied with 3/8"-16 hex head nuts with Belleville washers. Order two connector kits to cover both line and load. For single lug connector kits for the **U2120** and **U2594** units, order as extra **K3082** (350 kcmil) or **K3441** (600 kcmil). For twin lug connectors order as extra: **K3442** (350 kcmil). Separate kits are required for both line and load.

Utility requirements for this equipment may vary. Always consult the serving utility for their requirements before ordering or installing equipment in this catalog.

