



Architectural Princess

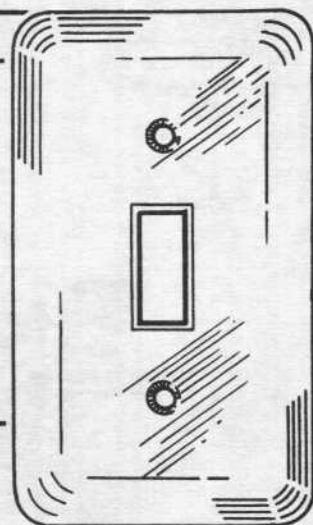













For color photos of finishes see inside back cover.

PRINCESS SHAPE

 listed 883C except where noted by asterisk(*).

See page A84 for ordering Custom Plates not found in this listing.

	STAINLESS TYPE 302 (.035") Spec. Grade Satin Finish U.S. #32D (302SS-PRL)	SATIN BRASS (.040") Satin Finish U.S. #4 (4BB-PRL)	ALUMINUM (.050") Clear Anodized U.S. #28 (5AA-PRL)	SATIN BRONZE (.040") Satin Finish U.S. #10 (4SBR-PRL)	STAINLESS TYPE 430 (.030") Satin Finish U.S. #32D (SS-PRL)	UN-FINISHED STEEL Zinc Coat (AUNF-PRL)
 1 Toggle Switch (1T)	53071	54071	55071	56071	57071	80071
 2 Toggle Switches (2T)	53072	54072	55072	56072	57072	80072
 3 Toggle Switches (3T)	53073	54073	55073	56073	57073	80073
 4 Toggle Switches (4T)	53074	54074	55074	56074	57074	80074
 5 Toggle Switches (5T)	53075	54075	55075	56075	57075	
 6 Toggle Switches (6T)	53076	54076	55076	56076	57076	
 1 Duplex Receptacle (10DR)	53101	54101	55101	56101	57101	80101
 2 Duplex Receptacles (20DR)	53102	54102	55102	56102	57102	80102
 3 Duplex Receptacles (30DR)	53103	54103	55103	56103	57103	
 4 Duplex Receptacles (40DR)	53104	54104	55104	56104	57104	
 5 Duplex Receptacles (50DR)	53105	54105	55105	56105	57105	
 6 Duplex Receptacles (60DR)	53106	54106	55106	56106	57106	