


















Commercial • Special Use

	GRAY SEMI- GLOSS	RED SEMI- GLOSS	BLACK MATTE	ALUMINUM PAINT	UNFINISHED STEEL
 Duplex Recept., 30A Range/Dryer Recept. (2.125" ID Hole) (10DR-3D)	58180	51180	87180	88180	89180
 Single Recept. (1.405" ID Hole) Blank (Box Mntg. 3.281") (10R-1B)	58552	51552	87552	88552	89552
 Block Duplex/GFI Recept., Blank (Box Mntg. 3.281") (SRM-1B)	58422	51422	87422	88422	89422
 Toggle Switch, Centered 2 Gang Plate (1T-2G)	58772	51772	87772	88772	89772
 Duplex Recept., Centered 2 Gang Plate (10DR-2G)	58773	51773	87773	88773	89773
 Single Recept. (1.405" ID Hole), Centered 2 Gang Plate (10R-2G)	58774	51774	87774	88774	89774
 5/8" ID Phone (Box Mntg. 3.281"), Centered 2 Gang Plate (01-2G)	58775	51775	87775	88775	89775
 2 Toggle Switches, Duplex Receptacle (2T-10DR)	58543	51543	87543	88543	89543
 2 Toggle Switches, Blank (Box Mntg. 3.281") (2T-1B)	58533	51533	87533	88533	89533
 2 Toggle Switches, Block Duplex/GFI Recept. (2T-SRM)	58443	51443	87443	88443	89443
 Toggle Switch, 2 Block Duplex/GFI Recepts. (1T-2SRM)	58453	51453	87453	88453	89453
 Toggle Switch, 2 Blanks (Box Mntg. 3.281") (1T-2B)	58133	51133	87133	88133	89133
 Toggle Switch, 2 Duplex Recepts. (1T-20DR)	58553	51553	87553	88553	89553
 Toggle Switch, Block Duplex; Duplex Recept. (1T-SRM-10DR)	58503	51503	87503	88503	89503
 Duplex Recept., 2 Blanks (Box Mntg. 3.281") (10DR-2B)	58423	51423	87423	88423	89423
 Blank (Box Mntg. 3.281"), Duplex Recept., Blank (Box Mntg. 3.281") (1B-10DR-1B)	58193	51193	87193	88193	89193

COLD ROLLED

Commercial Special Use

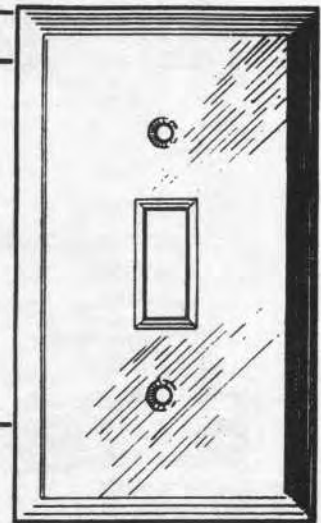













For color photos of finishes see inside front cover.


STANDARD SHAPE

listed 883C except where noted by asterisk(*)

See page A84 for ordering Custom Plates not found in this listing.

	GRAY SEMI-GLOSS Painted Steel	RED SEMI-GLOSS Painted Steel (RA)	BLACK MATTE Painted Steel (BL)	ALUMINUM PAINT Painted Steel (CDA)	UNFINISHED STEEL Zinc Coat (AUNF)
 1 Toggle Switch (1T)	58071	51071	87071	88071	89071
 2 Toggle Switches (2T)	58072	51072	87072	88072	89072
 3 Toggle Switches (3T)	58073	51073	87073	88073	89073
 4 Toggle Switches (4T)	58074	51074	87074	88074	89074
 5 Toggle Switches (5T)	58075	51075	87075	88075	89075
 6 Toggle Switches (6T)	58076	51076	87076	88076	89076
 7 Toggle Switches (7T)	58077	51077	87077	88077	89077
 8 Toggle Switches (8T)	58078	51078	87078	88078	89078
 9 Toggle Switches (9T)	58079	51079	87079	88079	89079
 10 Toggle Switches (10T)	58080	51080	87080	88080	89080
 1 Duplex Receptacle (10DR)	58101	51101	87101	88101	89101
 2 Duplex Receptacles (20DR)	58102	51102	87102	88102	89102



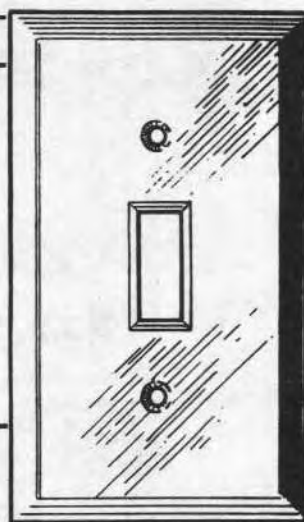





 



General Construction Finishes



For color photos of finishes see inside front cover.

STANDARD SHAPE

See page A84 for ordering Custom Plates not found in this listing.

	CHROME PLATED	WHITE SEMI-GLOSS	STAIN-LESS TYPE 302 (.035") Spec. Grade Satin Finish (302SS)	STAIN-LESS TYPE 430 (.030") Satin Finish (SS)	BROWN WRINKLE	IVORY WRINKLE
 1 Toggle Switch (1T)	Polished Steel (CA) 83071	Painted Steel (WA) 86071	893071	897071	898071	899071
 2 Toggle Switches (2T)	83072	86072	93072	97072	98072	99072
 3 Toggle Switches (3T)	83073	86073	93073	97073	98073	99073
 4 Toggle Switches (4T)	83074	86074	93074	97074	98074	99074
 5 Toggle Switches (5T)	83075	86075	93075	97075	98075	99075
 6 Toggle Switches (6T)	83076	86076	93076	97076	98076	99076
 7 Toggle Switches (7T)	83077	86077	93077	97077	98077	99077
 8 Toggle Switches (8T)	83078	86078	93078	97078	98078	99078
 9 Toggle Switches (9T)	83079	86079	93079	97079	98079	99079
 10 Toggle Switches (10T)	83080	86080	93080	97080	98080	99080
 1 Duplex Receptacle (10DR)	83101	86101	93101	97101	98101	99101
 2 Duplex Receptacles (20DR)	83102	86102	93102	97102	98102	99102