



Deep Plates

9/16"

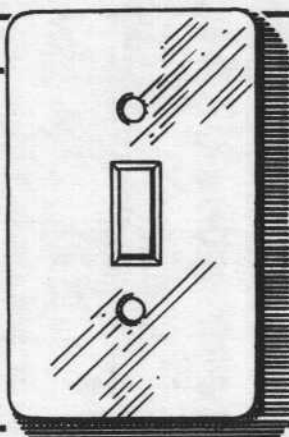

3/8"

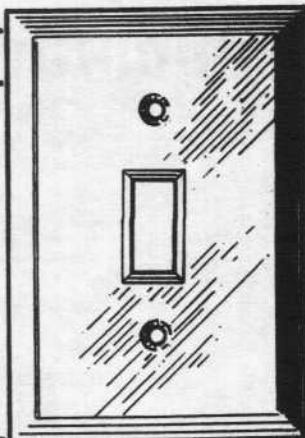


Ideal for use where box extends out from wall. Single gang only, no bevel, 90° return.

Ideal for use where box extends out from wall. Available 1-3 gangs only, in all finishes. All wiring devices can be used except interchangeable and block type receptacles.


Box mount (3.281") only.
Deep plates available
in GFI opening

9/16" Deep Plates

 1 Toggle Switch
(1T-GP)


 1 Duplex
Receptacle
(10DR-GP)


 1 Single Recept.
(1.405")
(10R-GP)


 1 Blank
(Box Mntg. 3.281")
(1B-GP)

3/8" Deep Plates

 1 Toggle Switch
(1T-NGP)


 2 Toggle Switches
(2T-NGP)


 3 Toggle Switches
(3T-NGP)

 1 Duplex
Receptacle
(10DR-NGP)

 2 Duplex
Receptacles
(20DR-NGP)












 


 1 Single Recept.
(1.405")
(10R-NGP)

 1 Blank
(Box Mntg. 3.281")
(1B-NGP)

 2 Blanks
(Box Mntg. 3.281")
(2B-NGP)

 Toggle Switch,
Duplex Recept.
(1T-10DR-NGP)

 2 Toggle Switches,
Duplex Receptacle
(2T-10DR-NGP)

	IVORY SEMI- GLOSS	WHITE WRINKLE	WHITE SEMI- GLOSS	SATIN BRASS (.040")	STAIN- LESS TYPE 430	BROWN WRINKLE	IVORY WRINKLE
	Painted Steel (IA)	Painted Steel (DW)	Painted Steel (WA)	Satin Finish US#4 (4BB)	Satin Finish US#32 (SS)	Painted Steel (DB)	Painted Steel (DI)
 1 Toggle Switch (1T-GP)	84752	85752	86752	94752	97752	98752	99752
 1 Duplex Receptacle (10DR-GP)	84753	85753	86753	94753	97753	98753	99753
 1 Single Recept. (1.405") (10R-GP)	84754	85754	86754	94754	97754	98754	99754
 1 Blank (Box Mntg. 3.281") (1B-GP)	84755	85755	86755	94755	97755	98755	99755
9/16" Deep Plates							
 1 Toggle Switch (1T-NGP)	84821	85821	86821	94821	97821	98821	99821
 2 Toggle Switches (2T-NGP)	84824	85824	86824	94824	97824	98824	99824
 3 Toggle Switches (3T-NGP)	84828	85828	86828	94828	97828	98828	99828
 1 Duplex Receptacle (10DR-NGP)	84822	85822	86822	94822	97822	98822	99822
 2 Duplex Receptacles (20DR-NGP)	84826	85826	86826	94826	97826	98826	99826
 1 Single Recept. (1.405") (10R-NGP)	84823	85823	86823	94823	97823	98823	99823
 1 Blank (Box Mntg. 3.281") (1B-NGP)	84831	85831	86831	94831	97831	98831	99831
 2 Blanks (Box Mntg. 3.281") (2B-NGP)	84827	85827	86827	94827	97827	98827	99827
 Toggle Switch, Duplex Recept. (1T-10DR-NGP)	84825	85825	86825	94825	97825	98825	99825
 2 Toggle Switches, Duplex Receptacle (2T-10DR-NGP)	84829	85829	86829	94829	97829	98829	99829