


















General Construction Finishes

	CHROME PLATED	WHITE SEMI- GLOSS	STAIN- LESS TYPE 302	STAIN- LESS TYPE 430	BROWN WRINKLE	IVORY WRINKLE
 Duplex Recept., 30A Range/Dryer Recept. (2.125" ID Hole) (10DR-3D)	83180	86180	93180	97180	98180	99180
 Single Recept. (1.405" ID Hole), Blank (Box Mntg. 3.281") (10R-1B)	83552	86552	93552	97552	98552	99552
 Block Duplex/GFI Recept., Blank (Box Mntg. 3.281") (SRM-1B)	83422	86422	93422	97422	98422	99422
 Toggle Switch, Centered 2 Gang Plate (1T-2G)	83772	86772	93772	97772	98772	99772
 Duplex Recept., Centered 2 Gang Plate (10DR-2G)	83773	86773	93773	97773	98773	99773
 Single Recept. (1.405" ID Hole), Centered 2 Gang Plate (10R-2G)	83774	86774	93774	97774	98774	99774
 3/4" ID Phone (Box Mntg. 3.281"), Centered 2 Gang Plate (01-2G)	83775	86775	93775	97775	98775	99775
 2 Toggle Switches, Duplex Receptacle (2T-10DR)	83543	86543	93543	97543	98543	99543
 2 Toggle Switches, Blank (Box Mntg. 3.281") (2T-1B)	83533	86533	93533	97533	98533	99533
 2 Toggle Switches, Block Duplex/GFI Recept. (2T-SRM)	83443	86443	93443	97443	98443	99443
 Toggle Switch, 2 Block Duplex/GFI Recepts. (1T-2SRM)	83453	86453	93453	97453	98453	99453
 Toggle Switch, 2 Blanks (Box Mntg. 3.281") (1T-2B)	83133	86133	93133	97133	98133	99133
 Toggle Switch, 2 Duplex Recepts. (1T-20DR)	83553	86553	93553	97553	98553	99553
 Toggle Switch, Block Duplex, Duplex Recept. (1T-SRM-10DR)	83503	86503	93503	97503	98503	99503
 Duplex Recept., 2 Blanks (Box Mntg. 3.281") (10DR-2B)	83423	86423	93423	97423	98423	99423
 Blank (Box Mntg. 3.281"), Duplex Recept., Blank (Box Mntg. 3.281") (1B-10DR-1B)	83193	86193	93193	97193	98193	99193





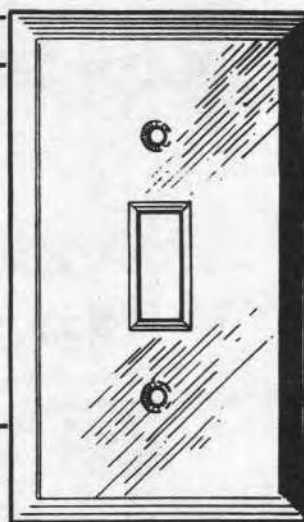



 



General Construction Finishes



For color photos of finishes see inside front cover.

STANDARD SHAPE

See page A84 for ordering Custom Plates not found in this listing.

	CHROME PLATED	WHITE SEMI-GLOSS	STAIN-LESS TYPE 302 (.035") Spec. Grade Satin Finish (302SS)	STAIN-LESS TYPE 430 (.030") Satin Finish (SS)	BROWN WRINKLE	IVORY WRINKLE
 1 Toggle Switch (1T)	Polished Steel (CA) 83071	Painted Steel (WA) 86071	83071	97071	Painted Steel (DB) 98071	Painted Steel (DI) 99071
 2 Toggle Switches (2T)	83072	86072	93072	97072	98072	99072
 3 Toggle Switches (3T)	83073	86073	93073	97073	98073	99073
 4 Toggle Switches (4T)	83074	86074	93074	97074	98074	99074
 5 Toggle Switches (5T)	83075	86075	93075	97075	98075	99075
 6 Toggle Switches (6T)	83076	86076	93076	97076	98076	99076
 7 Toggle Switches (7T)	83077	86077	93077	97077	98077	99077
 8 Toggle Switches (8T)	83078	86078	93078	97078	98078	99078
 9 Toggle Switches (9T)	83079	86079	93079	97079	98079	99079
 10 Toggle Switches (10T)	83080	86080	93080	97080	98080	99080
 1 Duplex Receptacle (10DR)	83101	86101	93101	97101	98101	99101
 2 Duplex Receptacles (20DR)	83102	86102	93102	97102	98102	99102