


Jumbo/ Oversize

 
- Ideal for covering broken plaster and irregularly cut holes in sheet rock or paneling around the box.
- Can be used to protect wall surrounding wiring devices thus reducing maintenance.
- Useful for replacement of plates in old work where a mark is left around the original plate.

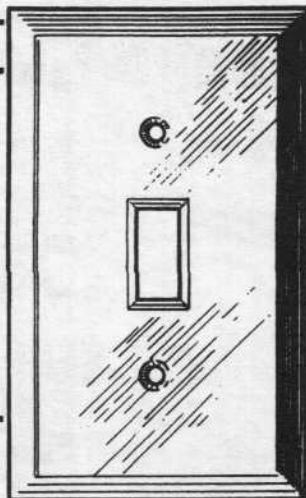














For color photos of finishes see inside front cover.

1 Gang	5.5" x 3.5"
2 Gang	5.5" x 5.5"
3 Gang	5.5" x 7.5"
4 Gang	5.5" x 9.5"
5 Gang	5.5" x 11.5"

STANDARD SHAPE

 listed 883C except where noted by asterisk(*)

See page A85 for ordering Custom Jumbo/Oversize Plates not found in this listing. Available to 20 gangs on special order.

	STAIN-LESS TYPE 302 (.035") Spec. Grade Satin Finish (302SS)	SATIN BRASS (.040") Satin Finish US#4 (4BB)	ALUMI-NUM (.050") Clear Anodized US#28 (5AA)	STAIN-LESS TYPE 430 (.030") Satin Finish US#32 (SS)	BROWN WRINKLE Painted Steel (DB)	IVORY WRINKLE Painted Steel (DI)
 1 Toggle Switch (1T-SL)	93871	94871	95871	97871	98871	99871
 2 Toggle Switches (2T-SL)	93872	94872	95872	97872	98872	99872
 3 Toggle Switches (3T-SL)	93873	94873	95873	97873	98873	99873
 4 Toggle Switches (4T-SL)	93874	94874	95874	97874	98874	99874
 5 Toggle Switches (5T-SL)	93875	94875	95875	97875	98875	99875
 1 Duplex Receptacle (10DR-SL)	93801	94801	95801	97801	98801	99801
 2 Duplex Receptacles (20DR-SL)	93802	94802	95802	97802	98802	99802
 1 Single Recept. (1.405") (10R-SL)	93891	94891	95891	97891	98891	99891
 1 Blank (Box Mntg. 3.281") (1B-SL)	93851	94851	95851	97851	98851	99851
 2 Blanks (Box Mntg. 3.281") (2B-SL)	93852	94852	95852	97852	98852	99852
 3 Blanks (Box Mntg. 3.281") (3B-SL)	93853	94853	95853	97853	98853	99853
 One 5/8" ID Phone (Box Mntg. 3.281") (01-SL)*	93861	94861	95861	97861	98861	99861
 One Phone with .375" ID Grommet and Mounting Strap (Device Mntg. 2.375")*	93881	94881	95881	97881	98881	99881