


Cleaver Brooks


A06-SJ4	120	60
---------	-----	----

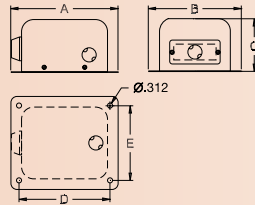

A	B	C	D	E
6.63	5.75	4.81	5.63	4.63

Cleaver Brooks



A06-SJ5	120	60
---------	-----	----

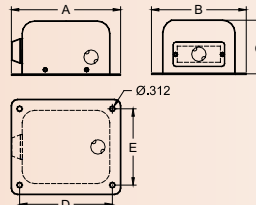

A	B	C	D	E
6.50	5.50	4.75	5.63	4.63

Gordon Piatt

Secondary 6,000 V 20 mA, 175 VA, End Ground		
Catalog No.	Primary	Hz
A06-SV12	120	60

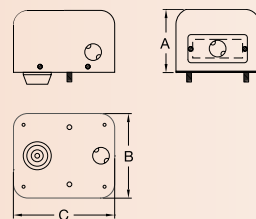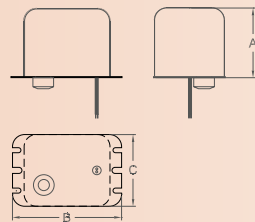


Dunham Bush

Secondary 6,000 V 20 mA, 175 VA, End Ground		
Catalog No.	Primary	Hz
A06-SY3	120	60

A	B	C
4.25	4.44	5.38

Universal


Secondary 8,500 V 20 mA, 230 VA, End Ground		
Catalog No.	Primary	Hz
A08-SA1	120	60

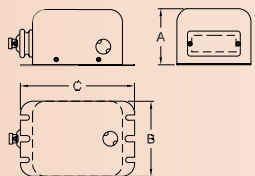

A	B	C
4.31	4.44	6.75

Industrial Combustion


Secondary 8,500 V 20 mA, 230 VA, End Ground		
Catalog No.	Primary	Hz
A08-SJ5	120	60

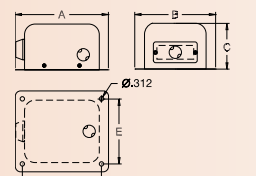


A	B	C	D	E
6.50	5.50	4.75	5.63	4.63

Universal

Secondary 10,000 V 22 mA, 250 VA, End Ground		
Catalog No.	Primary	Hz
A10-LA2	120	60
C10-LA2	240	60
K10-LA2	208	60
E10-LA2	110	50
F10-LA2	220	50

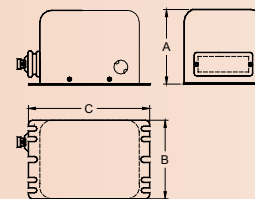

A	B	C
4.69	4.94	7.63

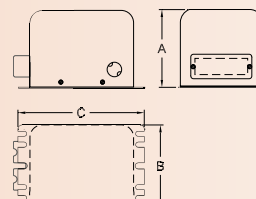

A	B	C
4.69	4.94	7.63

Universal

Secondary 2 x 5,000 V or 10,000 22 mA, 250 VA		
Catalog No.	Primary	Hz
A10-LF3	120	60
C10-LF3	240	60
N10-LF3	480	60