


# Soundsational™ Speaker Cable



94722

## Pro Audio Cable (high-strand, pressure-extruded, round)

| Part Number | Description                          | AWG | Cond | UL Type | Weight (Nom.) | Outside Dia. (Nom.) | Packaging      | Jacket Color              |
|-------------|--------------------------------------|-----|------|---------|---------------|---------------------|----------------|---------------------------|
| 94762       | 16/2 stranded BC (65/34) 99.97% OFC  | 16  | 2    | CL3     | 31 lbs        | 0.192"              | 500' Box (45)  | White (01)<br>Yellow (02) |
| 94764       | 16/4 stranded BC (65/34) 99.97% OFC  | 16  | 4    | CL3     | 47 lbs        | 0.224"              | 500' Box (45)  | Blue (06)                 |
| 94742       | 14/2 stranded BC (105/34) 99.97% OFC | 14  | 2    | CL3     | 44 lbs        | 0.222"              | 500' Box (45)  | White (01)<br>Yellow (02) |
| 94744       | 14/4 stranded BC (105/34) 99.97% OFC | 14  | 4    | CL3     | 69 lbs        | 0.260"              | 500' Box (45)  |                           |
| 94722       | 12/2 stranded BC (168/34) 99.97% OFC | 12  | 2    | CL3     | 73 lbs        | 0.278"              | 500' Reel (05) | White (01)<br>Purple (13) |

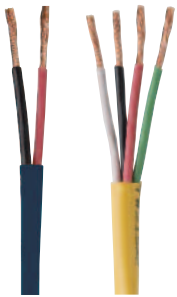

94542

94564

## Complete Audio Cable (direct burial, high-strand, tubed construction)

| Part Number | Description                          | AWG | Cond | UL Type | Weight (Nom.) | Outside Dia. (Nom.) | Packaging      | Jacket Color              |
|-------------|--------------------------------------|-----|------|---------|---------------|---------------------|----------------|---------------------------|
| 94562       | 16/2 stranded BC (65/34) 99.97% OFC  | 16  | 2    | CL3     | 24 lbs        | 0.188"              | 1000' Box (46) | White (01)<br>Blue (06)   |
| 94564       | 16/4 stranded BC (65/34) 99.97% OFC  | 16  | 4    | CL3     | 43 lbs        | 0.220"              | 500' Box (45)  |                           |
| 94542       | 14/2 stranded BC (105/34) 99.97% OFC | 14  | 2    | CL3     | 35 lbs        | 0.218"              | 1000' Box (46) | White (01)<br>Yellow (02) |
| 94544       | 14/4 stranded BC (105/34) 99.97% OFC | 14  | 4    | CL3     | 64 lbs        | 0.256"              | 1000' Box (46) |                           |

Rated CM/CL3/FPL/PLTC



94642

94664

## Easy Audio Cable (direct burial, tubed construction)

| Part Number | Description                             | AWG | Cond | UL Type | Weight (Nom.) | Outside Dia. (Nom.) | Packaging       | Jacket Color              |
|-------------|---|-----|------|---------|---------------|---------------------|-----------------|---------------------------|
| 94662       | 16/2 stranded BC (26/30) 99.97% OFC     | 16  | 2    | CL3     | 23 lbs        | 0.188"              | 500' Box (45)   | White (01)<br>Blue (06)   |
| 94772       | 16/2 stranded OAS BC (26/30) 99.97% OFC | 16  | 2    | CL3     | 27 lbs        | 0.197"              | 1000' Reel (06) | White (01)                |
| 94664       | 16/4 stranded BC (26/30) 99.97% OFC     | 16  | 4    | CL3     | 42 lbs        | 0.220"              | 500' Box (45)   | White (01)<br>Blue (06)   |
| 94642       | 14/2 stranded BC (41/30) 99.97% OFC     | 14  | 2    | CL3     | 34 lbs        | 0.218"              | 500' Box (45)   | White (01)<br>Yellow (02) |
| 94644       | 14/4 stranded BC (41/30) 99.97% OFC     | 14  | 4    | CL3     | 63 lbs        | 0.256"              | 500' Box (45)   |                           |

Rated CM/CL3/FPL/PLTC