

# GROUND CLAMPS

## Heavy Duty Direct Burial Ground Clamps, Direct Burial for Rebar

### G-S-DB, G-S-BS SERIES




### HEAVY DUTY DIRECT BURIAL




- UL Listed for direct burial in earth or concrete.
- Screws are 304 stainless steel.
- cULus Listed 467 Grounding and Bonding.

#### G-1-S DB

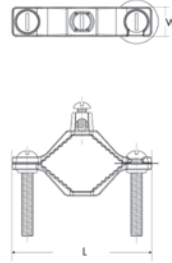

#### G-2-SDB

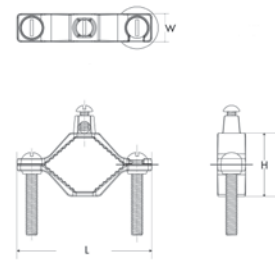

All dimensional data is listed in inches.

CAT. NO.	PIPE SIZE (IPS)	GROUND WIRE BOLT SIZE	GROUND CLAMP BOLT SIZE	GROUND WIRE RANGE	LENGTH (L)	WIDTH (W)	HEIGHT (H)	STD. CTN. QTY.
<b>G-1-S DB*</b>	1/2-1	1/4"-20 x 1/2"	1/4"-20 x 1.50"	10 SOL - 2 STR	2.280	0.650	1.400	20
<b>G-2-SDB*</b>	1 1/4-2	1/4"-20 x 1/2"	5/16"-18 x 2"	10 SOL - 2 STR	3.600	0.750	1.690	10

\*Available with silicon bronze screws by adding suffix of -SB.


### DIRECT BURIAL FOR REBAR



- Used to connect bare copper wire to copper water pipe, ground rods and rebar for bonding.
- Assembled with copper alloy screws and UL Listed for direct burial in earth and concrete.
- Can accommodate ground wires up to 2 AWG.
- cULus Listed 467 Grounding and Bonding.



#### G-4-S BS

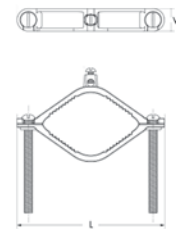

All dimensional data is listed in inches.

CAT. NO.	PIPE SIZE (IPS)	REBAR SIZE	GROUND WIRE RANGE	GROUND CLAMP BOLT SIZE	GROUND WIRE BOLT SIZE	LENGTH (L)	WIDTH (W)	HEIGHT (H)	STD. CTN. QTY.
<b>G-4-S BS</b>	2 1/2-4	3/8 - 1	10 SOL-2 STR	1/4-20 x 1/2"	3/8-16 x 4"	6.350	0.970	3.750	6

GROUNDING