


Copper Short Barrel Compression Splice - SC Series

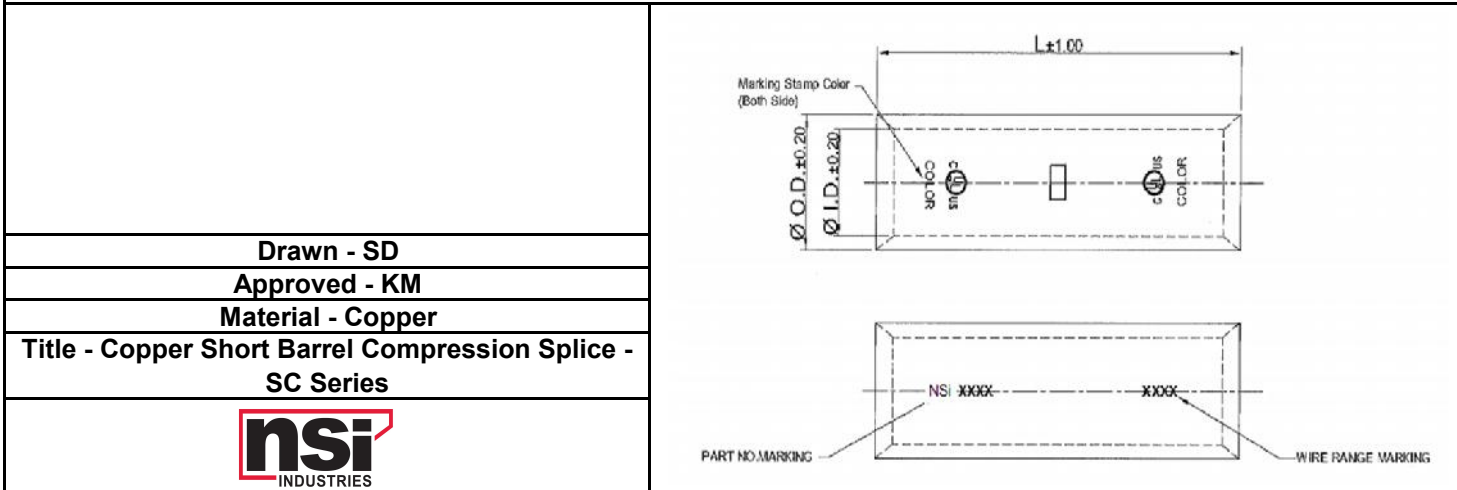

Drawn - SD

Approved - KM

Material - Copper

Title - Copper Short Barrel Compression Splice - SC Series



Part Number	Wire Range	Color Code	I.D. mm	I.D. Inches	O.D. mm	O.D. Inches	Length mm	Length Inches
SC-8	8 AWG	RED	4.40	0.17	6.90	0.27	22.90	0.90
SC-6	6 AWG	BLUE	5.20	0.20	7.50	0.30	25.40	1.00
SC-4	4 AWG	GRAY	6.40	0.25	8.70	0.34	25.40	1.00
SC-2	2 AWG	BROWN	8.00	0.31	10.70	0.42	31.80	1.25
SC-1	1 AWG	GREEN	9.10	0.36	11.90	0.47	45.70	1.80
SC-1/0	1/0 AWG	PINK	9.90	0.39	13.20	0.52	40.60	1.60
SC-2/0	2/0 AWG	BLACK	11.20	0.44	14.30	0.56	44.50	1.75
SC-3/0	3/0 AWG	ORANGE	12.50	0.49	15.80	0.62	44.50	1.75
SC-4/0	4/0 AWG	PURPLE	13.90	0.55	17.50	0.69	48.30	1.90
SC-250	250 MCM	YELLOW	15.10	0.59	19.10	0.75	50.80	2.00
SC-300	300 MCM	WHITE	16.70	0.66	20.70	0.81	53.30	2.10
SC-350	350 MCM	RED	17.80	0.70	22.20	0.87	53.30	2.10
SC-400	400 MCM	BLUE	19.40	0.76	24.10	0.95	58.40	2.30
SC-500	500 MCM	BROWN	21.20	0.83	27.00	1.06	63.50	2.50
SC-600	600 MCM	GREEN	30.20	1.19	30.20	1.19	63.50	2.50
SC-750	750 MCM	BLACK	26.20	1.03	33.30	1.31	81.30	3.20