


Type
Project
Catalog No.
Lamp/Wattage

NTA-86 / NTA-87 / NTA-88 / NTA-89
Wall Wash Eyelid with Cone Reflector

TRIM DIMENSIONS

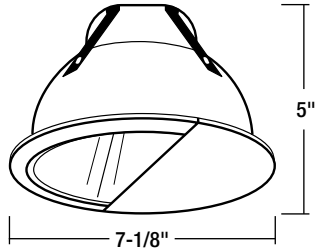

Trim OD: 7-1/8"
 Height: 5"

FEATURES

Trim
 Precision spun 0.050 aluminum high grade reflector with steel half moon. Separate trim ring available in plastic or metal, may also be used with custom combination of ring finishes.

Mounting
 Trim includes three trim springs on the top of the trim that snap and securely hold the trim into the housing when installed.

Compatible Housings
 Compatible with Line Voltage, Compact Fluorescent, HID housings, and CFL Retrofits. See individual specification sheets for more information.

- Lamp**
 Line Voltage
 60W A19 Maximum (NHIC-17QAT, NHRIC-17QAT)
 100W A19 Maximum (NH-26Q; NHR-26Q; NHIC-17/100DWQA)
 Compact Fluorescent
 13W-26W 4-Pin Quad (NHP Series; NHPIC Series; NHRP Series; NHRPIC Series)
 13W-42W 4-Pin Triple (NHP Series; NHPIC Series; NHRP Series; NHRPIC Series)
 HID
 39W PAR20/PAR30 CMH (NHPM-735/EL; NHRPM-735/EL)
 50W ED17 CMH (NHPM-750/EL; NHRPM-750/EL)
 70W ED17/PAR30 CMH (NHPM-770/EL; NHRPM-770/EL)
 100W ED17 CMH (NHPM-7100/EL; NHRPM-7100/EL)
 Compact Fluorescent Retrofit Kits
 13W 2-Pin Twin (NPK-13)
 13W 4-Pin Quad/Triple (NPK-13EL)
 18W 4-Pin Quad/Triple (NPK-18EL)
 26W 4-Pin Quad/Triple (NPK-26EL)

Labels and Listings
 cULus Listed for Damp Location when used with compatible housing

Wall Wash Eyelid with Cone Reflector

- NTA-86: White Wall Wash Eyelid with Specular Gold Cone Reflector and White Plastic Ring
- NTA-87: White Wall Wash Eyelid with Specular Clear Cone Reflector and White Plastic Ring
- NTA-88: White Wall Wash Eyelid with Specular Black Cone Reflector and White Plastic Ring
- NTA-88BZ: Bronze Wall Wash Eyelid with Bronze Cone Reflector and Bronze Metal Ring
- NTA-88CO: Copper Wall Wash Eyelid with Copper Cone Reflector and Copper Metal Ring
- NTA-88N: Natural Metal Wall Wash Eyelid with Natural Metal Cone Reflector and Natural Metal Ring
- NTA-89: White Wall Wash Eyelid with Specular White Cone Reflector and White Plastic Ring

Compatible Housings

LINE VOLTAGE			
Item Number	Installation Type	Lamp	Dimensions
NH-26Q	Non-IC New Construction	100W A19 Max.	W: 7" L: 10-1/8" H: 7-1/2"
NHIC-17/100DWQA	IC Double Wall Air-Tight NC	100W A19 Max.	W: 9-1/8" L: 12-1/2" H: 7-3/4"
NHIC-17QAT	IC Air-Tight New Construction	60W A19 Max.	W: 7" L: 10-1/8" H: 7-1/2"
NHR-26Q	Non-IC Remodel Housing	100W A19 Max.	W: 6-3/4" L: 13-3/4" H: 7-1/2"
NHRIC-17QAT	IC Air-Tight Remodel Housing	60W A19 Max.	W: 6-3/4" L: 13-3/4" H: 7-1/2"
COMPACT FLUORESCENT			
NHP-13EL	Non-IC New Construction	13W Quad/Trip	W: 7-5/8" L: 14" H: 7-3/8"
NHP-13M	Non-IC New Construction	13W Quad	W: 7-5/8" L: 14" H: 7-3/8"
NHP-18EL	Non-IC New Construction	18W Quad/Trip	W: 7-5/8" L: 14" H: 7-3/8"
NHP-2642EL	Non-IC New Construction	26-42W Q/T	W: 7-5/8" L: 14" H: 7-3/8"
NHPIC-13EL	IC New Construction	13W Quad/Trip	W: 7-5/8" L: 14" H: 7-3/8"
NHPIC-13ELAT	IC Air-Tight New Construction	13W Quad/Trip	W: 7-5/8" L: 14" H: 7-3/8"
NHPIC-13MQ	IC New Construction	13W Quad	W: 7-5/8" L: 14" H: 7-3/8"
NHPIC-18ATE2	IC Air-Tight New Construction	18W Quad/Trip	W: 7-5/8" L: 14" H: 7-3/8"
NHPIC-18ELAT	IC Air-Tight New Construction	18W Quad/Trip	W: 7-5/8" L: 14" H: 7-3/8"
NHPIC-26ATE2	IC Air-Tight New Construction	26W Quad/Trip	W: 7-5/8" L: 14" H: 7-3/8"
NHPIC-26ELAT	IC Air-Tight New Construction	26W Quad/Trip	W: 7-5/8" L: 14" H: 7-3/8"
NHPIC-2642ELAT	IC Double Wall Air-Tight NC	26-42W Q/T	W: 7-5/8" L: 14" H: 7-3/8"
NHRP-13EL	Non-IC Remodel Housing	13W Quad/Trip	W: 6-3/4" L: 13-1/2" H: 7-3/8"
NHRP-13MQ	Non-IC Remodel Housing	13W Quad	W: 6-3/4" L: 13-1/2" H: 7-3/8"
NHRP-18EL	Non-IC Remodel Housing	18W Quad/Trip	W: 6-3/4" L: 13-1/2" H: 7-3/8"
NHRP-2642EL	Non-IC Remodel Housing	26-42W Q/T	W: 6-3/4" L: 13-1/2" H: 7-3/8"
NHRPIC-13EL	IC Remodel Housing	13W Quad/Trip	W: 6-3/4" L: 13-1/2" H: 7-3/8"
NHRPIC-13ELAT	IC Air-Tight Remodel Housing	13W Quad/Trip	W: 6-3/4" L: 13-1/2" H: 7-3/8"
NHRPIC-13MQ	IC Remodel Housing	13W Quad	W: 6-3/4" L: 13-1/2" H: 7-3/8"
NHRPIC-18EL	IC Remodel Housing	18W Quad/Trip	W: 6-3/4" L: 13-1/2" H: 7-3/8"
NHRPIC-18ELAT	IC Air-Tight Remodel Housing	18W Quad/Trip	W: 6-3/4" L: 13-1/2" H: 7-3/8"
NHRPIC-26ATE2	IC Air-Tight Remodel Housing	26W Quad/Trip	W: 6-3/4" L: 13-1/2" H: 7-3/8"
NHRPIC-26ELAT	IC Air-Tight Remodel Housing	26W Quad/Trip	W: 6-3/4" L: 13-1/2" H: 7-3/8"
HID			
NHPM-735/EL	Non-IC New Construction	39W PAR20/PAR30	W: 7-5/8" L: 12" H: 7-1/2"
NHPM-750/EL	Non-IC New Construction	50W ED17	W: 7-5/8" L: 12" H: 7-1/2"
NHPM-770/EL	Non-IC New Construction	70W ED17/PAR30	W: 7-5/8" L: 12" H: 7-1/2"
NHPM-7100/EL	Non-IC New Construction	100W ED17	W: 7-5/8" L: 12" H: 7-1/2"
NHRPM-735/EL	Non-IC Remodel Housing	39W PAR20/PAR30	W: 6" L: 14-1/2" H: 7-3/8"
NHRPM-750/EL	Non-IC Remodel Housing	50W ED17	W: 6" L: 14-1/2" H: 7-3/8"
NHRPM-770/EL	Non-IC Remodel Housing	70W ED17/PAR30	W: 6" L: 14-1/2" H: 7-3/8"
NHRPM-7100/EL	Non-IC Remodel Housing	100W ED17	W: 6" L: 14-1/2" H: 7-3/8"
COMPACT FLUORESCENT RETROFIT KITS			
NPK-13	Retrofit Kit, Magnetic	13W Twin	Dia: 5-15/16" H: 5-1/2"
NPK-13EL	Retrofit Kit, Electronic	13W Quad/Trip	Dia: 5-15/16" H: 5-1/2"
NPK-18EL	Retrofit Kit, Electronic	18W Quad/Trip	Dia: 5-15/16" H: 5-1/2"
NPK-26EL	Retrofit Kit, Electronic	26W Quad/Trip	Dia: 5-15/16" H: 5-1/2"