

Pipe Freeze Protection Plug-in Heating Cable (9mm)

PIPE MATERIAL

Metal
Plastic

[Up to 6" diameter, with 1" fiberglass insulation]

WATTAGE

8 watts

[Output per foot @ 50°F on metal pipes]

VOLTAGE

120V

CABLE DIMENSIONS

0.36 inches x 0.22 inches
(9.1mm x 5.6mm)

MINIMUM BEND RADIUS

1.18 inches (30mm)

MAXIMUM EXPOSURE TEMP.

150°F (66°C)

Plug-In Self-Regulating Heating Cable (9mm)

MODEL NUMBERS

5 ft 9PK08W1 -5
10 ft 9PK08W1 -10
15 ft 9PK08W1 -15
25 ft 9PK08W1 -25
50 ft 9PK08W1 -50
75 ft 9PK08W1 -75
100 ft 9PK08W1 -100

WARRANTY

10 years*



The Nuheat 9 millimeter (mm) Plug-In Cable is a self-regulating heating cable designed for residential and commercial pipe freeze protection.

Available in 120V, this 8 watt cable is suitable for metal or plastic pipes and can accommodate pipes up to 6 inches in diameter**.

Factory assembled with a standard three-prong plug, each cable can simply connect to any grounded 120V receptacle.

The cable's ability to self-regulate allows it to overlap across

itself—without risk of overheating or burnout—for easy installation around pipes and pipe features.

Available in a range of lengths, from 5 - 100 feet, the 9mm Plug-in cable is the quick and easy solution for pipe freeze protection.

Features



- produces 8 watts per ft (@ 50°F)
- available in 120V
- simple plug-in feature allows for easy installation
- cable can overlap across itself without risk of overheating and/or burnout for easy installation around pipes and pipe features
- can accommodate pipes up to 6 inches in diameter**

** based on 1" fiberglass insulation

* available when registered online within 30 days of installation

PIPE FREEZE PROTECTION

13

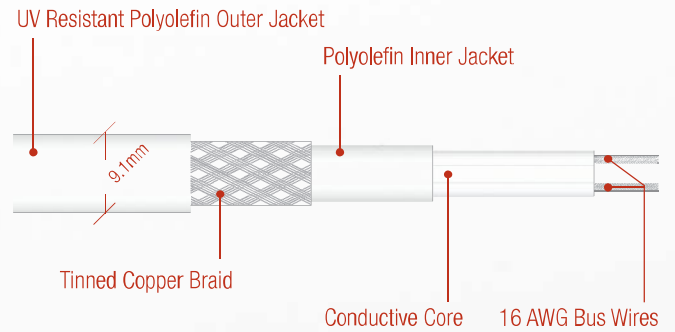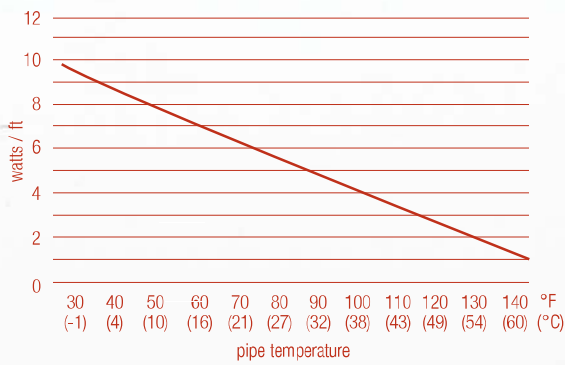

MODEL #	COLD LEAD LENGTH (FT)	HEAT CABLE LENGTH (FT)
9PK 08W1 - 5	3	5
9PK 08W1 - 10	3	10
9PK 08W1 - 15	3	15
9PK 08W1 - 25	3	25
9PK 08W1 - 50	3	50
9PK 08W1 - 75	3	75
9PK 08W1 - 100	3	100