


# Straight Blade Receptacles TradeMaster® Decorator Hallway Lights & Combination Devices


Pass & Seymour




Features	
<ul style="list-style-type: none"> <li>Impact-resistant face and body.</li> <li>GE Lexan™ high impact-resistant lens.</li> <li>External screw-pressure-plate back and side wired. Accepts #12 and #14 AWG.</li> <li>Ground screw position under the end of the strap minimizes the risk of contact.</li> </ul>	<ul style="list-style-type: none"> <li>Energy-efficient LED has average 20-year life expectancy: eliminates bulb replacement.</li> <li>Sensor automatically turns light ON in the dark.</li> <li>Increased light output for better illumination.</li> <li>Light sensor for enhanced sensitivity.</li> </ul>

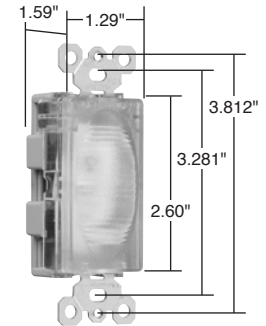


TMHWLCC

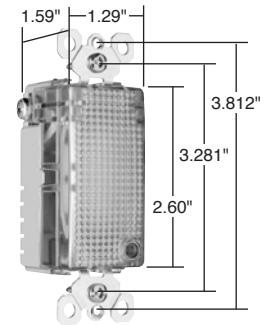

TMHWLECC

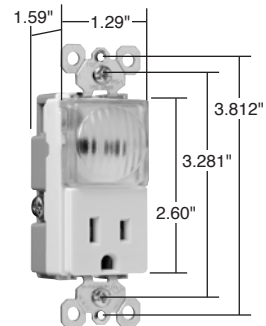

TM8HWLWCC

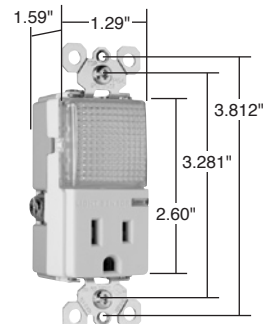

TM8HWLEWCC4

Catalog Number	Rating A. VAC	Light Output In 1' FCD*	Color	3rd Party Compliance
				cUL <sub>us</sub> UL1598
<b>TradeMaster® Decorator Full Hallway Light</b>				
TMHWLCC	— 120	0.1328	Clear	•
<b>Enhanced Decorator Full Hallway Light with Light Sensor</b>				
TMHWLECC	— 120	1.079	Clear	•
<b>Enhanced Decorator Full Hallway Light without Light Sensor</b>				
TMHWLENSCC	— 120	1.113	Clear	•
<b>Full Hallway Decorator Light for use with P&amp;S Metal Louver Plates**</b>				
TMHWLLOUVCC	— 120	0.0843	Clear	•

\*FCD = Foot Candle Distance. 1 Lumen = 1 FCD. See Page U-55 for more information.

\*\*For Louver Plates, see Page S-20.

Catalog Number	Rating A. VAC	Light Output In 1' FCD*	Color	NEMA Config. No.	3rd Party Compliance
					cUL <sub>us</sub> UL498
<b>TradeMaster® Decorator Hallway Light &amp; Single Receptacle</b>					
TM8HWLICCC	15 120/125	0.1442	Ivory	5-15R	•
TM8HWLWCC	15 120/125	0.1442	White	5-15R	•
TM8HWLBKCC	15 120/125	0.1442	Black	5-15R	•
TM8HWLCC	15 120/125	0.1442	Brown	5-15R	•
TM8HWLLACC	15 120/125	0.1442	Light Almond	5-15R	•
<b>Enhanced Decorator Hallway Light &amp; Single Receptacle</b>					
TM8HWLEICC	15 120/125	0.2561	Ivory	5-15R	•
TM8HWLEWCC	15 120/125	0.2561	White	5-15R	•
TM8HWLELACC	15 120/125	0.2561	Light Almond	5-15R	•

\*FCD = Foot Candle Distance. 1 Lumen = 1 FCD. See Page U-55 for more information.

2 Pole, 3 Wire



NEMA 5-15R

For complete line of Decorator Combination Devices and Hallway Lights, see Pages E-7 – E-11, E-17, E-18, E-21, E-30, E-36 and E-72.

All devices listed on this page conform to NEMA WD-1 and WD-6.

Straight Blade Receptacles

Hallway Lights & Combination Devices