


Pass & Seymour



Straight Blade Receptacles TradeMaster® Tamper-Resistant Receptacles

Meets 2008 National Electrical Code®
Tamper-Resistant requirements.

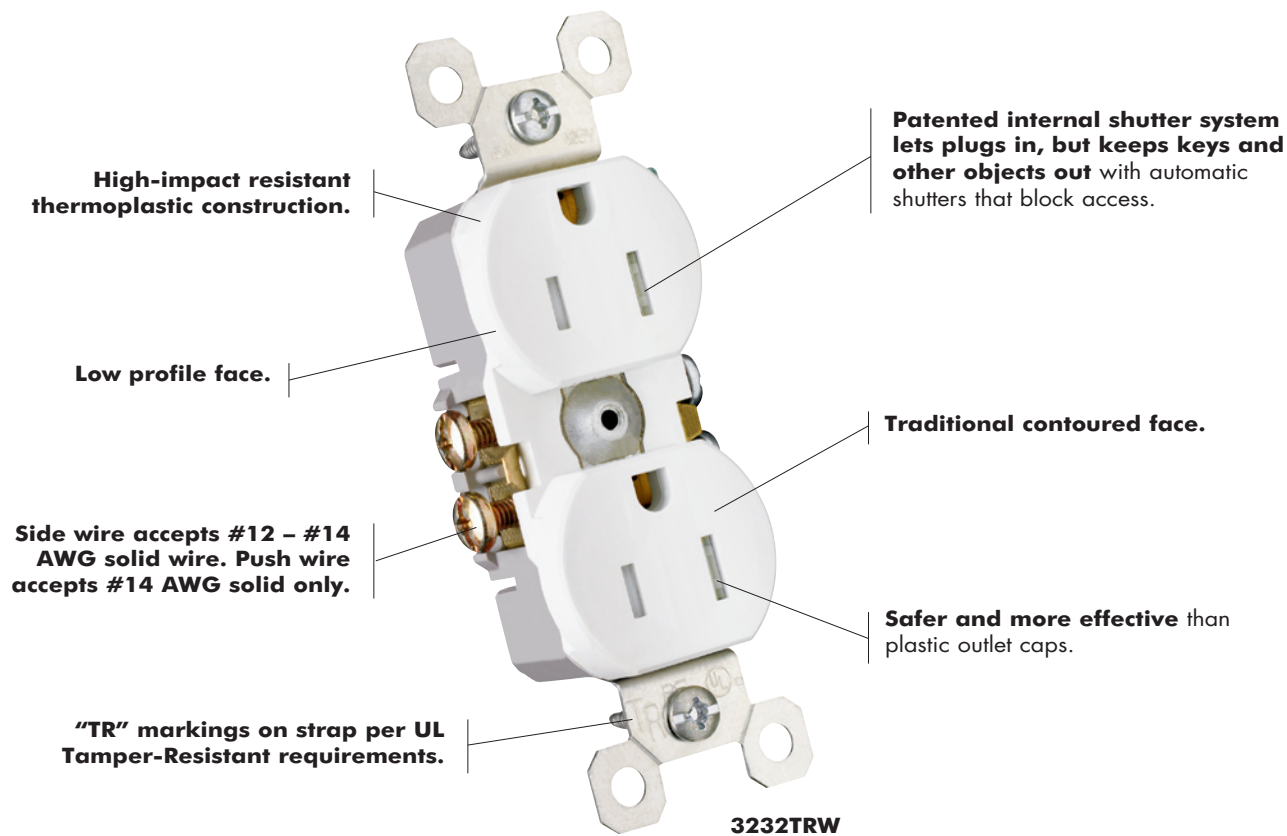

2008 National Electrical Code® Section 406.11 Tamper-Resistant Receptacles in Dwelling Units.

In all areas specified in 210.52 all 125-volt, 15- and 20-amp receptacles shall be listed tamper-resistant receptacles.

Straight Blade Receptacles TradeMaster® Tamper-Resistant Receptacles




15A, 125V

Pass & Seymour



Straight Blade Receptacles

Features	
<ul style="list-style-type: none"> ■ Meets 2008 National Electrical Code® Tamper-Resistant requirements. ■ Protects children: patented shutter system helps prevent improper insertion of foreign objects. ■ High-impact resistant thermoplastic construction. ■ Extra-long strap. ■ Quickloop wire looping aid. ■ Long-term blade retention. ■ Longer tri-drive screws for easier 12 AWG looping. ■ Extra-large circuit break-off tabs. 	<ul style="list-style-type: none"> ■ Side-access push wire release. ■ Ultrasonic welding of face to back body. ■ Side wire accepts #12 – #14 AWG solid wire. ■ Push wire accepts #14 AWG solid only. ■ Superior protection than traditional outlet “caps” or “protection plates.” ■ Low profile face. ■ Traditional contoured face (3232 models). ■ Self-grounding models provide automatic ground clip.

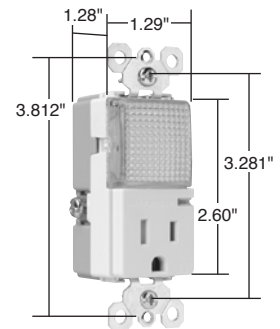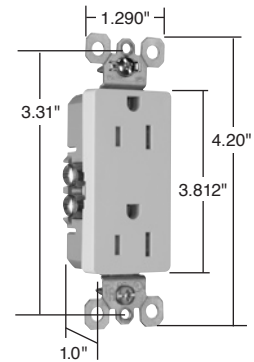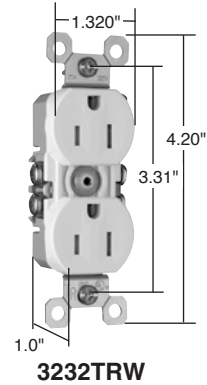

2 Pole, 3 Wire



**NEMA
5-15R**

Catalog Number	Rating A. V.	Color	NEMA Config. No.	3rd Party Compliance		
				UL498	C22.2 No. 42	c US cULus
Tamper-Resistant Duplex Receptacles – Grounding						
NEW 3232TRI	15 125	Ivory	5-15R	•	•	•
3232TRW	15 125	White	5-15R	•	•	•
3232TR	15 125	Brown	5-15R	•	•	•
3232TRBK	15 125	Black	5-15R	•	•	•
3232TRLA	15 125	Light Almond	5-15R	•	•	•
Self-Grounding Tamper-Resistant Duplex Receptacles						
3232TRSI	15 125	Ivory	5-15R	•	•	•
3232TRSW	15 125	White	5-15R	•	•	•
3232TRS	15 125	Brown	5-15R	•	•	•
3232TRSLA	15 125	Light Almond	5-15R	•	•	•
Decorator Tamper-Resistant Receptacles						
885TRI	15 125	Ivory	5-15R	•	•	•
885TRW	15 125	White	5-15R	•	•	•
885TR	15 125	Brown	5-15R	•	•	•
NEW 885TRGRY	15 125	Gray	5-15R	•	•	•
NEW 885TRBK	15 125	Black	5-15R	•	•	•
885TRLA	15 125	Light Almond	5-15R	•	•	•
Self-Grounding Decorator Tamper-Resistant Receptacles						
885TRSI	15 125	Ivory	5-15R	•	•	•
885TRSW	15 125	White	5-15R	•	•	•
885TRSLA	15 125	Light Almond	5-15R	•	•	•

Features	
<ul style="list-style-type: none"> ■ Impact-resistant face and body. ■ External screw-pressure-plate back and side wired. Accepts #12 and #14 AWG. ■ GE Lexan™ high impact-resistant lens. ■ Tri-drive screws. ■ Energy-efficient LED has average 20-year life expectancy: eliminates bulb replacement. ■ Sensor automatically turns light ON in the dark. 	<ul style="list-style-type: none"> ■ Increased light output for better illumination. ■ Light sensor for enhanced sensitivity. ■ UL tested shutter mechanism for protection against improper object insertion per UL498. ■ Specially designed for increased protection of children in their homes. ■ Superior protection than traditional outlet “caps” or “protection plates.”

Catalog Number	Rating A. VAC	Light Output in 1' FCD*	Color	NEMA Config. No.	3rd Party Compliance
					UL498
Decorator Hallway Light with High Output Light & Tamper-Resistant Single Receptacle					
TM8HWLTRICC	15 125	0.2561	Ivory	5-15R	•
TM8HWLTRWCC	15 125	0.2561	White	5-15R	•
TM8HWLTRBKCC	15 125	0.2561	Black	5-15R	•
TM8HWLTRCC	15 125	0.2561	Brown	5-15R	•
TM8HWLTRLACC	15 125	0.2561	Light Almond	5-15R	•

* FCD = Foot Candle Distance, 1 Lumen = 1 FCD. See Page U-55 for more information.

All devices listed on this page conform to NEMA WD-1 and WD-6.

TradeMaster® Tamper-Resistant Receptacles