


# 4x10 Punchdown Telecom Module w/ Line Seizure

TM7554

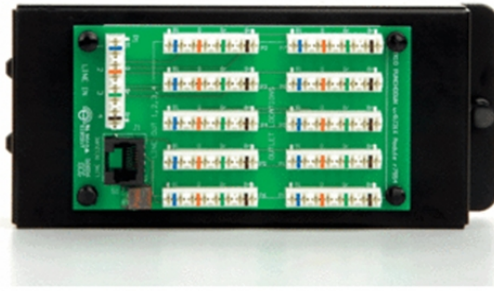

This telecom module includes a line seizure port for home security system configuration.

## features & benefits

Includes line seizure port for home security system configuration. Support four incoming phone lines and 10 flexible phone outlets. Bracket included.

## specifications

### General Info

Color: Black  
Footprint: Single Bay  
Termination: 8P8C TIA 586A  
Connection Type: 110 punchdown, RJ31x Female  
Type: Telecom Module

### Assembly/Installation Information

Mounting Hardware Included: Fasteners

### Listing Agencies/Third Party Information

U N SPS C: 43222819

### Dimensions

Depth Metric: 5 cm  
Depth U S: 2 in

Height Metric: 7.4 cm  
Height U S: 2.9 in  
Width Metric: 16.3 cm  
Width U S: 6.42 in

**Technical Information**

Flammability Rating: UL94V-0  
Material: 18 Gauge CRS  
Mounting: Enclosure  
Operating Temperature Celsius: 0°C to 55°C  
Operating Temperature Fahrenheit: 32°F to 131°F  
Receptacle Type: 11x 110 punchdown style connectors, 1x RJ31x  
Number Of Receptacles: 12