

Specification Data

Fixture Description:	Type
Project/Job:	
SYLVANIA lamp:	
SYLVANIA ballast:	
Notes:	

Ordering Information


Item Number	Ordering Abbreviation	Watts	Initial Lumens @25°C	Mean Lumens @25°C	Initial Lumens @35°C	Mean Lumens @35°C	Avg. Rated Life (hrs.) 3 hrs/st	Avg. Rated Life (hrs.) 12 hrs/st	CCT	CRI
21303	FP14/13W/830/SS/ECO	13	1200	1140	1350	1285	25,000	30,000	3000K	85
21304	FP14/13W/835/SS/ECO	13	1200	1140	1350	1285	25,000	30,000	3500K	85
21305	FP14/13W/841/SS/ECO	13	1200	1140	1350	1285	25,000	30,000	4100K	85
21306	FP21/19W/830/SS/ECO	19	1900	1805	2100	1995	25,000	30,000	3000K	85
21307	FP21/19W/835/SS/ECO	19	1900	1805	2100	1995	25,000	30,000	3500K	85
21308	FP21/19W/841/SS/ECO	19	1900	1805	2100	1995	25,000	30,000	4100K	85
21309	FP28/26W/830/SS/ECO	26	2600	2470	2900	2755	30,000	36,000	3000K	85
21310	FP28/26W/835/SS/ECO	26	2600	2470	2900	2755	30,000	36,000	3500K	85
21311	FP28/26W/841/SS/ECO	26	2600	2470	2900	2755	30,000	36,000	4100K	85

Ordering Guide

FP	14	/	13W	/	8	30	/	SS	/	ECO
Fluorescent PENTRON®	Full wattage equivalent		Actual Wattage 13, 19 or 26		CRI 85+ CRI	30 = 3000K CCT 35 = 3500K CCT 41 = 4100K CCT		SUPERSAVER		ECOLOGIC

Lamp Dimensions

	(A) Max. Overall Length (in.)	(B) Base Face to Opposite Pin (in.)	(C) Max. Base Face to Base Face (in.)	(D) Max. Outside Diameter (in.)
FP24	22.17"	Min. 21.80" Max. 21.89"	21.61"	0.67"
FP39	33.89"	Min. 33.61" Max. 33.70"	33.43"	0.67"
FP54	45.80"	Min. 45.42" Max. 45.52"	45.24"	0.67"

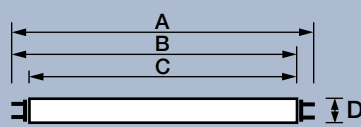

Related Literature

For optimum system performance and warranty pair with these QUICKTRONIC Ballast Systems

Ballast Technology Applications & Specification Guide (Literature Code: ECS-Electronic2009)

QUICK 60+® System Warranty (Literature Code: ECS140)

Sample Specification

Lamps shall be PENTRON® T5 SUPERSAVER® ECOLOGIC® lamps having miniature bi-pin bases and a minimum of 95% mean lumens. Lamps shall have a correlated color temperature of (3000K, 3500K, 4100K) and a CRI of 85. The PENTRON T5 SUPERSAVER ECO lamps shall be operated on QUICKTRONIC electronic T5 ballasts.

United States

OSRAM SYLVANIA

100 Endicott Street
Danvers, MA 01923
1-800-LIGHTBULB

Trade

Phone: 800-255-5042
Fax: 800-255-5043

National Accounts

Phone: 800-562-4671
Fax: 800-562-4674

OEM/Special Markets

Phone: 800-762-7191
Fax: 800-762-7192

Retail

Phone: 800-842-7010
Fax: 800-842-7011

SYLVANIA Lighting Services

Phone: 800-323-0572
Fax: 800-537-0784

Display/Optic

Phone: 888-677-2627
Fax: 855-543-1043

Canada

OSRAM SYLVANIA LTD.

2001 Drew Road
Mississauga, ON L5S 1S4
1-800-LIGHTBULB

Trade

Phone: 800-263-2852
Fax: 800-667-6772

OEM/Special Markets/Display/Optic

Phone: 800-265-2852
Fax: 800-667-6772

Retail

Phone: 800-720-2852
Fax: 800-667-6772

SYLVANIA Lighting Services

Phone: 800-663-4268
Fax: 866-239-1278

Mexico

OSRAM MEXICO

Tultitlan/Edo de Mexico
Phone: 011-52-55-58-99-18-50

ENCELIUM Technologies

United States

Phone: 201-928-2400
Fax: 201-928-4028

Canada

Phone: 905-731-7678
Fax: 905-731-1401

www.sylvania.com

 /sylvania

 /sylvania