

Ordering Guide

IL	L	XX	7	45	LB	MV	XX	GR	K
Product Series Industrial Linear	LED	Wattage 50, 100	CRI >70	Color Temp 4500K	Photometric Distribution Lambertian	Voltage 120-277V	Length 24 or 48 inches	Finish/Color Grey	KIT


Ordering Information

Item Number	Ordering Abbreviation	Power (W) ¹	CRI	Color Temp (CCT)	Distribution	Total Fixture Lumens	Lumens per Watt (LPW)	Length ² (inches)	BUG Rating
74851	IL-L-50-745-LB-MV-24-GR ³	50	>70	4500K	Lambertian	4100	>80	24	B2-U2-G1
74852	IL-L-100-745-LB-MV-48-GR	100	>70	4500K	Lambertian	8200	>80	48	B3-U3-G2
74854	IL-L-100-745-LB-MV-24-GR-K ⁴	100	>70	4500K	Lambertian	2 x 4100	>80	24	B2-U2-G1

- System wattage based on 120V input.
- Measurement taken on the lens.
- Each fixture is shipped with either a 50W or a 100W power supply.
- K is a kit consisting of two IL-L-50-745-LB-MV-24-GR luminaires and one power supply.

Photometric Information

Product Name: ProPoint™ Industrial Linear LED Luminaire-24" Lambertian Type Distribution

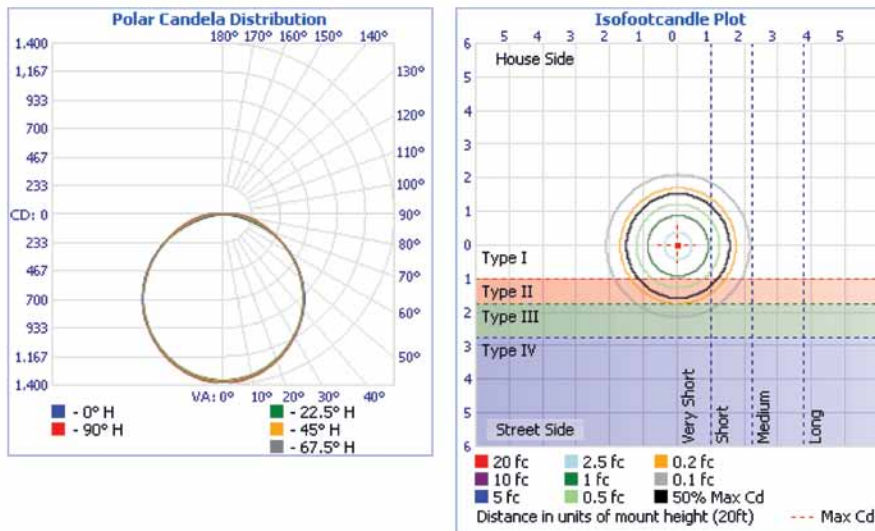

Product Name: ProPoint Industrial Linear LED Luminaire-48" Lambertian Type Distribution

