

**LIGHTS**

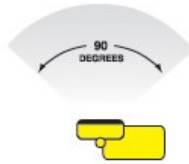
# 9430

## Remote Area Lighting System

- Polycarbonate Lens is light weight and impact resistant
- Maintenance Free LED Array with life expectancy of 50,000 hours
- Fully extendable mast with 360 degree rotating head
- Waterproof Rubber Activation Switch
- Mast Extension Lock
- Built Pelican Tough
- Unconditional Lifetime Guarantee



Black      Yellow


**9430**

**9450B**

**9460**

**9470**
**9430 RALS Specifications**
**Dimensions**

Head Length	Head Width	Head Depth
6.5" (16.5 cm)	7.87" (20 cm)	2.56" (6.5 cm)
Width Closed	Length Closed	Height Closed
7.87" (20 cm)	15.75" (40 cm)	9.06" (23 cm)
Mast Height Extended	Cord Length (Retracted)	Weight
32.28" (82 cm)	13.78" (35 cm)	22.05 lbs. (10 kg)

**Lamp Type/Brightness Test**

LED Type	LED Life	Tested Lumen Value	Brightness Settings
High Flux LED	50,000 hrs.	1000 (Low) 2000 (High)	2
Lamp Heads	Number of LED's	Beam Spread	
1	24	90 Degrees	

**Battery Type/Electrical Power**

Battery Type	Battery Burn Time	Battery Charging Time	Battery Life	Low Battery Warning
12v Rechargeable, Sealed	15 hours (Low) 8 hours (High)	7 hours	2000 Cycles	Intermittent Blinking
12 Volt Primary Sockets	12 Volt Auxiliary Sockets	Watts	Volts	
1	1	24	12	

**Approvals**

RoHS (Restriction of Hazardous Substances) Compliant

**Accessories**

Cat. #	Description	Sug. Retail
9430F	9430 RALS Charger	\$100.00
9430T	9430T Tripod Kit (with extension cord)	\$150.00
9431	9430 Tear-Off Back Pack	\$120.00
9432	9430 Back Pack	\$120.00
9434	Spare LED Head & T-Bar (Black or yellow)	n/a
9436	12/24v Vehicle Charger	\$120.00

