



CONNECTING YOUR TOMORROW.™

HOME : SALES LOCATIONS : PRODUCTS : CUSTOMER SERVICE : COMPANY : CONTACT US



PRODUCT QUICK SEARCH:

Penn Union Search:

Search

Competitor Search:

Search

Now In: [Penn-Union Products](#) → [Insulated Tap Connectors](#) → [Insulated Power Bars](#) → [IPBB-D - Black - Dual Entry](#) → [IPBB-NA600-4D - Aluminum Black Pre-Insulated Power Bar](#)



IPBB-NA600-4D - Aluminum Black Pre-Insulated Power Bar

For any combination of copper or aluminum

DUAL ENTRY

For splice, reducer and tap applications

Dual rated for both aluminum and copper conductors, simultaneous accommodations at 600V and 90°C

For use in areas such as troughs, gutters, panels, ducts and wireways

Only one conductor per set screw, and only one supply conductor per connector permitted.


Pre-insulated at factory - Eliminates the need for time consuming taping

Pre-Filled with oxide inhibitor and plugged ports - Prevents oxidation, moisture and contaminants from contact surfaces

Wide conductor range - Reduces inventory

Compact, versatile design - Use as a splice or splicer reducer

Product Drawing:

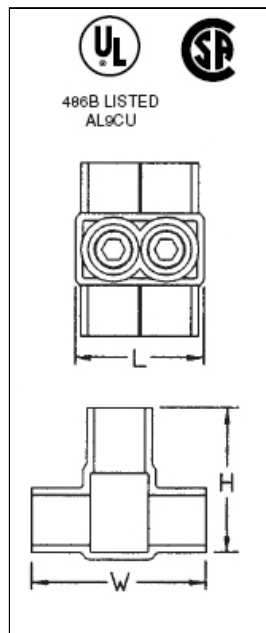

Click to expand.

Conductor Type	Conductor Range
Aluminum or Copper	4 Str. - 600 MCM

No. of Conductors: 4

Additional Details

Hex Key:	3/8
UL Listing:	UL 486B Listed AL9CU
CSA Listing:	Yes

Approximate Dimensions

H (in.):	2.69
L (in.):	5.15
W (in.):	3.00

© 2017 Penn-Union Corp. · 229 Waterford Street · Edinboro, PA 16412
Phone: 814-734-1631 · Fax: 814-734-4946 · info@penn-union.com

Designed & Developed by O-Web Technologies, Ltd.