


STRAIGHT SECTION

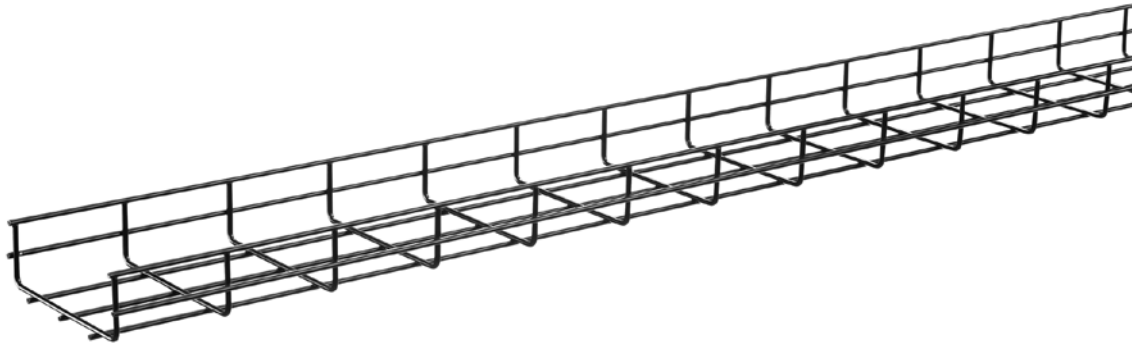

INDUSTRY STANDARDS

UL Classified for suitability as equipment ground conductor only.

NFPA 70, National Electrical Code, Article 392: Cable Trays; provides UL Classification and labels
 IEC 61537, Cable Tray Systems and Cable Ladder systems for Cable Management
 NEMA VE 1, Metal Cable Tray Systems, for materials, sizes and configurations

APPLICATION

The QUICK TRAY PRO™ cable tray routes cables through unused space while keeping them accessible for easy maintenance. Combine components to configure a system that meets application requirements.

SPECIFICATIONS

- Made of high-strength 5-mm or higher gauge steel wire
- T-weld top wire

FINISH

Pre-galvanized steel or black powder-coated finish.

BULLETIN: DQT

Standard Product

Catalog Number	AxBxC in./mm	Description	Finish	Load per 6-ft. span lbs./ft.	Cat6 Fill Rate* .19-in. dia. cable	Cat6A Fill Rate* .23-in. dia. cable
QTP2X4	2.00 x 4.00 x 120.00 51 x 102 x 3048	2 x 4-in. Straight Section	Pre-galvanized	43	108	99
QTP2X4BLK	2.00 x 4.00 x 120.00 51 x 102 x 3048	2 x 4-in. Straight Section	Black	43	108	99
QTP2X6	2.00 x 6.00 x 120.00 51 x 152 x 3048	2 x 6-in. Straight Section	Pre-galvanized	50	163	149
QTP2X6BLK	2.00 x 6.00 x 120.00 51 x 152 x 3048	2 x 6-in. Straight Section	Black	50	163	149
QTP2X8	2.00 x 8.00 x 120.00 51 x 203 x 3048	2 x 8-in. Straight Section	Pre-galvanized	52	218	200
QTP2X8BLK	2.00 x 8.00 x 120.00 51 x 203 x 3048	2 x 8-in. Straight Section	Black	52	218	200
QTP2X12	2.00 x 12.00 x 120.00 51 x 305 x 3048	2 x 12-in. Straight Section	Pre-galvanized	58	326	298
QTP2X12BLK	2.00 x 12.00 x 120.00 51 x 305 x 3048	2 x 12-in. Straight Section	Black	58	326	298
QTP2X16	2.00 x 16.00 x 120.00 51 x 406 x 3048	2 x 16-in. Straight Section	Pre-galvanized	70	439	402
QTP2X16BLK	2.00 x 16.00 x 120.00 51 x 406 x 3048	2 x 16-in. Straight Section	Black	70	439	402
QTP2X18	2.00 x 18.00 x 120.00 51 x 457 x 3048	2 x 18-in. Straight Section	Pre-galvanized	70	495	452
QTP2X18BLK	2.00 x 18.00 x 120.00 51 x 457 x 3048	2 x 18-in. Straight Section	Black	70	495	452
QTP2X20	2.00 x 20.00 x 120.00 51 x 508 x 3048	2 x 20-in. Straight Section	Pre-galvanized	73	550	503
QTP2X20BLK	2.00 x 20.00 x 120.00 51 x 508 x 3048	2 x 20-in. Straight Section	Black	73	550	503
QTP2X22	2.00 x 22.00 x 120.00 51 x 559 x 3048	2 x 22-in. Straight Section	Pre-galvanized	73	600	554
QTP2X22BLK	2.00 x 22.00 x 120.00 51 x 559 x 3048	2 x 22-in. Straight Section	Black	73	600	554
QTP2X24	2.00 x 24.00 x 120.00 51 x 610 x 3048	2 x 24-in. Straight Section	Pre-galvanized	75	660	604

Catalog Number	AxBxC in./mm	Description	Finish	Load per 6-ft. span lbs./ft.	Cat6 Fill Rate* .19-in. dia. cable	Cat6A Fill Rate* .23-in. dia. cable
QTP2X24BLK	2.00 x 24.00 x 120.00 51 x 610 x 3048	2 x 24-in. Straight Section	Black	75	660	604
QTP4X4	4.00 x 4.00 x 120.00 102 x 102 x 3048	4 x 4-in. Straight Section	Pre-galvanized	45	205	188
QTP4X4BLK	4.00 x 4.00 x 120.00 102 x 102 x 3048	4 x 4-in. Straight Section	Black	45	205	188
QTP4X6	4.00 x 6.00 x 120.00 102 x 152 x 3048	4 x 6-in. Straight Section	Pre-galvanized	49	310	285
QTP4X6BLK	4.00 x 6.00 x 120.00 102 x 152 x 3048	4 x 6-in. Straight Section	Black	49	310	285
QTP4X8	4.00 x 8.00 x 120.00 102 x 203 x 3048	4 x 8-in. Straight Section	Pre-galvanized	78	416	380
QTP4X8BLK	4.00 x 8.00 x 120.00 102 x 203 x 3048	4 x 8-in. Straight Section	Black	78	416	380
QTP4X12	4.00 x 12.00 x 120.00 102 x 305 x 3048	4 x 12-in. Straight Section	Pre-galvanized	78	621	568
QTP4X12BLK	4.00 x 12.00 x 120.00 102 x 305 x 3048	4 x 12-in. Straight Section	Black	78	621	568
QTP4X16	4.00 x 16.00 x 120.00 102 x 406 x 3048	4 x 16-in. Straight Section	Pre-galvanized	108	837	765
QTP4X16BLK	4.00 x 16.00 x 120.00 102 x 406 x 3048	4 x 16-in. Straight Section	Black	108	837	765
QTP4X18	4.00 x 18.00 x 120.00 102 x 457 x 3048	4 x 18-in. Straight Section	Pre-galvanized	116	942	862
QTP4X18BLK	4.00 x 18.00 x 120.00 102 x 457 x 3048	4 x 18-in. Straight Section	Black	116	942	862
QTP4X20	4.00 x 20.00 x 120.00 102 x 508 x 3048	4 x 20-in. Straight Section	Pre-galvanized	116	1047	958
QTP4X20BLK	4.00 x 20.00 x 120.00 102 x 508 x 3048	4 x 20-in. Straight Section	Black	116	1047	958
QTP4X22	4.00 x 22.00 x 120.00 102 x 559 x 3048	4 x 22-in. Straight Section	Pre-galvanized	116	1152	1054
QTP4X22BLK	4.00 x 22.00 x 120.00 102 x 559 x 3048	4 x 22-in. Straight Section	Black	116	1152	1054
QTP4X24	4.00 x 24.00 x 120.00 102 x 610 x 3048	4 x 24-in. Straight Section	Pre-galvanized	116	1257	1150
QTP4X24BLK	4.00 x 24.00 x 120.00 102 x 610 x 3048	4 x 24-in. Straight Section	Black	116	1257	1150
QTP6X8	6.00 x 8.00 x 120.00 152 x 203 x 3048	6 x 8-in. Straight Section	Pre-galvanized	116	623	570
QTP6X8BLK	6.00 x 8.00 x 120.00 152 x 203 x 3048	6 x 8-in. Straight Section	Black	116	623	570
QTP6X12	6.00 x 12.00 x 120.00 152 x 305 x 3048	6 x 12-in. Straight Section	Pre-galvanized	123	931	852
QTP6X12BLK	6.00 x 12.00 x 120.00 152 x 305 x 3048	6 x 12-in. Straight Section	Black	123	931	852
QTP6X16	6.00 x 16.00 x 120.00 152 x 406 x 3048	6 x 16-in. Straight Section	Pre-galvanized	123	1255	1148
QTP6X16BLK	6.00 x 16.00 x 120.00 152 x 406 x 3048	6 x 16-in. Straight Section	Black	123	1255	1148
QTP6X18	6.00 x 18.00 x 120.00 152 x 457 x 3048	6 x 18-in. Straight Section	Pre-galvanized	127	1413	1292
QTP6X18BLK	6.00 x 18.00 x 120.00 152 x 457 x 3048	6 x 18-in. Straight Section	Black	127	1413	1292
QTP6X20	6.00 x 20.00 x 120.00 152 x 508 x 3048	6 x 20-in. Straight Section	Pre-galvanized	127	1571	1437
QTP6X20BLK	6.00 x 20.00 x 120.00 152 x 508 x 3048	6 x 20-in. Straight Section	Black	127	1571	1437
QTP6X22	6.00 x 22.00 x 120.00 152 x 559 x 3048	6 x 22-in. Straight Section	Pre-galvanized	127	1728	1580
QTP6X22BLK	6.00 x 22.00 x 120.00 152 x 559 x 3048	6 x 22-in. Straight Section	Black	127	1728	1580
QTP6X24	6.00 x 24.00 x 120.00 152 x 610 x 3048	6 x 24-in. Straight Section	Pre-galvanized	150	1886	1726
QTP6X24BLK	6.00 x 24.00 x 120.00 152 x 610 x 3048	6 x 24-in. Straight Section	Black	150	1886	1726

* Based on 50% fill rate.