


## STRAIGHT SECTION

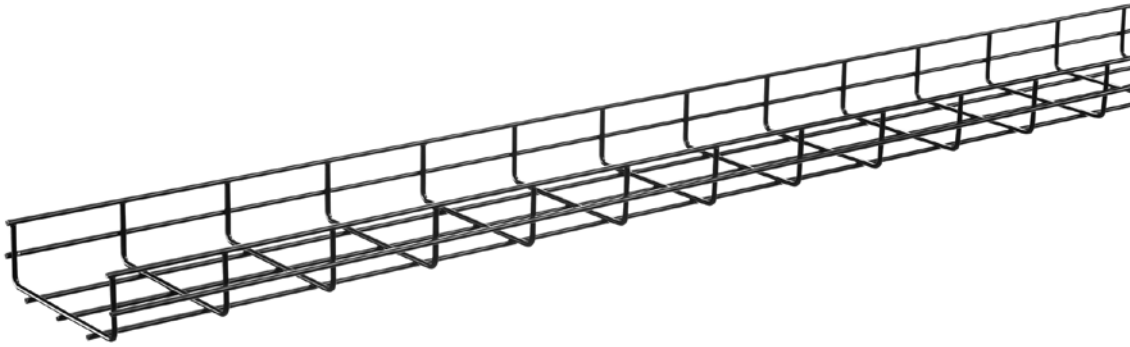

### INDUSTRY STANDARDS

UL Classified for suitability as equipment ground conductor only.

NFPA 70, National Electrical Code, Article 392: Cable Trays; provides UL Classification and labels  
IEC 61537, Cable Tray Systems and Cable Ladder systems for Cable Management  
NEMA VE 1, Metal Cable Tray Systems, for materials, sizes and configurations

### APPLICATION

The QUICK TRAY PRO™ cable tray routes cables through unused space while keeping them accessible for easy maintenance. Combine components to configure a system that meets application requirements.

### SPECIFICATIONS

- Made of high-strength 5-mm or higher gauge steel wire
- T-weld top wire

### FINISH

Pre-galvanized steel or black powder-coated finish.

**BULLETIN: DQT**

### Standard Product

Catalog Number	AxBxC in./mm	Description	Finish	Load per 6-ft. span lbs./ft.	Cat6 Fill Rate* .19-in. dia. cable	Cat6A Fill Rate* .23-in. dia. cable
QTP2X4	2.00 x 4.00 x 120.00 51 x 102 x 3048	2 x 4-in. Straight Section	Pre-galvanized	43	108	99
QTP2X4BLK	2.00 x 4.00 x 120.00 51 x 102 x 3048	2 x 4-in. Straight Section	Black	43	108	99
QTP2X6	2.00 x 6.00 x 120.00 51 x 152 x 3048	2 x 6-in. Straight Section	Pre-galvanized	50	163	149
QTP2X6BLK	2.00 x 6.00 x 120.00 51 x 152 x 3048	2 x 6-in. Straight Section	Black	50	163	149
QTP2X8	2.00 x 8.00 x 120.00 51 x 203 x 3048	2 x 8-in. Straight Section	Pre-galvanized	52	218	200
QTP2X8BLK	2.00 x 8.00 x 120.00 51 x 203 x 3048	2 x 8-in. Straight Section	Black	52	218	200
QTP2X12	2.00 x 12.00 x 120.00 51 x 305 x 3048	2 x 12-in. Straight Section	Pre-galvanized	58	326	298
QTP2X12BLK	2.00 x 12.00 x 120.00 51 x 305 x 3048	2 x 12-in. Straight Section	Black	58	326	298
QTP2X16	2.00 x 16.00 x 120.00 51 x 406 x 3048	2 x 16-in. Straight Section	Pre-galvanized	70	439	402
QTP2X16BLK	2.00 x 16.00 x 120.00 51 x 406 x 3048	2 x 16-in. Straight Section	Black	70	439	402
QTP2X18	2.00 x 18.00 x 120.00 51 x 457 x 3048	2 x 18-in. Straight Section	Pre-galvanized	70	495	452
QTP2X18BLK	2.00 x 18.00 x 120.00 51 x 457 x 3048	2 x 18-in. Straight Section	Black	70	495	452
QTP2X20	2.00 x 20.00 x 120.00 51 x 508 x 3048	2 x 20-in. Straight Section	Pre-galvanized	73	550	503
QTP2X20BLK	2.00 x 20.00 x 120.00 51 x 508 x 3048	2 x 20-in. Straight Section	Black	73	550	503
QTP2X22	2.00 x 22.00 x 120.00 51 x 559 x 3048	2 x 22-in. Straight Section	Pre-galvanized	73	600	554
QTP2X22BLK	2.00 x 22.00 x 120.00 51 x 559 x 3048	2 x 22-in. Straight Section	Black	73	600	554
QTP2X24	2.00 x 24.00 x 120.00 51 x 610 x 3048	2 x 24-in. Straight Section	Pre-galvanized	75	660	604

Catalog Number	AxBxC in./mm	Description	Finish	Load per 6-ft. span lbs./ft.	Cat6 Fill Rate* .19-in. dia. cable	Cat6A Fill Rate* .23-in. dia. cable
QTP2X24BLK	2.00 x 24.00 x 120.00 51 x 610 x 3048	2 x 24-in. Straight Section	Black	75	660	604
QTP4X4	4.00 x 4.00 x 120.00 102 x 102 x 3048	4 x 4-in. Straight Section	Pre-galvanized	45	205	188
QTP4X4BLK	4.00 x 4.00 x 120.00 102 x 102 x 3048	4 x 4-in. Straight Section	Black	45	205	188
QTP4X6	4.00 x 6.00 x 120.00 102 x 152 x 3048	4 x 6-in. Straight Section	Pre-galvanized	49	310	285
QTP4X6BLK	4.00 x 6.00 x 120.00 102 x 152 x 3048	4 x 6-in. Straight Section	Black	49	310	285
QTP4X8	4.00 x 8.00 x 120.00 102 x 203 x 3048	4 x 8-in. Straight Section	Pre-galvanized	78	416	380
QTP4X8BLK	4.00 x 8.00 x 120.00 102 x 203 x 3048	4 x 8-in. Straight Section	Black	78	416	380
QTP4X12	4.00 x 12.00 x 120.00 102 x 305 x 3048	4 x 12-in. Straight Section	Pre-galvanized	78	621	568
QTP4X12BLK	4.00 x 12.00 x 120.00 102 x 305 x 3048	4 x 12-in. Straight Section	Black	78	621	568
QTP4X16	4.00 x 16.00 x 120.00 102 x 406 x 3048	4 x 16-in. Straight Section	Pre-galvanized	108	837	765
QTP4X16BLK	4.00 x 16.00 x 120.00 102 x 406 x 3048	4 x 16-in. Straight Section	Black	108	837	765
QTP4X18	4.00 x 18.00 x 120.00 102 x 457 x 3048	4 x 18-in. Straight Section	Pre-galvanized	116	942	862
QTP4X18BLK	4.00 x 18.00 x 120.00 102 x 457 x 3048	4 x 18-in. Straight Section	Black	116	942	862
QTP4X20	4.00 x 20.00 x 120.00 102 x 508 x 3048	4 x 20-in. Straight Section	Pre-galvanized	116	1047	958
QTP4X20BLK	4.00 x 20.00 x 120.00 102 x 508 x 3048	4 x 20-in. Straight Section	Black	116	1047	958
QTP4X22	4.00 x 22.00 x 120.00 102 x 559 x 3048	4 x 22-in. Straight Section	Pre-galvanized	116	1152	1054
QTP4X22BLK	4.00 x 22.00 x 120.00 102 x 559 x 3048	4 x 22-in. Straight Section	Black	116	1152	1054
QTP4X24	4.00 x 24.00 x 120.00 102 x 610 x 3048	4 x 24-in. Straight Section	Pre-galvanized	116	1257	1150
QTP4X24BLK	4.00 x 24.00 x 120.00 102 x 610 x 3048	4 x 24-in. Straight Section	Black	116	1257	1150
QTP6X8	6.00 x 8.00 x 120.00 152 x 203 x 3048	6 x 8-in. Straight Section	Pre-galvanized	116	623	570
QTP6X8BLK	6.00 x 8.00 x 120.00 152 x 203 x 3048	6 x 8-in. Straight Section	Black	116	623	570
QTP6X12	6.00 x 12.00 x 120.00 152 x 305 x 3048	6 x 12-in. Straight Section	Pre-galvanized	123	931	852
QTP6X12BLK	6.00 x 12.00 x 120.00 152 x 305 x 3048	6 x 12-in. Straight Section	Black	123	931	852
QTP6X16	6.00 x 16.00 x 120.00 152 x 406 x 3048	6 x 16-in. Straight Section	Pre-galvanized	123	1255	1148
QTP6X16BLK	6.00 x 16.00 x 120.00 152 x 406 x 3048	6 x 16-in. Straight Section	Black	123	1255	1148
QTP6X18	6.00 x 18.00 x 120.00 152 x 457 x 3048	6 x 18-in. Straight Section	Pre-galvanized	127	1413	1292
QTP6X18BLK	6.00 x 18.00 x 120.00 152 x 457 x 3048	6 x 18-in. Straight Section	Black	127	1413	1292
QTP6X20	6.00 x 20.00 x 120.00 152 x 508 x 3048	6 x 20-in. Straight Section	Pre-galvanized	127	1571	1437
QTP6X20BLK	6.00 x 20.00 x 120.00 152 x 508 x 3048	6 x 20-in. Straight Section	Black	127	1571	1437
QTP6X22	6.00 x 22.00 x 120.00 152 x 559 x 3048	6 x 22-in. Straight Section	Pre-galvanized	127	1728	1580
QTP6X22BLK	6.00 x 22.00 x 120.00 152 x 559 x 3048	6 x 22-in. Straight Section	Black	127	1728	1580
QTP6X24	6.00 x 24.00 x 120.00 152 x 610 x 3048	6 x 24-in. Straight Section	Pre-galvanized	150	1886	1726
QTP6X24BLK	6.00 x 24.00 x 120.00 152 x 610 x 3048	6 x 24-in. Straight Section	Black	150	1886	1726

\* Based on 50% fill rate.

### SPLICE KIT



Splice Kits are used for bolting turns, bends and tees; connecting QUICK TRAY PRO™ sections; and fastening splice bars. Kit includes three-piece staked bolt, washer and nut.

**BULLETIN: DQT**

Catalog Number	AxBxC in./mm	Description	Pkg. Qty.
QTPBNWK	2.00 x 4.00 x 2.00 51 x 102 x 51	Splice Kit (Zinc)	50
QTPBNWKBLK	2.00 x 4.00 x 2.00 51 x 102 x 51	Splice Kit (Black)	50

### SPLICE WASHER



QUICK TRAY PRO Splice Washers are used with QTPBNWK/ QTPBNWKBLK Splice Kits for bolting turns, bends, and tees; connecting tray sections; and fastening splice bars.

**BULLETIN: DQT**

Catalog Number	AxBxC in./mm	Description	Finish	Pkg. Qty.
QTPSSW3	4.00 x 4.00 x 8.00 102 x 102 x 203	Splice Washer	Pre-galvanized	50
QTPSSW3BLK	4.00 x 4.00 x 8.00 102 x 102 x 203	Splice Washer	Black	50

### SPLICE BARS



QUICK TRAY PRO Splice Bars provide extra support and stability to tray sides when connecting tray sections with splice washers. Universal bars can be cut to fit with bolt cutters and bent for use in tees and elbows. Made of plated steel. Requires QTPSSW3/ QTPSSW3BLK Splice Washers and QTPBNWK/QTPBNWKBLK Splice Kits to fasten to side of tray.

**BULLETIN: DQT**

Catalog Number	AxBxC in./mm	Description	Pkg. Qty.
QTPUS10	4.00 x 13.00 x 4.00 102 x 330 x 102	Splice Bar, 10 in. Universal (Zinc)	50
QTPUS10BLK	4.00 x 13.00 x 4.00 102 x 330 x 102	Splice Bar, 10 in. Universal (Black)	50
QTP90TKIT	1.00 x 5.00 x 5.00 25 x 127 x 127	Includes: (2) 90° bends; (8) washers, (8) nuts, (8) bolts (Zinc)	1
QTP90TKITBLK	1.00 x 5.00 x 5.00 25 x 127 x 127	Includes: (2) 90° bends; (8) washers, (8) nuts, (8) bolts (Black)	1

### TRAPEZE HANGING CLIP



For trapeze hung QUICK TRAY PRO™ installations. Use with 1/4- or 3/8-in. threaded rod; obtain locally. Poly grommet retains tray in slot-unsnap to detach one side of tray for loading cables. Corrosion-resistant pre-galvanized finish.

**BULLETIN: DQT**

Catalog Number	AxBxC in./mm	Description	Pkg. Qty.
QTPTH	3.00 x 6.00 x 14.00 76 x 152 x 356	Trapeze Hanging Clips, Pre-galvanized	50
QTPTHBLK	3.00 x 6.00 x 14.00 76 x 152 x 356	Trapeze Hanging Clips, Black	50

### C-BRACKET



For QUICK TRAY PRO installations under ceiling or overhangs. Use with tray widths up to 12 in. (305 mm). To secure tray to bracket, use one QTPSSW3/QTPSSW3BLK Splice Washer and one QTPBNWK/QTPBNWKBLK Splice Kit on sizes up to 8 in. (203 mm); use two on 12-in. (305-mm) trays. Can be stacked for multi-level tray installations. Corrosion resistant plated finish.

**BULLETIN: DQT**

Catalog Number	AxBxC in./mm	Description	Finish	Tray Width in./mm
QTPCB4	8.00 x 1.00 x 4.00 203 x 25 x 102	C-Bracket	Pre-galvanized	4 102
QTPCB4BLK	8.00 x 1.00 x 4.00 203 x 25 x 102	C-Bracket	Black	4 102
QTPCB8	8.00 x 1.00 x 8.00 203 x 25 x 203	C-Bracket	Pre-galvanized	8 203
QTPCB8BLK	8.00 x 1.00 x 8.00 203 x 25 x 203	C-Bracket	Black	8 203
QTPCB12	8.00 x 1.00 x 12.00 203 x 25 x 305	C-Bracket	Pre-galvanized	12 305
QTPCB12BLK	8.00 x 1.00 x 12.00 203 x 25 x 305	C-Bracket	Black	12 305

### CENTER HANGERS



Use with up to 1/2-in. threaded rod (obtain locally). Only one rod needed to suspend tray. Snap-on attachment holds QUICK TRAY PRO cable tray secure without nuts and bolts. For use with 4- to 24-in. (102- to 610-mm) tray widths. Can be used for multiple-level installations; 1/2-in. threaded rod recommended. Corrosion-resistant plated finish.

**BULLETIN: DQT**

Catalog Number	AxBxC in./mm	Description	Finish	Tray Width in./mm
QTPCH4	7.50 x 4.00 x 1.00 191 x 102 x 25	Center Hanger	Pre-galvanized	4 102
QTPCH4BLK	7.50 x 4.00 x 1.00 191 x 102 x 25	Center Hanger	Black	4 102
QTPCH12	7.50 x 12.00 x 1.00 191 x 305 x 25	Center Hanger	Pre-galvanized	12 305
QTPCH12BLK	7.50 x 12.00 x 1.00 191 x 305 x 25	Center Hanger	Black	12 305
QTPCH24	7.50 x 24.00 x 1.00 191 x 610 x 25	Center Hanger	Pre-galvanized	24 610
QTPCH24BLK	7.50 x 24.00 x 1.00 191 x 610 x 25	Center Hanger	Black	24 610

**L-BRACKETS**


L-Brackets mount directly to wall for overhead mounting. Corrosion-resistant plated finish. Fasten QUICK TRAY PRO™ to bracket with one QTPSSW3/QTPSSW3BLK Splice Washer and one QTPBNWK/QTPBNWKBLK Splice Kit on sizes up to 8 in. (203 mm); use two on 12-in. (305-mm) trays.

**BULLETIN: DQT**

Catalog Number	AxBxC in./mm	Description	Finish
QTPLB4	6.00 x 1.00 x 4.00 152 x 25 x 102	4-in. L-Bracket	Pre-galvanized
QTPLB4BLK	6.00 x 1.00 x 4.00 152 x 25 x 102	4-in. L-Bracket	Black
QTPLB8	6.00 x 1.00 x 8.00 152 x 25 x 203	8-in. L-Bracket	Pre-galvanized
QTPLB8BLK	6.00 x 1.00 x 8.00 152 x 25 x 203	8-in. L-Bracket	Black
QTPLB12	6.00 x 1.00 x 12.00 152 x 25 x 305	12-in. L-Bracket	Pre-galvanized
QTPLB12BLK	6.00 x 1.00 x 12.00 152 x 25 x 305	12-in. L-Bracket	Black

**REINFORCED WALL BRACKET**


For heavy-duty QUICK TRAY PRO applications. Mounts on 1-5/8-in. wide metal channel. To secure tray to bracket, use one QTPSSW3/QTPSSW3BLK Splice Washer and one QTPBNWK/QTPBNWKBLK Splice Kit on sizes up to 8 in. (203 mm); use two on 12-in. (305-mm) and wider trays. Made of plated steel for corrosion resistance.

**BULLETIN: DQT**

Catalog Number	AxBxC in./mm	Description	Finish	Width in./mm
QTPRW4	3.00 x 1.00 x 4.00 76 x 25 x 102	Reinforced Wall Bracket	Pre-galvanized	4 102
QTPRW4BLK	3.00 x 1.00 x 4.00 76 x 25 x 102	Reinforced Wall Bracket	Black	4 102
QTPRW6	3.00 x 1.00 x 6.00 76 x 25 x 152	Reinforced Wall Bracket	Pre-galvanized	6 152
QTPRW6BLK	3.00 x 1.00 x 6.00 76 x 25 x 152	Reinforced Wall Bracket	Black	6 152
QTPRW8	4.00 x 1.00 x 8.00 102 x 25 x 203	Reinforced Wall Bracket	Pre-galvanized	8 203
QTPRW8BLK	4.00 x 1.00 x 8.00 102 x 25 x 203	Reinforced Wall Bracket	Black	8 203
QTPRW12	6.00 x 1.00 x 12.00 152 x 25 x 305	Reinforced Wall Bracket	Pre-galvanized	12 305
QTPRW12BLK	6.00 x 1.00 x 12.00 152 x 25 x 305	Reinforced Wall Bracket	Black	12 305
QTPRW16	9.00 x 1.00 x 16.00 229 x 25 x 406	Reinforced Wall Bracket	Pre-galvanized	16 406
QTPRW16BLK	9.00 x 1.00 x 16.00 229 x 25 x 406	Reinforced Wall Bracket	Black	16 406
QTPRW18	3.00 x 8.00 x 3.00 76 x 203 x 76	Reinforced Wall Bracket	Pre-galvanized	18 457
QTPRW18BLK	3.00 x 8.00 x 3.00 76 x 203 x 76	Reinforced Wall Bracket	Black	18 457
QTPRW20	9.00 x 1.00 x 20.00 229 x 25 x 508	Reinforced Wall Bracket	Pre-galvanized	20 508
QTPRW20BLK	9.00 x 1.00 x 20.00 229 x 25 x 508	Reinforced Wall Bracket	Black	20 508
QTPRW24	9.00 x 1.00 x 24.00 229 x 25 x 610	Reinforced Wall Bracket	Pre-galvanized	24 610
QTPRW24BLK	9.00 x 1.00 x 24.00 229 x 25 x 610	Reinforced Wall Bracket	Black	24 610

### DIVIDER STRIP



For wire separation within a single QUICK TRAY PRO™ cable tray. 5-ft. (1.5-m) long strips are available in 2-, 4- and 6-in. (51-, 102- and 152-mm) heights. To secure divider strips to tray, use QTPSSW3/QTPSSW3BLK Splice Washer and QTPBNWK/QTPBNWKBLK Splice Kit for each strip.

**BULLETIN: DQT**

Catalog Number	AxBxC in./mm	Description	Finish	Tray Height in./mm
QTPDS2	2.00 x 1.00 x 60.00 51 x 25 x 1524	Divider Strip	Pre-galvanized	2 51
QTPDS2BLK	2.00 x 1.00 x 60.00 51 x 25 x 1524	Divider Strip	Black	2 51
QTPDS4	4.00 x 1.00 x 60.00 102 x 25 x 1524	Divider Strip	Pre-galvanized	4 102
QTPDS4BLK	4.00 x 1.00 x 60.00 102 x 25 x 1524	Divider Strip	Black	4 102
QTPDS6	6.00 x 1.00 x 60.00 152 x 25 x 1524	Divider Strip	Pre-galvanized	6 152
QTPDS6BLK	6.00 x 1.00 x 60.00 152 x 25 x 1524	Divider Strip	Black	6 152

### SIDE-ACTION BOLT CUTTER



The QUICK TRAY PRO Side-Action Bolt Cutter insures a flush cut and helps create a protective coating for the new cut.

**BULLETIN: DQT**

Catalog Number	AxBxC in./mm	Description
QTPBC	12.00 x 1.00 x 0.50 305 x 25 x 13	Side Action Bolt Cutter

### VERTICAL DOWN



The QUICK TRAY PRO Vertical Down protects cables when exiting and entering tray. Built-in hold down method for side mount. Attached with 1/4 in. hardware for center mount.

**BULLETIN: DQT**

Catalog Number	AxBxC in./mm	Description	Finish
QTPVD	1.00 x 8.00 x 11.00 25 x 203 x 279	Vertical Down	Pre-galvanized
QTPVDBLK	1.00 x 8.00 x 11.00 25 x 203 x 279	Vertical Down	Black

### WALL-TERMINATION BRACKET



Fastens the end of QUICK TRAY PRO™ cable tray to a wall. Attach to tray with QTPSSW3/QTPSSW3BLK Splice Washers and QTPBNWK/QTPBNWKBLK Splice Kits.

**BULLETIN: DQT**

Catalog Number	AxBxC in./mm	Description	Finish
QTPWTB	3.00 x 12.00 x 3.00 76 x 305 x 76	Wall-Termination Bracket, 12 in. (305 mm)	Pre-galvanized
QTPWTBBLK	3.00 x 12.00 x 3.00 76 x 305 x 76	Wall-Termination Bracket, 12 in. (305 mm)	Black

### POLYMER INSERT



Polymer inserts provide continuous support for the cables when used as a tray liner. This flame retardant polymer material is prescored at the factory to fit in all standard width QUICK TRAY PRO cable trays.

**BULLETIN: DQT**

Catalog Number	Description	Tray Width in./mm
QTP4INST	4 x 120-in. (102 x 3048-mm) Polymer Insert	4 102
QTP6INST	6 x 120-in. (152 x 3048-mm) Polymer Insert	6 152
QTP8INST	8 x 120-in. (203 x 3048-mm) Polymer Insert	8 203
QTP12INST	12 x 120-in. (305 x 3048-mm) Polymer Insert	12 305
QTP16INST	16 x 120-in. (406 x 3048-mm) Polymer Insert	16 406
QTP18INST	18 x 120-in. (457 x 3048-mm) Polymer Insert	18 457
QTP20INST	20 x 120-in. (508 x 3048-mm) Polymer Insert	20 508
QTP24INST	24 x 120-in. (610 x 3048-mm) Polymer Insert	24 610

## Notes