

**TELEPHONE CABINET, TYPE 1**

**FEATURES**

- Continuous hinge
- Tumbler lock with key
- Flush or surface mounting
- 3/4-in.-thick plywood mounting panel included

**SPECIFICATIONS**

- 16, 14 or 12 gauge galvanized steel body, mild steel door

**FINISH**

- ANSI 61 gray polyester powder paint on front only

**ACCESSORIES**

See also *Accessories*.  
Replacement Tumbler Lock

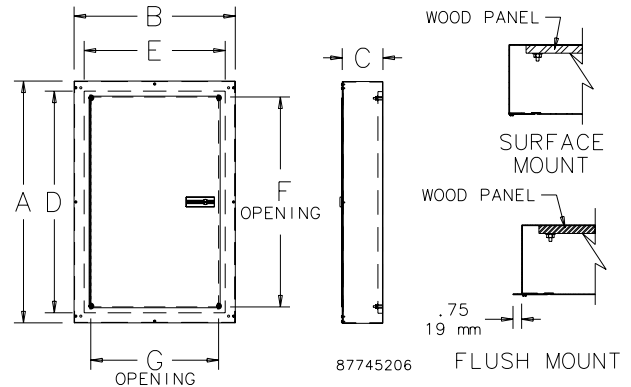
**BULLETIN: T90**
**INDUSTRY STANDARDS**

UL 50, 50E Listed; Type 1; File No. E27567  
cUL Listed per CSA C22.2 No 40; Type 1; File No. E27567

NEMA/EEMAC Type 1  
IEC 60529, IP30

**APPLICATION**

Telephone Cabinets house telephone and communication cable terminations as well as electrical controls and instruments in indoor applications.


**Standard Product**

Catalog Number	AxBxC in./mm	Mount	Panel Size D x E in./mm	Nominal Door Size F in./mm	Nominal Door Size G in./mm
ATC10104S	10.00 x 10.00 x 4.00	Surface	7.00 x 7.00	6.80	6.75
	254 x 254 x 102		178 x 178	173	171
ATC10104F	10.00 x 10.00 x 4.00	Flush	7.00 x 7.00	6.80	6.75
	254 x 254 x 102		178 x 178	173	171
ATC12124S	12.00 x 12.00 x 4.00	Surface	9.00 x 9.00	8.30	8.25
	305 x 305 x 102		229 x 229	211	210
ATC12124F	12.00 x 12.00 x 4.00	Flush	9.00 x 9.00	8.30	8.25
	305 x 305 x 102		229 x 229	211	210
ATC18124S	18.00 x 12.00 x 4.00	Surface	15.00 x 9.00	14.30	8.25
	455 x 305 x 102		381 x 229	363	210
ATC18124F	18.00 x 12.00 x 4.00	Flush	15.00 x 9.00	14.30	8.25
	455 x 305 x 102		381 x 229	363	210
ATC18184S	18.00 x 18.00 x 4.00	Surface	15.00 x 15.00	14.30	14.25
	455 x 455 x 102		381 x 381	363	362
ATC18184F	18.00 x 18.00 x 4.00	Flush	15.00 x 15.00	14.30	14.25
	455 x 455 x 102		381 x 381	363	362
ATC24184S	24.00 x 18.00 x 4.00	Surface	21.00 x 15.00	20.30	14.25
	610 x 455 x 102		533 x 381	516	362
ATC24184F	24.00 x 18.00 x 4.00	Flush	21.00 x 15.00	20.30	14.25
	610 x 455 x 102		533 x 381	516	362
ATC24244S	24.00 x 24.00 x 4.00	Surface	21.00 x 21.00	19.30	19.14
	610 x 610 x 102		533 x 533	490	486
ATC24244F	24.00 x 24.00 x 4.00	Flush	21.00 x 21.00	19.30	19.14
	610 x 610 x 102		533 x 533	490	486
ATC30244S	30.00 x 24.00 x 4.00	Surface	27.00 x 21.00	25.30	19.14
	762 x 610 x 102		686 x 533	643	486
ATC30244F	30.00 x 24.00 x 4.00	Flush	27.00 x 21.00	25.30	19.14
	762 x 610 x 102		686 x 533	643	486
ATC30304S	30.00 x 30.00 x 4.00	Surface	27.00 x 27.00	25.30	25.14
	762 x 762 x 102		686 x 686	643	639
ATC36244S	36.00 x 24.00 x 4.00	Surface	33.00 x 21.00	31.30	19.14
	914 x 610 x 102		838 x 533	795	486
ATC36244F	36.00 x 24.00 x 4.00	Flush	33.00 x 21.00	31.30	19.14
	914 x 610 x 102		838 x 533	795	486