



# Low Pressure Sodium - SOX

## SOX 18W 1SL

High energy efficiency low pressure sodium lamps for indoor and outdoor applications.

### Product data

#### • General Characteristics

Base	DC Bayonet
Bulb	T15 [Diameter: 1.97 inch]
Operating Position	Base Up +/- 110 D [Hanging +/-110D or Base Up (BU)]
Life to 5% failures	6000 hr
Life to 20% failures	12000 hr
RatedAvgLife(See Family Notes)	18000 hr

#### • Light Technical Characteristics

Color Temperature	1800 K
Initial Lumens	1800 Lm
Luminous Efficacy	100 Lm/W
Lamp EM	
Lumen Maintenance 2000h	95 %
Lumen Maintenance 5000h	90 %
Luminance Average EM	7 cd/cm <sup>2</sup>

#### • Electrical Characteristics

Watts	18 W
Lamp Wattage	18 W
Lamp Voltage	57 V
Lamp Current EM	0.33 A
Dimmable	No

#### • Environmental Characteristics

Mercury (Hg) Content	0 mg
----------------------	------

#### • Luminaire Design Requirements

Cap-Base Temperature	150 (max) C
Bulb Temperature	150 (max) C

#### • Product Dimensions

Overall Length C	216 (max) mm
Diameter D	52 (max) mm

#### • Product Data



Product number	234047
Full product name	MASTER SOX-E 18W BY22d 1SL
Short product name	MASTER SOX-E 18W BY22d 1SL/12
Pieces per Sku	1
eop_pck_cfg	12
Skus/Case	12
Bar code on pack	8711500600097
Bar code on case	8711500600103
Logistics code(s)	928145200028
tpd_ilcos_cd	LSE-E18-BY22d
eop_net_weight_pp	150.000 gr

### Dimensional drawing

## Dimensional drawing

### BY22d, T50/T65

Product	C (Max)	D (Max)
SOX E 18W BY22d T50	216	52

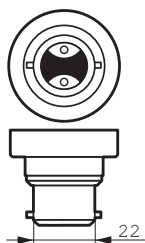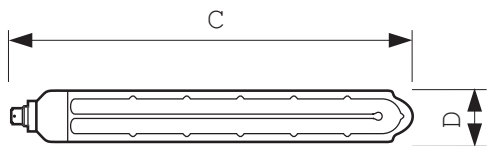

BY22d



© 2012 Koninklijke Philips Electronics N.V.  
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

[www.philips.com/lighting](http://www.philips.com/lighting)

2012, August 4  
data subject to change