



Candle LED

3BA11/END/2700-E12 DIM 8/1

Philips Candle Dimmable LED Lamps offer decorative energy saving ambience with the elegant effect of incandescent candles. Available in bent, blunt and flame tip candles, their unique design provides light in all directions, giving lighting designers a long life alternative to standard incandescent sources.

Product data

• General Characteristics

Cap-Base	E12
Bulb	BA11
Bulb Finish	Clear
Rated Avg. Life (Hours)	25000 hr
Rated Avg. Life (Hours)	25000 hr
Rated Lifetime (years)	22.8 an

• Light Technical Characteristics

Color Code	WW
Color Designation	Warm White
Correlated Color Temperature	2700 K
CRI	92
Color Temp. (Kelvin)	2700 K [CCT 2700K]
Rated Luminous Flux	180 Lm

• Electrical Characteristics

Wattage	3 W
Wattage Technical	3 W
Voltage	120 V
Power Factor	0.6 -
Lamp Current mA	34 mA

Dimmable	Yes
Wattage Equivalent	25 W
Rated Wattage	3.0 W
Starting Time	0.5 s

• Measuring Conditions

Switching cycle	50000x
-----------------	--------

• Product Dimensions

Diameter D	35 mm
Overall Length C	102 mm
Overall Length C [inch]	4.016 (max) in

• Product Data


Product number	420422
Full product name	3BA11/END/2700-E12 DIM 8/1
Short product name	3BA11/END/2700-E12 DIM 8/1
Pieces per Sku	1
eop_pck_cfg	8
Skus/Case	8
Bar code on pack	46677420420
Bar code on case	50046677420425
Logistics code(s)	929000222804
eop_net_weight_pp	0.050 kg




PHILIPS

sense and simplicity


Dimensional drawing

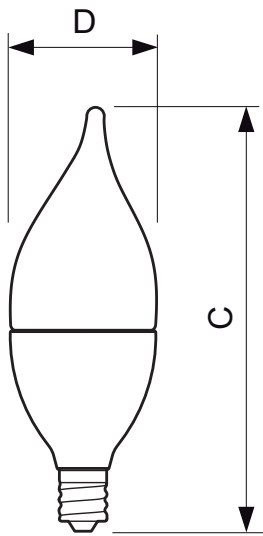

3W E12 BA11

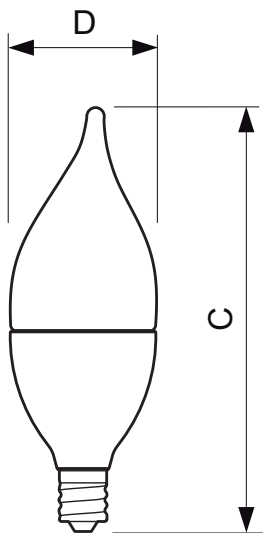

3W E12 BA11

 

E12



© 2012 Koninklijke Philips Electronics N.V.
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

www.philips.com/lighting

2012, August 14
data subject to change