



# Candle LED

3F15/END/2700-E26 DIM 8/1

Philips Candle Dimmable LED Lamps offer decorative energy saving ambience with the elegant effect of incandescent candles. Available in bent, blunt and flame tip candles, their unique design provides light in all directions, giving lighting designers a long life alternative to standard incandescent sources.

## Product data

### • General Characteristics

Cap-Base	E26
Bulb	F15
Bulb Finish	Clear

### • Light Technical Characteristics

Color Code	WW
Color Designation	Warm White
CRI	92
Color Temp. (Kelvin)	2700 K [CCT 2700K]
Rated Luminous Flux	200 Lm

### • Electrical Characteristics

Wattage	3 W
Wattage Technical	3 W
Voltage	120 V
Power Factor	0.6 -
Lamp Current mA	37 mA
Dimmable	Yes
Wattage Equivalent	25 W
Rated Wattage	3.0 W
Starting Time	0.5 s

### • Measuring Conditions

Switching cycle	50000x
-----------------	--------

### • Product Dimensions

Diameter D	63 mm
Overall Length C	112 mm
Overall Length C	4.41 (max) in
[inch]	

### • Product Data


Product number	420430
Full product name	3F15/END/2700-E26 DIM 8/1
Short product name	3F15/END/2700-E26 DIM 8/1
Pieces per Sku	1
eop_pck_cfg	8
Skus/Case	8
Bar code on pack	46677420437
Bar code on case	50046677420432
Logistics code(s)	929000222904
eop_net_weight_pp	0.055 kg




# PHILIPS

sense and simplicity

## Dimensional drawing

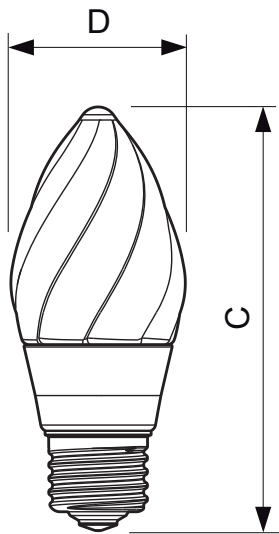

3W E26 F15

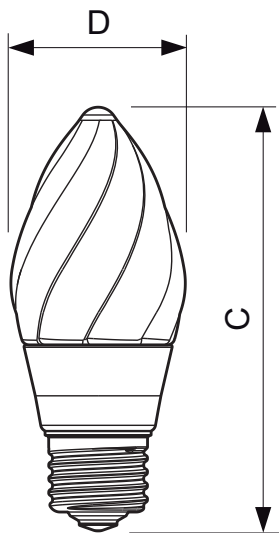

3W E26 F15



E26



© 2012 Koninklijke Philips Electronics N.V.  
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

[www.philips.com/lighting](http://www.philips.com/lighting)

2012, August 14  
data subject to change