



# MasterColor® CDM ED17 Protected

MasterColor CDM 100W/940 Med ED17P CL ALTO+FB

Direct retrofit with immediate energy savings! Range of protected, high-efficiency long life ceramic metal halide lamps with a stable color over lifetime and a crisp, sparkling light to be used in open fixtures.

## Product data

### • General Characteristics

Base	Medium [Single Contact Medium Screw]
Base Information	Brass [Brass Base]
Bulb	ED17P [Protected]
Bulb Material	Hard Glass
Bulb Finish	Clear
Operating Position	Universal [Any or Universal (U)]
Main Application	General Lighting
RatedAvgLife(See Family Notes)	20000 hr

### • Light Technical Characteristics

Color Code	940 [CCT of 4000K]
Color Rendering Index	92 Ra8
Color Designation	Deluxe Cool White
Color Temperature	4000 K
Color Temperature technical	3800 (min), 4000 (nom), 4200 (max) K
Chromaticity Coordinate X	374 (min), 383 (nom), 392 (max) -
Chromaticity Coordinate Y	366 (min), 372 (nom), 378 (max) -
Initial Lumens	8200 Lm
Luminous Efficacy Lamp	82 Lm/W
Lumen Maintenance 2000h	90 %
Lumen Maintenance 5000h	81 %
Design Mean Lumens	6150 Lm

### • Electrical Characteristics

Watts	100 W
-------	-------

Lamp Voltage	104 V
Lamp Current	1.1 A
Ignition Time	10 (max) s
Ignition Supply Voltage	235 V
Re-ignition Time [min]	10 (max) min

### • Environmental Characteristics

Mercury (Hg) Content	5.9 (max) mg
Picogram per Lumen Hour	46.1 p/LuHr

### • UV-related Characteristics

Damage Factor D/fc	.41 -
PET (NIOSH)	286.7 h500lx
UV A	14.8 mW/cm2
UV B	0.02 mW/cm2
UV C	0.01 mW/cm2

### • Luminaire Design Requirements

Cap-Base Temperature	190 (max) C
Bulb Temperature	400 (max) C

### • Product Dimensions

Light Center Length L	3.438 in
Max Overall Length (MOL) - C	5.438 (max) in
Diameter D	2.125 in

# PHILIPS

sense and simplicity

• Footnotes

Footnotes HID 902 [Exclusive to Philips Lighting Company.]

• Product Data

Product number 360602  
 Full product name MasterColor CDM 100W/940 Med ED17P CL ALTO+FB

Short product name CDM 100W/940 Med ED17P CL ALTO+FB  
 Pieces per Sku 1  
 eop\_pck\_cfg 12  
 Skus/Case 12  
 Bar code on pack 46677360603  
 Bar code on case 50046677360608  
 Logistics code(s) 928601138001  
 eop\_net\_weight\_pp 0.001 kg

## Warnings and Safety


- R "WARNING: These lamps can cause serious skin burn and eye inflammation from short wave ultraviolet radiation if outer envelope of the lamp is broken or punctured. Do not use where people will

remain for more than a few minutes unless adequate shielding or other safety precautions are used. Certain lamps that will automatically extinguish when the outer envelope is broken or punctured are commercially available." This lamp complies with FDA radiation performance standard 21 CFR subchapter J. (USA:21 CFR 1040.30 Canada: SOR/DORS/80-381)

## Dimensional drawing

### E26, ED-17P

Product	C (Max)	D (Norm)
MHC P 100W/940 E26 ED17P U ALTO+FB	5.438	2.125

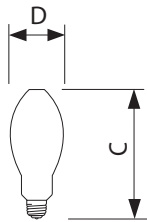

E26



© 2012 Koninklijke Philips Electronics N.V.  
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

[www.philips.com/lighting](http://www.philips.com/lighting)

2012, August 4  
data subject to change