



Energy Saver T2

EL-md T2 18W

The Philips EnergySaver T2 provides energy efficient lighting in a smaller, sleeker, size that fits more fixtures. The energy saving T2 is a direct replacement for most incandescents, provides soft white light and lasts 11 years* reducing the hassle of frequent replacements.

Product data

• General Characteristics

Base	Medium [Single Contact Medium Screw]
RatedAvgLife(See Family Notes)	12000 hr
Estimated Energy Cost/YR	2.17 \$
Life with 3h/day use [years]	11 an

• Light Technical Characteristics

Color Code	827 [CCT of 2700K]
Color Rendering Index	80 (min) Ra8
Color Designation	Warm White
Color Temperature	2690 K
Color Temperature technical	2700 K
Chromaticity Coordinate X	463 -
Chromaticity Coordinate Y	420 -
Initial lumen	1250 Lm
Luminous Efficacy Lamp	65 Lm/W
Lumen Maintenance 2000h	85 %
Lumen Maintenance 5000h	75 %

• Electrical Characteristics

Watts	18 W
Power Factor	0.55 -
Voltage	110-127 V
Lamp Current mA	290 mA
Line Frequency	50/60 Hz
Starting Time	0.2 s
Warm-up Time to 60% Light Outp	90 s

• Product Dimensions


Overall Length C	110.0 (max) mm
Diameter D	56.0 (max) mm
Width F	50.5 (max) mm

• Product Data

Product number	414003
Full product name	EL-md T2 18W
Short product name	EL/mdT2 18W
Pieces per Sku	1
Skus/Case	6
Bar code on pack	46677414009
Bar code on case	50046677414004
Logistics code(s)	929689988503
eop_net_weight_pp	0.072 kg

Dimensional drawing

Dimensional drawing

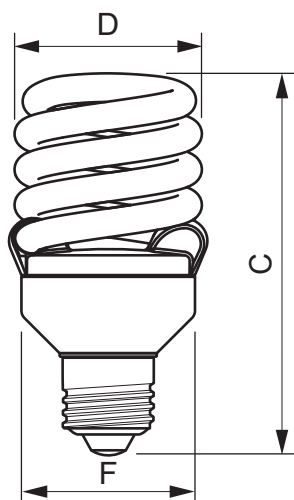

E26

T2, 18W, E26/E27

Product	C (Max)	D (Max)	F (Max)
T2FSpiral 18W/827 E26 110-127V 50/60Hz	110.0	56.0	50.5



© 2012 Koninklijke Philips Electronics N.V.
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

www.philips.com/lighting

2012, August 4
data subject to change