

# Low Voltage Capsules

## LV Capsule 50W 12V T4 CL 1BC

Functional light with substantial energy savings Philips Halogen Low Voltage Capsules provide sparkling, white light. These lamps offer an average rated life of 2000 hours making them perfect for undercabinet or task lighting.



### Product data

#### • General Characteristics

Philips Code	14730
Base	GY6.35
Base Information	na [-]
Bulb	T3 [Diameter: .433 inch /11mm]
Bulb Finish	Clear
Operating Position	Universal [Any or Universal (U)]
RatedAvgLife(See Family Notes)	2000 hr

#### • Light Technical Characteristics

Color Rendering Index	100 Ra8
Color Temperature	3000 K
Color Temperature technical	3000 K
Initial lumen	700 Lm

#### • Electrical Characteristics

Watts	50 W
Lamp Wattage Technical	50 W
Voltage	12 V

Dimmable Yes

#### • Luminaire Design Requirements

Pinch Temperature 350 (max) C

#### • Product Dimensions


Overall Length C 44 (max) mm  
Diameter D 12 (max) mm  
Light Center Length L 30 mm

#### • Product Data

Product number 203307  
Full product name LV Capsule 50W 12V T4 CL 1BC  
Short product name BC50W/T4/12V/CAPSULE 12/1  
Pieces per Sku 1  
eop\_pck\_cfg 12  
Skus/Case 12  
Bar code on pack 46677203306  
Bar code on case 50046677203301  
Logistics code(s) 924062017190  
eop\_net\_weight\_pp 0.002 kg

### Dimensional drawing

## Dimensional drawing

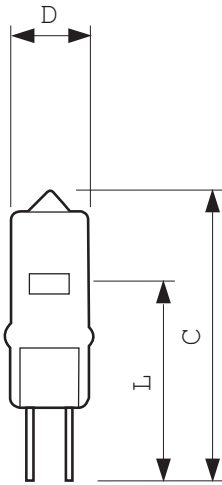

### G4/GY6.35, Fighter

Product	C (Max)	D (Max)	L (Norm)
CAP Fighter 14730 50W GY6.35 12V CL	44	12	30



© 2012 Koninklijke Philips Electronics N.V.  
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

[www.philips.com/lighting](http://www.philips.com/lighting)

2012, August 4  
data subject to change